

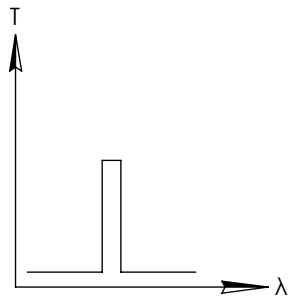
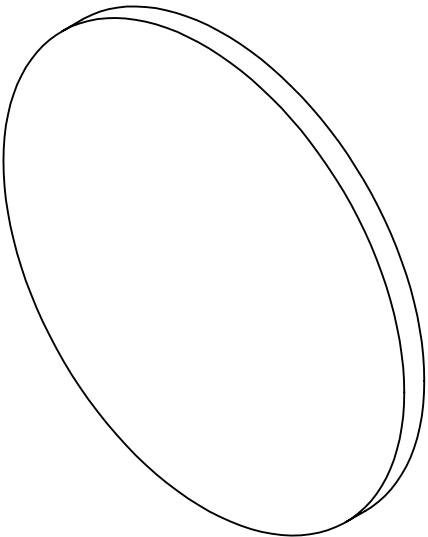


NOTES:

1. SUBSTRATE: COLORED GLASS

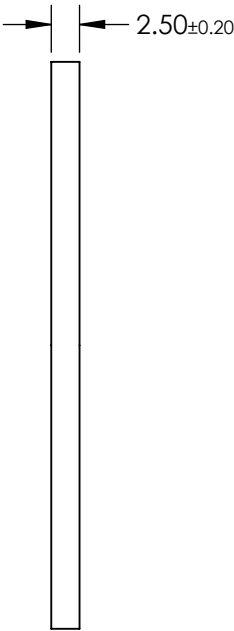

BANDPASS FILTER

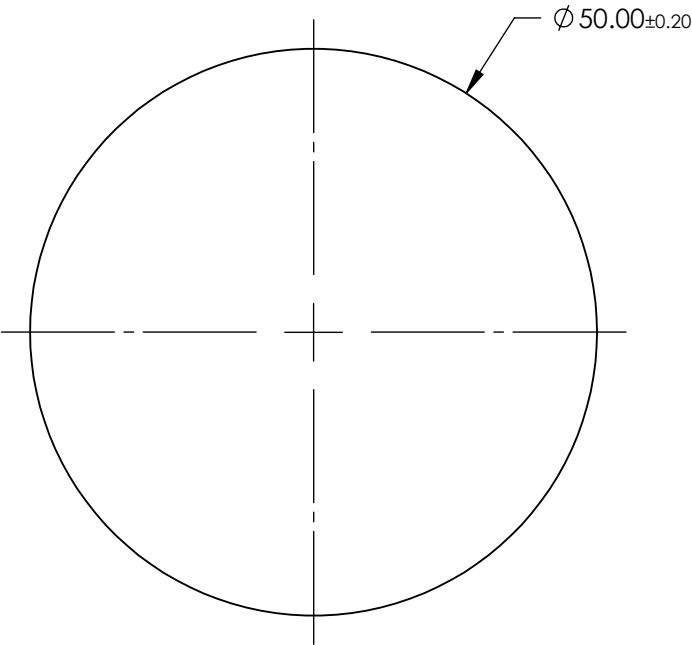

**FOR INFORMATION ONLY:  
DO NOT MANUFACTURE  
PARTS TO THIS DRAWING**


SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE  
DIMENSIONS ARE FOR REFERENCE ONLY

	VALUE
SHAPE	PLANO
CENTER WAVELENGTH (nm)	370.00
FULL WIDTH HALF MAX (FWHM) (nm)	100.00
SURFACE QUALITY	60-40
COATING TYPE	UNCOATED
BEVEL	PROTECTIVE AS NEEDED

THIRD ANGLE  
PROJECTION

ALL DIMS IN

mm

 **Edmund Optics®**

TITLE	Hoya B370 (UVVIS) 50mm Dia., 2.5mm Thick, Colored Glass Bandpass Filter		
DWG NO	18779	SHEET 1 OF 1	