

[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Plano-Concave \(PCV\) Lenses](#)

TECHSPEC® NIR I Coated Plano-Concave (PCV) Lenses



- AR Coated to Provide <0.5% Reflectance per Surface for 600 - 1050nm
- Designed for 0° Angle of Incidence
- Various Coating Options: [Uncoated](#), [VIS-EXT](#), [MgF₂](#), [VIS 0°](#), [VIS-NIR](#), [YAG-BBAR](#), and [NIR II](#)

Common Specifications

Physical & Mechanical Properties


Bevel: Protective as needed

Optical Properties

Coating: NIR I (600-1050nm)

Wavelength Range (nm):	600 - 1050	Coating Specification:	$R_{avg} \leq 0.5\%$ @ 600 - 1050nm
Focal Length Specification Wavelength (nm):	587.6	Focal Length Tolerance (%):	±1
Damage Threshold, By Design:	7 J/cm ² @ 1064nm, 10ns	Power (P-V) @ 632.8nm:	1.5λ
Irregularity (P-V) @ 632.8nm:	λ/4		


Technical Information

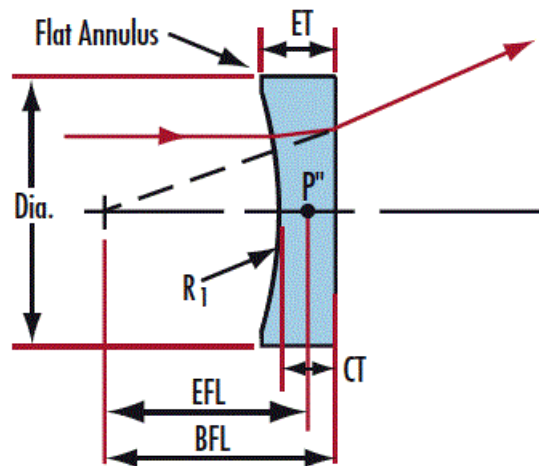

NIR I Coating

$R_{avg} \leq 0.5\% @ 600 - 1050\text{nm}$

Typ. Energy Density Limit: $7 \text{ J/cm}^2 @ 1064\text{nm}, 10\text{ns}$

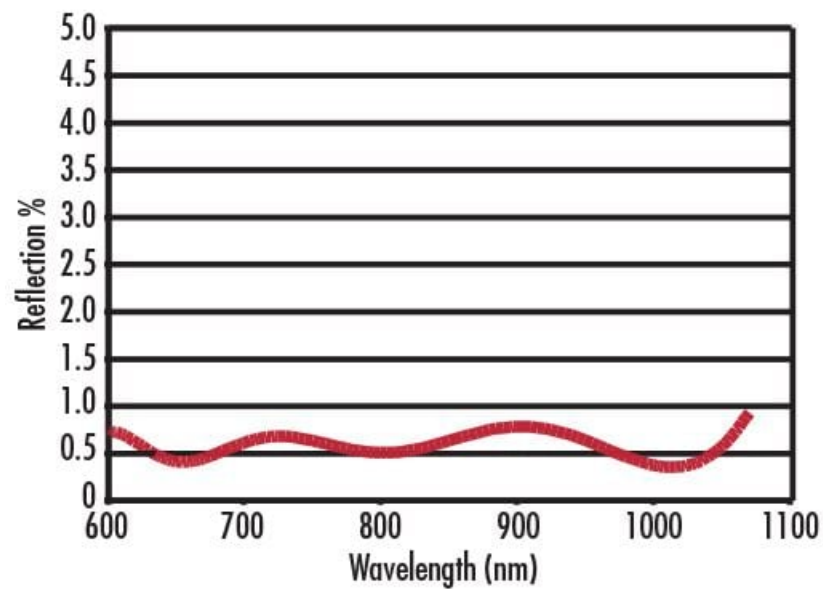

Products

Dia. (mm)	EFL (mm)	BFL (mm)	Coating	Substrate	Stock Number	Price	Buy
3.00	-6.00	-6.56	NIR I (600-1050nm)	N-SF11	#84-383	C\$99.79 Volume Pricing	20+ In Stock
3.00	-9.00	-9.56	NIR I (600-1050nm)	N-SF11	#84-384	C\$99.79 Volume Pricing	Contact Us
6.00	-6.00	-6.84	NIR I (600-1050nm)	N-SF11	#49-516	C\$61.24 Volume Pricing	20+ In Stock
6.00	-9.00	-9.84	NIR I (600-1050nm)	N-SF11	#49-517	C\$61.24 Volume Pricing	20+ In Stock
6.00	-12.00	-12.99	NIR I (600-1050nm)	N-BK7	#49-518	C\$61.24 Volume Pricing	Contact Us
6.00	-15.00	-16.32	NIR I (600-1050nm)	N-BK7	#49-519	C\$61.24 Volume Pricing	6 In Stock
6.00	-18.00	-19.32	NIR I (600-1050nm)	N-BK7	#49-520	C\$61.24 Volume Pricing	20+ In Stock
9.00	-9.00	-10.21	NIR I (600-1050nm)	N-SF11	#49-521	C\$62.75 Volume Pricing	Contact Us
9.00	-12.00	-13.26	NIR I (600-1050nm)	N-SF11	#49-522	C\$62.75 Volume Pricing	5 In Stock
9.00	-18.00	-19.26	NIR I (600-1050nm)	N-SF11	#49-523	C\$62.75 Volume Pricing	20+ In Stock
9.00	-27.00	-28.68	NIR I (600-1050nm)	N-SF11	#49-524	C\$62.75 Volume Pricing	10 In Stock
12.00	-12.00	-13.23	NIR I (600-1050nm)	N-SF11	#49-525	C\$65.77 Volume Pricing	20+ In Stock
12.00	-15.00	-16.68	NIR I (600-1050nm)	N-SF11	#49-526	C\$65.77 Volume Pricing	20+ In Stock
12.00	-18.00	-19.95	NIR I (600-1050nm)	N-SF11	#49-527	C\$65.77 Volume Pricing	7 In Stock
12.00	-24.00	-26.32	NIR I (600-1050nm)	N-BK7	#49-528	C\$65.77 Volume Pricing	4 In Stock
12.00	-48.00	-50.31	NIR I (600-1050nm)	N-BK7	#49-530	C\$65.77 Volume Pricing	13 In Stock

20.00	-30.00	-31.96	NIR I (600-1050nm)	N-SF11	#49-531	C\$68.04 Volume Pricing	3 In Stock
20.00	-40.00	-42.31	NIR I (600-1050nm)	N-BK7	#49-532	C\$68.04 Volume Pricing	8 In Stock
20.00	-50.00	-52.31	NIR I (600-1050nm)	N-BK7	#49-533	C\$68.04 Volume Pricing	4 In Stock
20.00	-	-	NIR I (600-1050nm)	N-BK7	#22-247	C\$68.04 Volume Pricing	4 In Stock
25.00	-25.00	-26.96	NIR I (600-1050nm)	N-SF11	#49-534	C\$69.93 Volume Pricing	20+ In Stock
25.00	-35.00	-36.96	NIR I (600-1050nm)	N-SF11	#49-535	C\$69.93 Volume Pricing	6 In Stock
25.00	-50.00	-52.31	NIR I (600-1050nm)	N-BK7	#49-536	C\$69.93 Volume Pricing	14 In Stock
25.00	-	-	NIR I (600-1050nm)	N-BK7	#49-537	C\$69.93 Volume Pricing	13 In Stock
50.00	-	-	NIR I (600-1050nm)	N-BK7	#49-538	C\$101.30 Volume Pricing	5 In Stock
50.00	-	-	NIR I (600-1050nm)	N-BK7	#49-539	C\$101.30 Volume Pricing	5 In Stock



Copyright 2023, Edmund Optics Inc., 101 East Gloucester Pike, Barrington, NJ 08007-1380 USA

Phone: 1-800-363-1992 :

www.edmundoptics.com