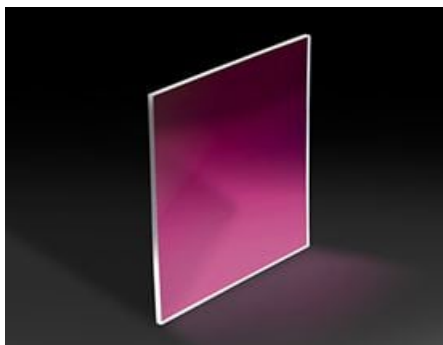


[All Products](#) / [Optics](#) / [Windows and Diffusers](#) / [Visible Windows](#)
TECHSPEC® Gorilla® Glass Windows


- Chemically Strengthened Drawn Glass
- Highly Resistance to Surface Scratches
- Ideal for Electronic Displays

Common Specifications

General

Chemical Strengthening Cycle (hours):	8
---------------------------------------	---

Physical & Mechanical Properties

Bevel:	Protective as needed
--------	----------------------

Clear Aperture (%):	90.00
---------------------	-------

Poisson's Ratio:	0.22
------------------	------

Young's Modulus (GPa):	70
------------------------	----

Optical Properties

Index of Refraction (n_d):	1.5
--------------------------------	-----

Substrate:	Gorilla® Glass
------------	----------------

Surface Quality:	80-50
------------------	-------


Material Properties

Coefficient of Thermal Expansion CTE ($10^{-6}/^{\circ}\text{C}$):	7.58 (0 to +300°C)
--	--------------------

Density (g/cm^3):	2.39
-------------------------------------	------

Technical Information

Gorilla® Glass 3 Typical Transmission

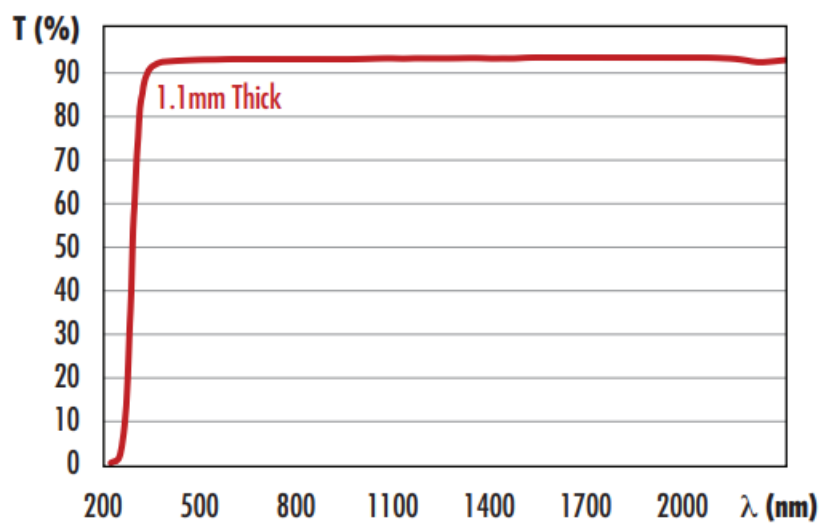

Products

Dia. (mm)	Dimensions (mm)	Thickness (mm)	Coating	Stock Number	Price	Buy
5.00	-	1.10	Uncoated	#83-359	C\$44.89 Volume Pricing	20+ In Stock
5.00	-	1.10	MgF ₂ (400-700nm)	#22-848	C\$75.68 Volume Pricing	9 In Stock
10.00	-	1.10	Uncoated	#83-360	C\$44.89 Volume Pricing	Contact Us
10.00	-	1.10	MgF ₂ (400-700nm)	#22-849	C\$75.68 Volume Pricing	8 In Stock
12.50	-	1.10	Uncoated	#83-361	C\$44.89 Volume Pricing	20+ In Stock
12.50	-	1.10	MgF ₂ (400-700nm)	#22-850	C\$75.68 Volume Pricing	8 In Stock
20.00	-	1.10	Uncoated	#83-362	C\$46.38 Volume Pricing	Contact Us
20.00	-	0.40	Uncoated	#29-719	C\$46.38 Volume Pricing	Contact Us
20.00	-	0.55	Uncoated	#29-720	C\$46.38 Volume Pricing	9 In Stock
20.00	-	1.50	Uncoated	#29-721	C\$46.38 Volume Pricing	Contact Us
20.00	-	2.00	Uncoated	#29-722	C\$46.38 Volume Pricing	Contact Us
20.00	-	1.10	MgF ₂ (400-700nm)	#22-851	C\$77.17 Volume Pricing	Contact Us
25.00	-	1.10	Uncoated	#83-363	C\$46.38 Volume Pricing	20+ In Stock
25.00	-	0.40	Uncoated	#21-232	C\$46.38 Volume Pricing	4 In Stock
25.00	-	0.55	Uncoated	#21-233	C\$46.38 Volume Pricing	3 In Stock
25.00	-	0.80	Uncoated	#21-234	C\$46.38 Volume Pricing	20+ In Stock

25.00	-	1.50	Uncoated	#21-235	C\$46.38 Volume Pricing	15 In Stock
25.00	-	2.00	Uncoated	#21-236	C\$46.38 Volume Pricing	20+ In Stock
25.00	-	1.10	MgF ₂ (400-700nm)	#22-852	C\$77.17 Volume Pricing	5 In Stock
30.00	-	1.10	Uncoated	#83-364	C\$57.88 Volume Pricing	20+ In Stock
30.00	-	0.40	Uncoated	#29-723	C\$57.88 Volume Pricing	20+ In Stock
30.00	-	0.55	Uncoated	#29-724	C\$57.88 Volume Pricing	9 In Stock
30.00	-	1.50	Uncoated	#29-725	C\$57.88 Volume Pricing	2 In Stock
30.00	-	2.00	Uncoated	#29-726	C\$57.88 Volume Pricing	6 In Stock
30.00	-	1.10	MgF ₂ (400-700nm)	#22-853	C\$96.46 Volume Pricing	11 In Stock
40.00	-	1.10	Uncoated	#83-365	C\$64.18 Volume Pricing	Contact Us
40.00	-	1.10	MgF ₂ (400-700nm)	#22-854	C\$102.40 Volume Pricing	20+ In Stock
50.00	-	1.10	Uncoated	#83-366	C\$67.89 Volume Pricing	20+ In Stock
50.00	-	0.40	Uncoated	#29-727	C\$67.89 Volume Pricing	20+ In Stock
50.00	-	0.55	Uncoated	#29-728	C\$67.89 Volume Pricing	Contact Us
50.00	-	1.50	Uncoated	#29-729	C\$67.89 Volume Pricing	1 In Stock
50.00	-	2.00	Uncoated	#29-730	C\$67.89 Volume Pricing	20+ In Stock
50.00	-	1.10	MgF ₂ (400-700nm)	#22-855	C\$106.85 Volume Pricing	20+ In Stock
75.00	-	1.10	Uncoated	#11-854	C\$71.60 Volume Pricing	20+ In Stock
75.00	-	1.10	MgF ₂ (400-700nm)	#22-856	C\$142.46 Volume Pricing	Contact Us

100.00	-	1.10	Uncoated	#21-239	C\$89.04 Volume Pricing	11 In Stock
100.00	-	0.40	Uncoated	#29-731	C\$89.04 Volume Pricing	5 In Stock
100.00	-	0.55	Uncoated	#29-732	C\$89.04 Volume Pricing	3 In Stock
100.00	-	1.50	Uncoated	#29-733	C\$89.04 Volume Pricing	5 In Stock
100.00	-	2.00	Uncoated	#29-734	C\$89.04 Volume Pricing	5 In Stock
200.00	-	1.10	Uncoated	#21-240	C\$146.92 Volume Pricing	2 In Stock
-	203.2 x 254	1.10	Uncoated	#21-237	C\$146.92 Volume Pricing	5 In Stock
-	254 x 304.8	1.10	Uncoated	#21-238	C\$166.21 Volume Pricing	7 In Stock
-	25.00 x 25.00	1.10	Uncoated	#12-228	C\$44.89 Volume Pricing	20+ In Stock
-	50.00 x 50.00	1.10	Uncoated	#11-853	C\$68.64 Volume Pricing	20+ In Stock
-	75.00 x 75.00	1.10	Uncoated	#11-855	C\$71.60 Volume Pricing	10 In Stock
-	100.00 x 100.00	1.10	Uncoated	#83-367	C\$80.88 Volume Pricing	20+ In Stock
-	100.00 x 100.00	0.40	Uncoated	#29-970	C\$80.88 Volume Pricing	2 In Stock
-	100.00 x 100.00	0.55	Uncoated	#29-971	C\$80.88 Volume Pricing	3 In Stock
-	100.00 x 100.00	1.50	Uncoated	#29-972	C\$80.88 Volume Pricing	4 In Stock
-	100.00 x 100.00	2.00	Uncoated	#29-973	C\$80.88 Volume Pricing	10 In Stock
150.00	-	1.10	Uncoated	#29-736	C\$112.04 Volume Pricing	9 In Stock
-	150.00 x 150.00	1.10	Uncoated	#29-735	C\$112.04 Volume Pricing	9 In Stock
-	200.00 x 200.00	1.10	Uncoated	#83-368	C\$146.92 Volume Pricing	12 In Stock

-	250.00 x 250.00	1.10	Uncoated	#17-161	C\$166.21 Volume Pricing	6 In Stock
-	500.00 x 500.00	1.10	Uncoated	#17-162	C\$451.14 Volume Pricing	1 In Stock



Copyright 2023, Edmund Optics Inc., 101 East Gloucester Pike, Barrington, NJ 08007-1380 USA

Phone: 1-800-363-1992 :

www.edmundoptics.com