

[All Products](#) / [Optics](#) / [Optical Filters](#) / [Bandpass Filters](#)

TECHSPEC® Hard Coated OD 4.0 50nm Bandpass Filters



- High Transmission, Deep Blocking
- Broad Bandwidths Ideal for Imaging Applications
- Available in VIS and IR Center Wavelengths
- [Hard Coated OD 4.0 10nm](#) and [25nm](#) Bandpass Filters Also Available

Common Specifications

Physical & Mechanical Properties

Construction: Mounted in Black Anodized Ring	Physical Durability: Adhesion per MIL-PRF-13830B, Section C.4.5.12 Moderate abrasion per MIL-PRF-13830B, Section C.4.5.11 Cleaning per MIL-C-48497A Section 4.5.4.2
---	--

Optical Properties

Angle of Incidence (°): 0	Bandwidth (nm): 45
Optical Density OD (Average): ≥ 4.0	Substrate: Optical Glass
Coating: Hard Coated	Surface Quality: 80-50


Threading & Mounting

Mount Thickness (mm): 5.0 $\pm$ 0.1
--

Environmental & Durability Factors

Environmental Durability: Humidity per MIL-STD-810H, Section 507.6 Temperature per MIL-STD-810H, Section 501.7 and 502.7
--

Technical Information

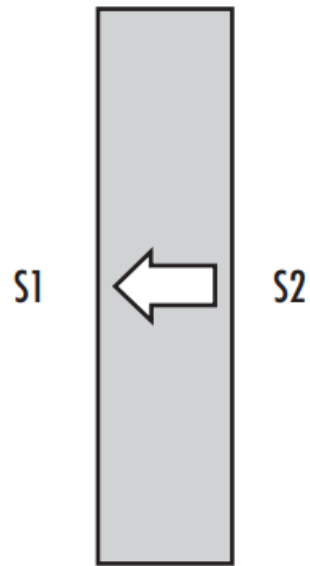

All mounted TECHSPEC® Optical Filters have an arrow on the side of the mount that points to the filter-coated surface for quick reference. Filter oriented such that arrow points to filter coated surface S1. Anti-reflective (AR) coating is applied to S2.

Products

Dia. (mm)	CWL (nm)	FWHM (nm)	Minimum Transmission (%)	Blocking Wavelength Range (nm)	Stock Number	Price	Buy
12.50	300.00	50.00	≥60	200 - 1200	#12-088	C\$287.00 Volume Pricing	3 In Stock
25.00	300.00	50.00	≥60	200 - 1200	#12-093	C\$413.00 Volume Pricing	2 In Stock
50.00	300.00	50.00	≥60	200 - 1200	#12-097	C\$959.00 Volume Pricing	1 In Stock
12.50	325.00	50.00	>80	200 - 1200	#12-089	C\$287.00 Volume Pricing	20+ In Stock
25.00	325.00	50.00	>80	200 - 1200	#12-094	C\$413.00 Volume Pricing	5 In Stock
50.00	325.00	50.00	>80	200 - 1200	#12-098	C\$959.00 Volume Pricing	11 In Stock
12.50	350.00	50.00	>90	200 - 1200	#12-090	C\$287.00 Volume Pricing	20+ In Stock
25.00	350.00	50.00	>90	200 - 1200	#12-095	C\$413.00 Volume Pricing	1 In Stock
50.00	350.00	50.00	>90	200 - 1200	#12-099	C\$959.00 Volume Pricing	1 In Stock
12.50	375.00	50.00	>90	200 - 1200	#12-091	C\$287.00 Volume Pricing	16 In Stock
25.00	375.00	50.00	>90	200 - 1200	#12-096	C\$413.00 Volume Pricing	4 In Stock
50.00	375.00	50.00	>90	200 - 1200	#12-100	C\$959.00 Volume Pricing	4 In Stock
12.50	400.00	50.00	≥90	200 - 1200	#84-769	C\$259.00 Volume Pricing	20+ In Stock
25.00	400.00	50.00	≥90	200 - 1200	#84-781	C\$392.00 Volume Pricing	7 In Stock
50.00	400.00	50.00	≥90	200 - 1200	#84-793	C\$924.00 Volume Pricing	3 In Stock
12.50	425.00	50.00	≥90	200 - 1200	#86-937	C\$259.00 Volume Pricing	20+ In Stock
25.00	425.00	50.00	≥90	200 - 1200	#86-949	C\$392.00 Volume Pricing	2 In Stock

50.00	425.00	50.00	≥90	200 - 1200	#86-961	C\$924.00 Volume Pricing	5 In Stock
12.50	450.00	50.00	≥90	200 - 1200	#84-770	C\$259.00 Volume Pricing	20+ In Stock
25.00	450.00	50.00	≥90	200 - 1200	#84-782	C\$392.00 Volume Pricing	20+ In Stock
50.00	450.00	50.00	≥90	200 - 1200	#84-794	C\$924.00 Volume Pricing	6 In Stock
12.50	475.00	50.00	≥90	200 - 1200	#86-938	C\$259.00 Volume Pricing	20+ In Stock
25.00	475.00	50.00	≥90	200 - 1200	#86-950	C\$392.00 Volume Pricing	8 In Stock
50.00	475.00	50.00	≥90	200 - 1200	#86-962	C\$924.00 Volume Pricing	3 In Stock
12.50	500.00	50.00	≥90	200 - 1200	#84-771	C\$259.00 Volume Pricing	20+ In Stock
25.00	500.00	50.00	≥90	200 - 1200	#84-783	C\$392.00 Volume Pricing	20+ In Stock
50.00	500.00	50.00	≥90	200 - 1200	#84-795	C\$924.00 Volume Pricing	Contact Us
12.50	525.00	50.00	≥90	200 - 1200	#86-939	C\$259.00 Volume Pricing	20+ In Stock
25.00	525.00	50.00	≥90	200 - 1200	#86-951	C\$392.00 Volume Pricing	Contact Us
50.00	525.00	50.00	≥90	200 - 1200	#86-963	C\$924.00 Volume Pricing	Contact Us
12.50	550.00	50.00	≥90	200 - 1200	#84-772	C\$259.00 Volume Pricing	20+ In Stock
25.00	550.00	50.00	≥90	200 - 1200	#84-784	C\$392.00 Volume Pricing	6 In Stock
50.00	550.00	50.00	≥90	200 - 1200	#84-796	C\$924.00 Volume Pricing	5 In Stock
12.50	575.00	50.00	≥90	200 - 1200	#86-940	C\$259.00 Volume Pricing	20+ In Stock
25.00	575.00	50.00	≥90	200 - 1200	#86-952	C\$392.00 Volume Pricing	9 In Stock
50.00	575.00	50.00	≥90	200 - 1200	#86-964	C\$924.00 Volume Pricing	1 In Stock
12.50	600.00	50.00	≥90	200 - 1200	#84-773	C\$259.00 Volume Pricing	16 In Stock

25.00	600.00	50.00	≥90	200 - 1200	#84-785	C\$392.00 Volume Pricing	14 In Stock
50.00	600.00	50.00	≥90	200 - 1200	#84-797	C\$924.00 Volume Pricing	4 In Stock
12.50	625.00	50.00	≥90	200 - 1200	#86-941	C\$259.00 Volume Pricing	2 In Stock
25.00	625.00	50.00	≥90	200 - 1200	#86-953	C\$392.00 Volume Pricing	1 In Stock
50.00	625.00	50.00	≥90	200 - 1200	#86-965	C\$924.00 Volume Pricing	2 In Stock
12.50	650.00	50.00	≥90	200 - 1200	#84-774	C\$259.00 Volume Pricing	20+ In Stock
25.00	650.00	50.00	≥90	200 - 1200	#84-786	C\$392.00 Volume Pricing	11 In Stock
50.00	650.00	50.00	≥90	200 - 1200	#84-798	C\$924.00 Volume Pricing	1 In Stock
12.50	675.00	50.00	≥90	200 - 1200	#86-942	C\$259.00 Volume Pricing	4 In Stock
25.00	675.00	50.00	≥90	200 - 1200	#86-954	C\$392.00 Volume Pricing	6 In Stock
50.00	675.00	50.00	≥90	200 - 1200	#86-966	C\$924.00 Volume Pricing	7 In Stock
12.50	700.00	50.00	≥90	200 - 1200	#84-775	C\$259.00 Volume Pricing	Contact Us
25.00	700.00	50.00	≥90	200 - 1200	#84-787	C\$392.00 Volume Pricing	20+ In Stock
50.00	700.00	50.00	≥90	200 - 1200	#84-799	C\$924.00 Volume Pricing	11 In Stock
12.50	725.00	50.00	≥90	200 - 1200	#86-943	C\$287.00 Volume Pricing	20+ In Stock
25.00	725.00	50.00	≥90	200 - 1200	#86-955	C\$413.00 Volume Pricing	4 In Stock
50.00	725.00	50.00	≥90	200 - 1200	#86-967	C\$959.00 Volume Pricing	12 In Stock
12.50	750.00	50.00	≥90	200 - 1200	#84-776	C\$287.00 Volume Pricing	20+ In Stock
25.00	750.00	50.00	≥90	200 - 1200	#84-788	C\$413.00 Volume Pricing	2 In Stock
50.00	750.00	50.00	≥90	200 - 1200	#84-800	C\$959.00 Volume Pricing	5 In Stock

12.50	775.00	50.00	≥90	200 - 1200	#86-944	C\$287.00 Volume Pricing	20+ In Stock
25.00	775.00	50.00	≥90	200 - 1200	#86-956	C\$413.00 Volume Pricing	5 In Stock
50.00	775.00	50.00	≥90	200 - 1200	#86-968	C\$959.00 Volume Pricing	5 In Stock
12.50	800.00	50.00	≥90	200 - 1200	#84-777	C\$287.00 Volume Pricing	20+ In Stock
25.00	800.00	50.00	≥90	200 - 1200	#84-789	C\$413.00 Volume Pricing	2 In Stock
50.00	800.00	50.00	≥90	200 - 1200	#84-801	C\$959.00 Volume Pricing	5 In Stock
12.50	825.00	50.00	≥90	200 - 1200	#86-945	C\$287.00 Volume Pricing	6 In Stock
25.00	825.00	50.00	≥90	200 - 1200	#86-957	C\$413.00 Volume Pricing	10 In Stock
50.00	825.00	50.00	≥90	200 - 1200	#86-969	C\$959.00 Volume Pricing	3 In Stock
12.50	850.00	50.00	≥90	200 - 1200	#84-778	C\$287.00 Volume Pricing	5 In Stock
25.00	850.00	50.00	≥90	200 - 1200	#84-790	C\$413.00 Volume Pricing	Contact Us
50.00	850.00	50.00	≥90	200 - 1200	#84-802	C\$959.00 Volume Pricing	Contact Us
12.50	875.00	50.00	≥90	200 - 1200	#86-946	C\$287.00 Volume Pricing	20+ In Stock
25.00	875.00	50.00	≥90	200 - 1200	#86-958	C\$413.00 Volume Pricing	14 In Stock
50.00	875.00	50.00	≥90	200 - 1200	#86-970	C\$959.00 Volume Pricing	10 In Stock
12.50	900.00	50.00	≥90	200 - 1200	#84-779	C\$287.00 Volume Pricing	20+ In Stock
25.00	900.00	50.00	≥90	200 - 1200	#84-791	C\$413.00 Volume Pricing	5 In Stock
50.00	900.00	50.00	≥90	200 - 1200	#84-803	C\$959.00 Volume Pricing	11 In Stock
12.50	925.00	50.00	≥90	200 - 1200	#86-947	C\$287.00 Volume Pricing	9 In Stock
25.00	925.00	50.00	≥90	200 - 1200	#86-959	C\$413.00 Volume Pricing	11 In Stock

50.00	925.00	50.00	≥90	200 - 1200	#86-971	C\$959.00 Volume Pricing	1 In Stock
12.50	950.00	50.00	≥90	200 - 1200	#84-780	C\$287.00 Volume Pricing	20+ In Stock
25.00	950.00	50.00	≥90	200 - 1200	#84-792	C\$413.00 Volume Pricing	20+ In Stock
50.00	950.00	50.00	≥90	200 - 1200	#84-804	C\$959.00 Volume Pricing	6 In Stock
12.50	975.00	50.00	≥90	200 - 1200	#86-948	C\$287.00 Volume Pricing	20+ In Stock
25.00	975.00	50.00	≥90	200 - 1200	#86-960	C\$413.00 Volume Pricing	Contact Us
50.00	975.00	50.00	≥90	200 - 1200	#86-972	C\$959.00 Volume Pricing	5 In Stock
12.50	1,000.00	50.00	≥90	200 - 1500	#85-880	C\$336.00 Volume Pricing	5 In Stock
25.00	1,000.00	50.00	≥90	200 - 1500	#85-892	C\$504.00 Volume Pricing	7 In Stock
50.00	1,000.00	50.00	≥90	200 - 1500	#85-904	C\$1,211.00 Volume Pricing	2 In Stock
12.50	1,025.00	50.00	>90	200 - 1500	#87-847	C\$336.00 Volume Pricing	5 In Stock
25.00	1,025.00	50.00	>90	200 - 1500	#87-860	C\$504.00 Volume Pricing	1 In Stock
50.00	1,025.00	50.00	>90	200 - 1500	#87-873	C\$1,211.00 Volume Pricing	1 In Stock
12.50	1,050.00	50.00	≥90	200 - 1500	#85-881	C\$336.00 Volume Pricing	20+ In Stock
25.00	1,050.00	50.00	≥90	200 - 1500	#85-893	C\$504.00 Volume Pricing	7 In Stock
50.00	1,050.00	50.00	≥90	200 - 1500	#85-905	C\$1,211.00 Volume Pricing	8 In Stock
12.50	1,075.00	50.00	>90	200 - 1500	#87-848	C\$336.00 Volume Pricing	20+ In Stock
25.00	1,075.00	50.00	>90	200 - 1500	#87-861	C\$504.00 Volume Pricing	20+ In Stock
50.00	1,075.00	50.00	>90	200 - 1500	#87-874	C\$1,211.00 Volume Pricing	1 In Stock
12.50	1,100.00	50.00	≥90	200 - 1500	#85-882	C\$336.00 Volume Pricing	3 In Stock

25.00	1,100.00	50.00	≥90	200 - 1500	#85-894	C\$504.00 Volume Pricing	6 In Stock
50.00	1,100.00	50.00	≥90	200 - 1500	#85-906	C\$1,211.00 Volume Pricing	1 In Stock
12.50	1,125.00	50.00	>90	200 - 1500	#87-849	C\$336.00 Volume Pricing	Contact Us
25.00	1,125.00	50.00	>90	200 - 1500	#87-862	C\$504.00 Volume Pricing	20+ In Stock
50.00	1,125.00	50.00	>90	200 - 1500	#87-875	C\$1,211.00 Volume Pricing	5 In Stock
12.50	1,150.00	50.00	≥90	200 - 1500	#85-883	C\$336.00 Volume Pricing	20+ In Stock
25.00	1,150.00	50.00	≥90	200 - 1500	#85-895	C\$504.00 Volume Pricing	1 In Stock
50.00	1,150.00	50.00	≥90	200 - 1500	#85-907	C\$1,211.00 Volume Pricing	2 In Stock
12.50	1,175.00	50.00	>90	200 - 1500	#87-850	C\$336.00 Volume Pricing	5 In Stock
25.00	1,175.00	50.00	>90	200 - 1500	#87-863	C\$504.00 Volume Pricing	3 In Stock
50.00	1,175.00	50.00	>90	200 - 1500	#87-876	C\$1,211.00 Volume Pricing	1 In Stock
12.50	1,200.00	50.00	≥90	200 - 1500	#85-884	C\$336.00 Volume Pricing	5 In Stock
25.00	1,200.00	50.00	≥90	200 - 1500	#85-896	C\$504.00 Volume Pricing	5 In Stock
50.00	1,200.00	50.00	≥90	200 - 1500	#85-908	C\$1,211.00 Volume Pricing	1 In Stock
12.50	1,225.00	50.00	>90	200 - 1800	#87-851	C\$336.00 Volume Pricing	1 In Stock
25.00	1,225.00	50.00	>90	200 - 1800	#87-864	C\$504.00 Volume Pricing	1 In Stock
50.00	1,225.00	50.00	>90	200 - 1800	#87-877	C\$1,211.00 Volume Pricing	1 In Stock
12.50	1,250.00	50.00	≥90	200 - 1800	#85-885	C\$336.00 Volume Pricing	4 In Stock
25.00	1,250.00	50.00	≥90	200 - 1800	#85-897	C\$504.00 Volume Pricing	Contact Us
50.00	1,250.00	50.00	≥90	200 - 1800	#85-909	C\$1,211.00 Volume Pricing	2 In Stock

12.50	1,275.00	50.00	>90	200 - 1800	#87-852	C\$336.00 Volume Pricing	2 In Stock
25.00	1,275.00	50.00	>90	200 - 1800	#87-865	C\$504.00 Volume Pricing	4 In Stock
50.00	1,275.00	50.00	>90	200 - 1800	#87-878	C\$1,211.00 Volume Pricing	1 In Stock
12.50	1,300.00	50.00	≥90	200 - 1800	#85-886	C\$336.00 Volume Pricing	14 In Stock
25.00	1,300.00	50.00	≥90	200 - 1800	#85-898	C\$504.00 Volume Pricing	15 In Stock
50.00	1,300.00	50.00	≥90	200 - 1800	#85-910	C\$1,211.00 Volume Pricing	3 In Stock
12.50	1,325.00	50.00	>90	200 - 1800	#87-853	C\$336.00 Volume Pricing	1 In Stock
25.00	1,325.00	50.00	>90	200 - 1800	#87-866	C\$504.00 Volume Pricing	2 In Stock
50.00	1,325.00	50.00	>90	200 - 1800	#87-879	C\$1,211.00 Volume Pricing	12 In Stock
12.50	1,350.00	50.00	≥90	200 - 1800	#85-887	C\$336.00 Volume Pricing	5 In Stock
25.00	1,350.00	50.00	≥90	200 - 1800	#85-899	C\$504.00 Volume Pricing	20+ In Stock
50.00	1,350.00	50.00	≥90	200 - 1800	#85-911	C\$1,211.00 Volume Pricing	4 In Stock
12.50	1,375.00	50.00	>90	200 - 1800	#87-854	C\$336.00 Volume Pricing	20+ In Stock
25.00	1,375.00	50.00	>90	200 - 1800	#87-867	C\$504.00 Volume Pricing	11 In Stock
50.00	1,375.00	50.00	>90	200 - 1800	#87-880	C\$1,211.00 Volume Pricing	2 In Stock
12.50	1,400.00	50.00	≥90	200 - 1800	#85-888	C\$336.00 Volume Pricing	1 In Stock
25.00	1,400.00	50.00	≥90	200 - 1800	#85-900	C\$504.00 Volume Pricing	5 In Stock
50.00	1,400.00	50.00	≥90	200 - 1800	#85-912	C\$1,211.00 Volume Pricing	5 In Stock
12.50	1,425.00	50.00	>90	200 - 1800	#87-855	C\$336.00 Volume Pricing	3 In Stock
25.00	1,425.00	50.00	>90	200 - 1800	#87-868	C\$504.00 Volume Pricing	1 In Stock

50.00	1,425.00	50.00	>90	200 - 1800	#87-881	C\$1,211.00 Volume Pricing	4 In Stock
12.50	1,450.00	50.00	≥90	200 - 1800	#85-889	C\$336.00 Volume Pricing	2 In Stock
25.00	1,450.00	50.00	≥90	200 - 1800	#85-901	C\$504.00 Volume Pricing	2 In Stock
50.00	1,450.00	50.00	≥90	200 - 1800	#85-913	C\$1,211.00 Volume Pricing	7 In Stock
12.50	1,475.00	50.00	>90	200 - 1800	#87-856	C\$336.00 Volume Pricing	1 In Stock
25.00	1,475.00	50.00	>90	200 - 1800	#87-869	C\$504.00 Volume Pricing	3 In Stock
50.00	1,475.00	50.00	>90	200 - 1800	#87-882	C\$1,211.00 Volume Pricing	7 In Stock
12.50	1,500.00	50.00	≥90	200 - 1800	#85-890	C\$336.00 Volume Pricing	1 In Stock
25.00	1,500.00	50.00	≥90	200 - 1800	#85-902	C\$504.00 Volume Pricing	15 In Stock
50.00	1,500.00	50.00	≥90	200 - 1800	#85-914	C\$1,211.00 Volume Pricing	1 In Stock
12.50	1,525.00	50.00	>90	200 - 1800	#87-857	C\$336.00 Volume Pricing	16 In Stock
25.00	1,525.00	50.00	>90	200 - 1800	#87-870	C\$504.00 Volume Pricing	4 In Stock
50.00	1,525.00	50.00	>90	200 - 1800	#87-883	C\$1,211.00 Volume Pricing	9 In Stock
12.50	1,550.00	50.00	≥90	200 - 1800	#85-891	C\$336.00 Volume Pricing	4 In Stock
25.00	1,550.00	50.00	≥90	200 - 1800	#85-903	C\$504.00 Volume Pricing	20+ In Stock
50.00	1,550.00	50.00	≥90	200 - 1800	#85-915	C\$1,211.00 Volume Pricing	5 In Stock
12.50	1,575.00	50.00	>90	200 - 1800	#87-858	C\$336.00 Volume Pricing	20+ In Stock
25.00	1,575.00	50.00	>90	200 - 1800	#87-871	C\$504.00 Volume Pricing	20+ In Stock
50.00	1,575.00	50.00	>90	200 - 1800	#87-884	C\$1,211.00 Volume Pricing	3 In Stock
12.50	1,600.00	50.00	>90	200 - 1800	#87-859	C\$336.00 Volume Pricing	4 In Stock

25.00	1,600.00	50.00	>90	200 - 1800	#87-872	C\$504.00 Volume Pricing	8 In Stock
		Edmund	200 - 1800	#87-885	C\$1,211.00 Volume Pricing	Contact Us	
		optics worldwide					

Copyright 2023, Edmund Optics Inc., 101 East Gloucester Pike, Barrington, NJ 08007-1380 USA
Phone: 1-800-363-1992 :
www.edmundoptics.com