


[All Products](#) / [Optics](#) / [Diffractive Optical Elements \(DOE\)](#)

## HOLO/OR Diffractive Diffusers

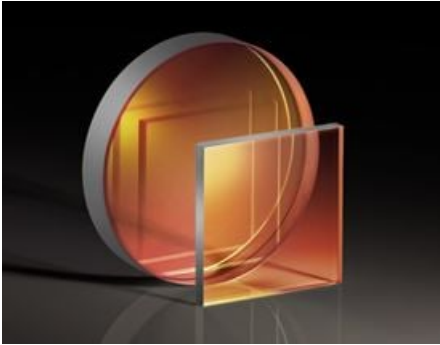

- Shape Laser Beams with Homogenized Distribution
- Circular or Square Output Shapes
- Designs for 532nm and 1064nm Nd:YAG Lasers
- Compatible with Single Mode or Multimode Beams

### Common Specifications

#### Optical Properties

<p><b>Substrate:</b> <a href="#">Fused Silica</a> (Corning 7980)</p>	<p><b>Input Beam Mode:</b> SM or MM</p>
<p><b>Damage Threshold, Reference:</b> <a href="#">See Link for More Details</a></p>	

## Technical Information

## Products

Title	Stock Number	Price	Buy
1064nm, 20mm Dia., Square Output, High Homogeneity Diffractive Diffuser	<a href="#">#14-681</a>	C\$2,905.00	4 In Stock
1064nm, 15mm Dia., Round Output, Diffractive Diffuser	<a href="#">#14-682</a>	C\$2,009.00	1 In Stock
532nm, 15 x 15mm, Round Output, High Homogeneity Diffractive Diffuser	<a href="#">#14-683</a>	C\$3,647.00	6 In Stock



Copyright 2023, Edmund Optics Inc., 101 East Gloucester Pike, Barrington, NJ 08007-1380 USA

Phone: 1-800-363-1992 :

[www.edmundoptics.com](http://www.edmundoptics.com)