


0.04 - 2.0 OD, 50mm, Apodizing Filter Reverse Bull's Eye

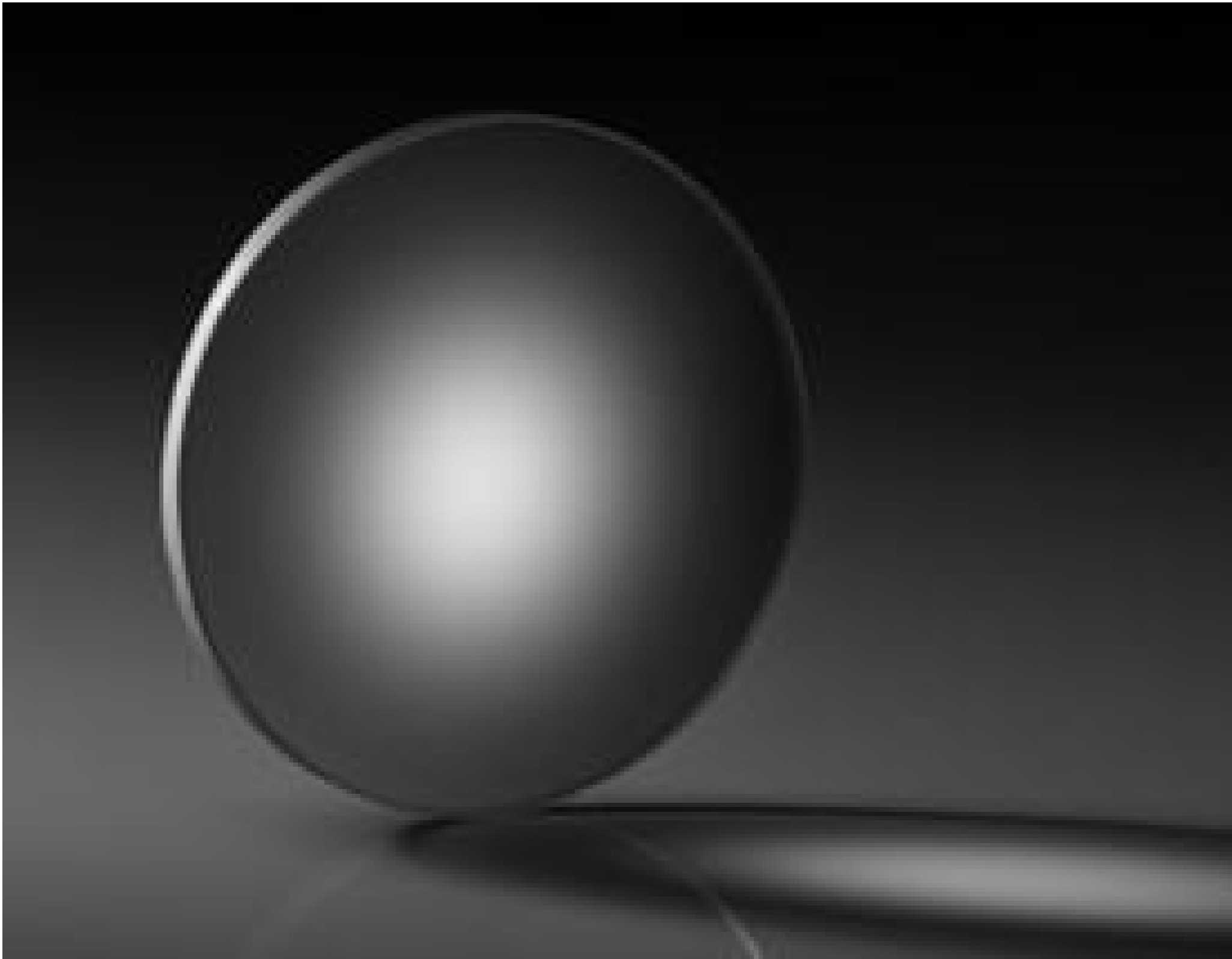

Reverse Bullseye Filter

Stock **#64-392** ☐ In Stock

-

1

+

C\$560.00

ADD TO CART

Qty 1-10

C\$560.00

Qty 11+

C\$503.72

Volume Pricing

[Request Quote](#)

Get Product Downloads



Diameter (mm):
50.00 +0.00/-0.20

Optical Density OD (Average):
0.04 - 2.0

Substrate: ☐
[B270](#)

Type of Filter: Reverse Bull's Eye
Coating: Variable
Surface Quality: 60-40
Thickness (mm): 1.50
Thickness Tolerance (mm): ±0.10
Type: Apodizing Filter
Linearity (%): ±5 of Optical Density
Wavelength Range (nm): 400 - 700

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View