


0.3 OD 12.5mm Dia, Absorptive ND Filter

See More by [Hoya](#)

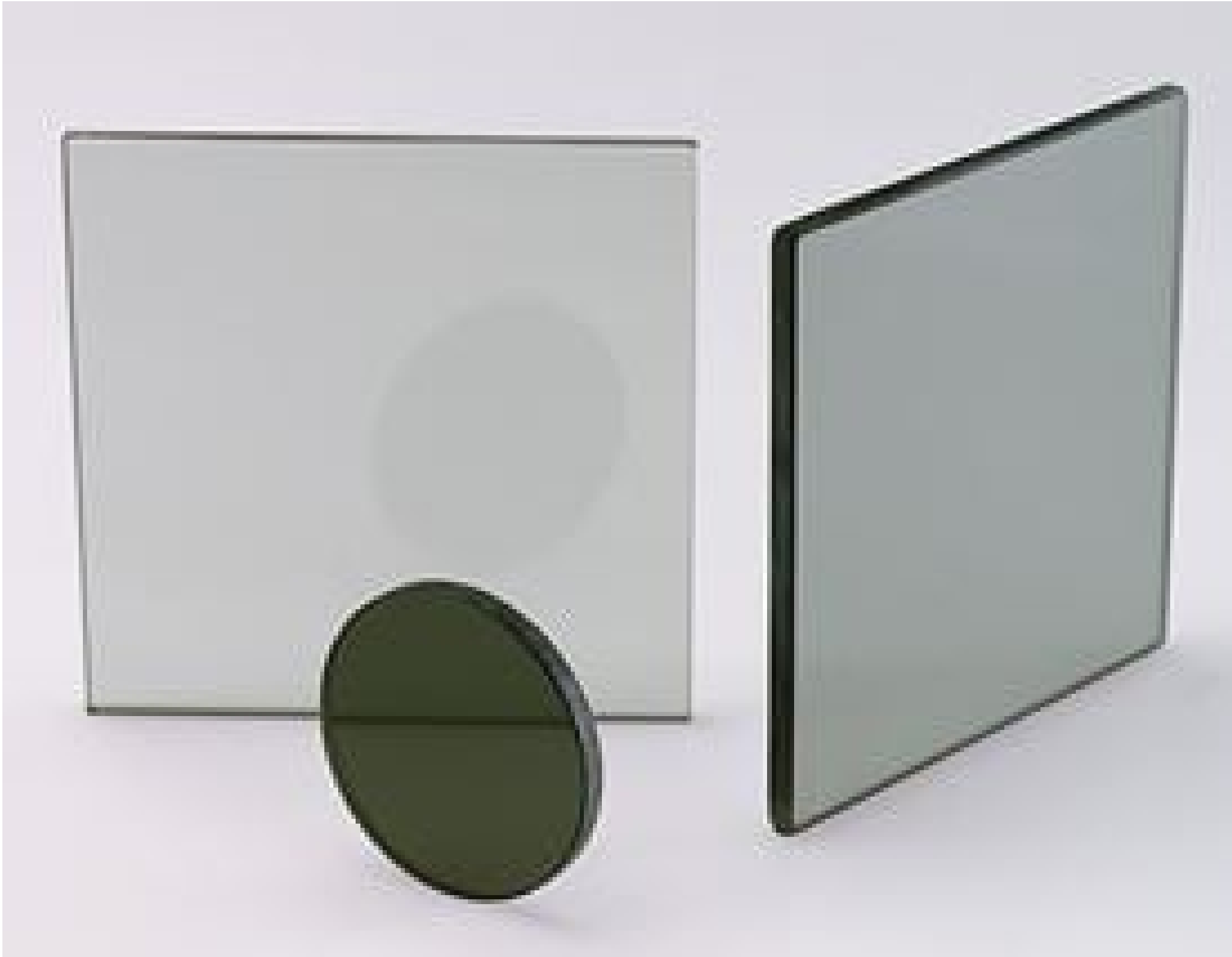

Stock **#48-524** ☐ In Stock

1

C\$43.40

ADD TO CART

Qty 1-10

C\$43.40

Qty 11+

C\$39.20

Volume Pricing

[Request Quote](#)

Get Product Downloads



Diameter (mm):
12.50

Optical Density OD (Average):
0.3 ±0.05

Glass/Filter Number: Hoya ND-50
Substrate: ☐ ND Filter Glass
Coating: Uncoated
Index of Refraction n_d: 1.50
Surface Quality: 80-50
Transformation Temperature (°C): 495
Thickness (mm): 2.50
Thickness Tolerance (mm): ±0.5
Transmission (%): 50.0 (average)
Type: Neutral Density Filter
Blocking Wavelength Range (nm): 400 - 700
Dimensional Tolerance (mm): ±0.1
Parallelism (mm): <0.02

Regulatory Compliance

RoHS 2015: Compliant
REACH 201: Compliant
Certificate of Conformance: View