


# 0.5 OD 50mm Dia, Absorptive ND Filter

See More by [Hoya](#)

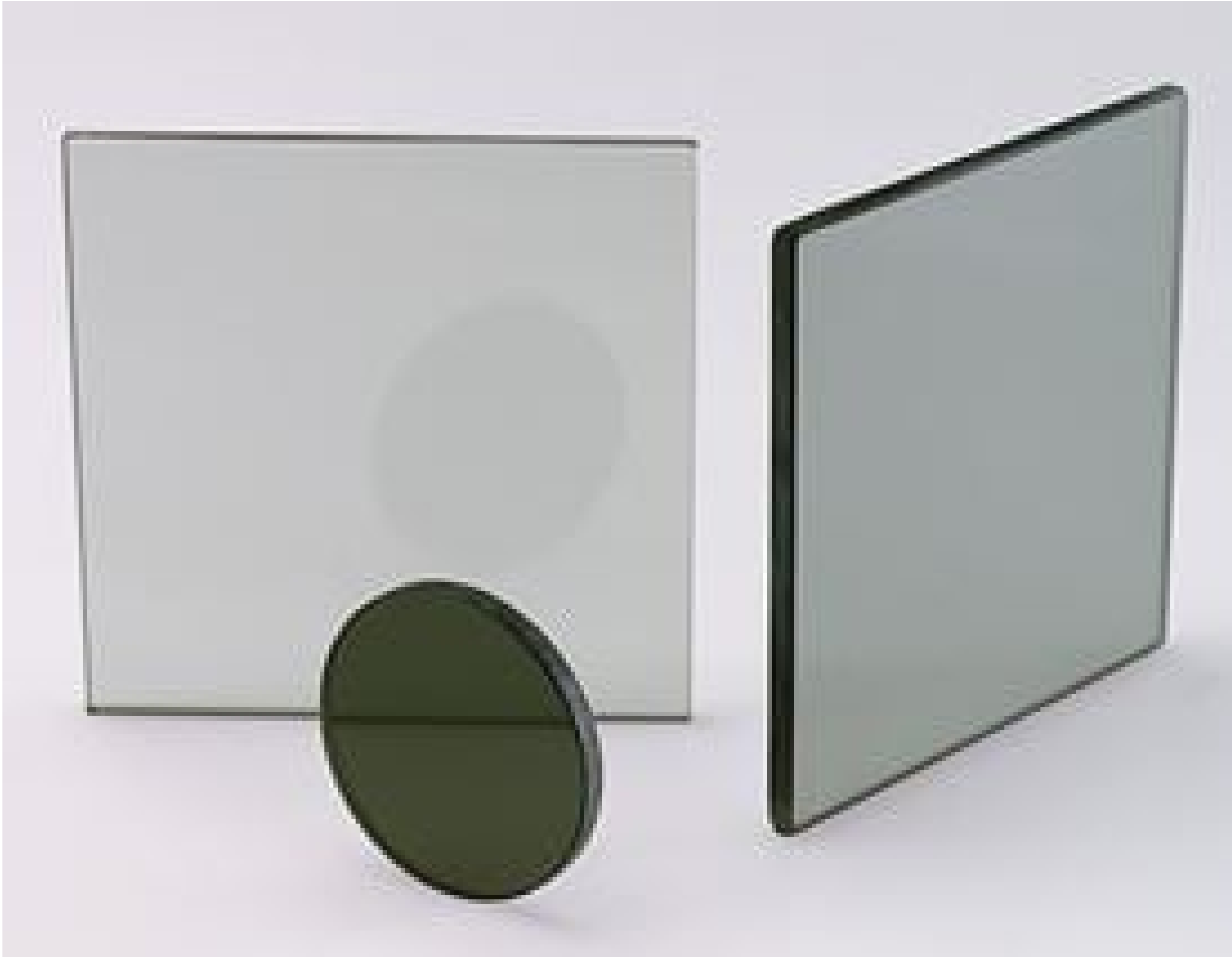

Stock **#65-813** ☐ In Stock

- 1 +

C\$133.00

ADD TO CART

|                               |
|-------------------------------|
| Qty 1-10                      |
| C\$133.00                     |
| Qty 11+                       |
| C\$117.60                     |
| Volume Pricing                |
| <a href="#">Request Quote</a> |

Get Product Downloads



Diameter (mm):  
50.00

Optical Density OD (Average):  
0.5 ±0.05

|                                                                    |
|--------------------------------------------------------------------|
| <div>Glass/Filter Number:<br/><a href="#">Hoya ND-25</a></div>     |
| <div>Substrate: <input type="checkbox"/><br/>ND Filter Glass</div> |
| <div>Coating:<br/>Uncoated</div>                                   |
| <div>Index of Refraction <math>n_d</math>:<br/>1.507</div>         |
| <div>Surface Quality:<br/>80-50</div>                              |
| <div>Transformation Temperature (°C):<br/>535</div>                |
| <div>Thickness (mm):<br/>2.00</div>                                |
| <div>Thickness Tolerance (mm):<br/>±0.5</div>                      |
| <div>Transmission (%):<br/>32.0 (average)</div>                    |
| <div>Type:<br/>Neutral Density Filter</div>                        |
| <div>Blocking Wavelength Range (nm):<br/>400 - 700</div>           |
| <div>Dimensional Tolerance (mm):<br/>±0.1</div>                    |
| <div>Parallelism (mm):<br/>&lt;0.02</div>                          |

### Regulatory Compliance

|                                                                 |
|-----------------------------------------------------------------|
| <div>RoHS 2015:<br/><a href="#">Compliant</a></div>             |
| <div>REACH 201:<br/><a href="#">Compliant</a></div>             |
| <div>Certificate of Conformance:<br/><a href="#">View</a></div> |