

Siemens Star Target, 4" x 4", 120 Sectors Photo Paper

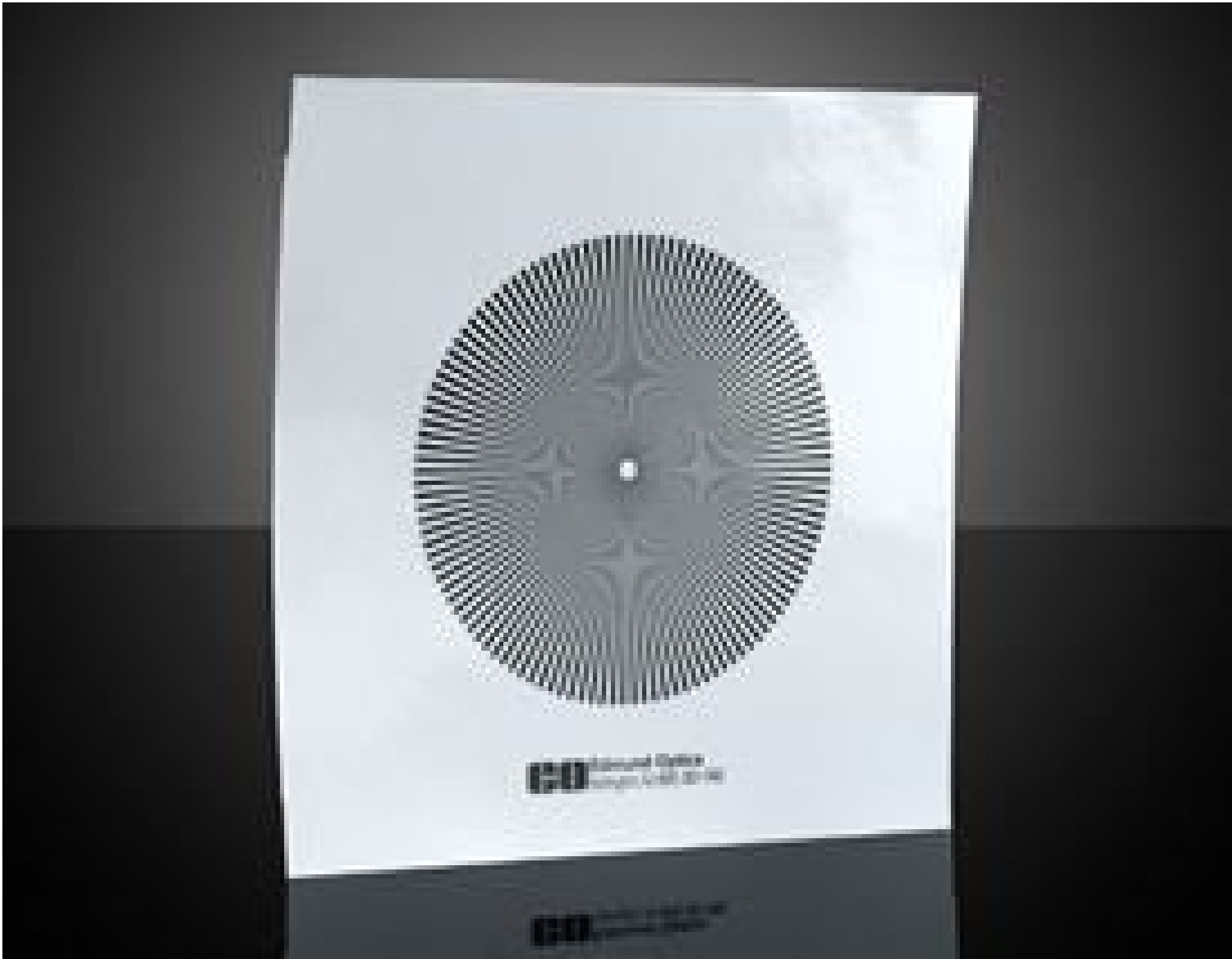


Photo Paper Star Target

Stock #46-246 ☐ In Stock



1



C\$175.00

ADD TO CART

Qty 1-4

C\$175.00

Qty 5+

C\$166.46

Volume Pricing

[Request Quote](#)

Get Product Downloads

Frequency (lp/mm):
0.6112 - 15.28

Substrate:
Photo Paper

Line Width (mm):
0.033 - 0.818

Number of Sectors:

120.00
Optical Density OD (Average): >1.6
Pattern Diameter (mm): 62.5
Dimensions (inches): 4 x 4 ±0.004
Thickness (mm): 0.20 ±nominal
Wedge Angle: 3°
Unresolved Core Diameter (mm): 2.5
Note: Emulsion Coated
NIST Certification: No

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant