


100mm, Green 530nm, MicroBrite Brightfield Ring Light

See More by [Advanced Illumination](#)

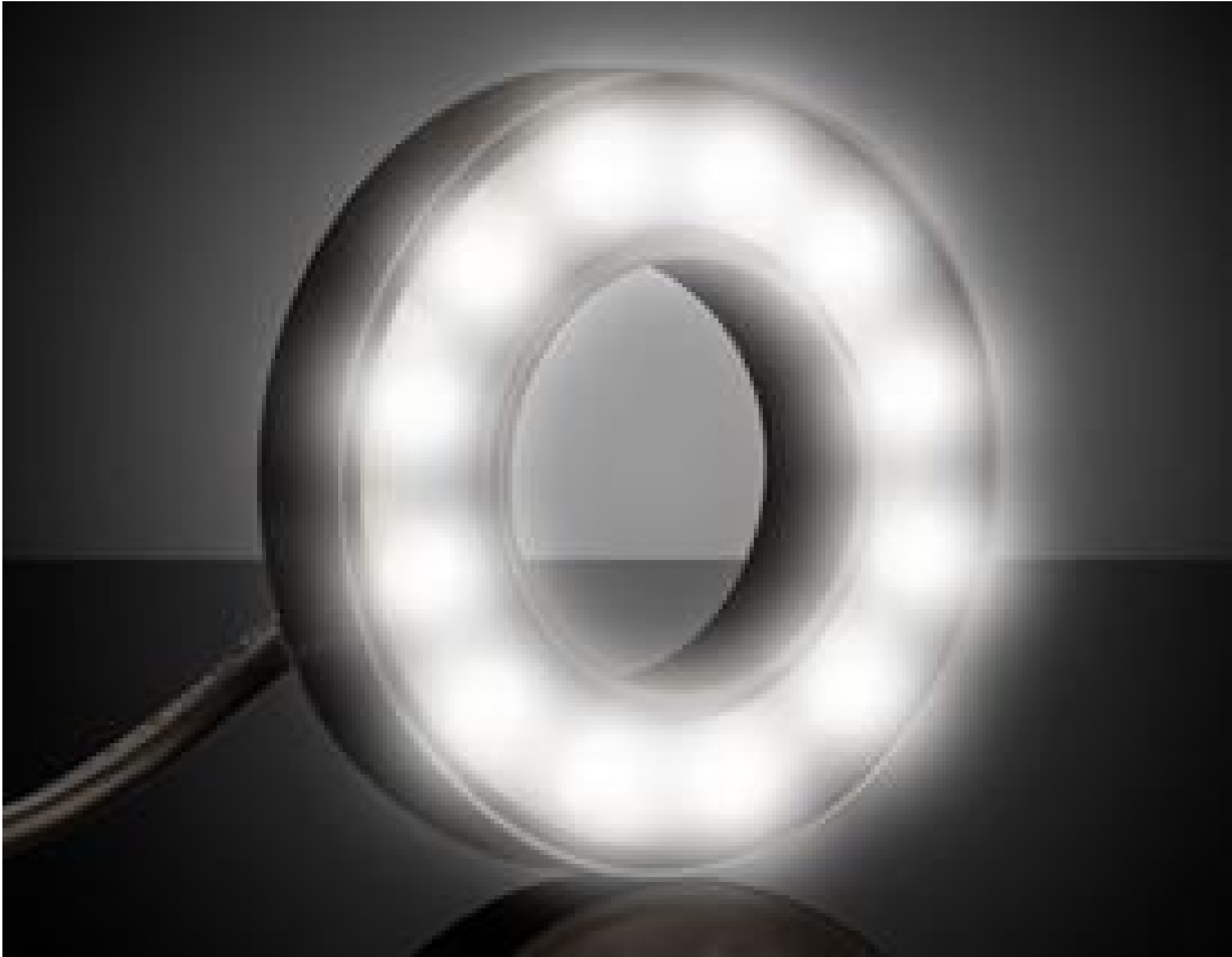

Stock **#18-577** ☐ In Stock

⊖

1

⊕

C\$1,647.80

ADD TO CART

Qty 1+

C\$1,647.80

Volume Pricing

[Request Quote](#)

Get Product Downloads

Color:
Green

Height (mm):
19.09

Inner Diameter (mm):
100

Input Voltage (V):
24V

Model Number:
RL208M-100530IC

Operating Temperature (°C): 0 - 60
Outer Diameter (mm): 145.34
Dimensions (mm): 100.00 x 145.34 x 19.09
Mounting Threads: M4 x4
Wavelength (nm): 530.00
Weight (g): 400
LED Lifetime (hours): 50,000
Power Supply: Power Supply Required and Sold Separately. USA: #66-855 Europe: #66-855 Japan: #66-855 Korea: Not Available China: #66-855
Type of Illumination: LED Illuminator
Note: Optional Manual Intensity Adjustment #86-887 and #89-555 are Available
Manufacturer: Advanced Illumination
Geometry: Ring Light
Maximum Input Current: 0.27A
Illumination Mode: Constant
Environmental Rating: IP50

Regulatory Compliance

RoHS 2015: Exempt
Certificate of Conformance: View
Reach 233: Contains SVHC(s)