


TECHSPEC® 10mm Uncoated Dove Prism

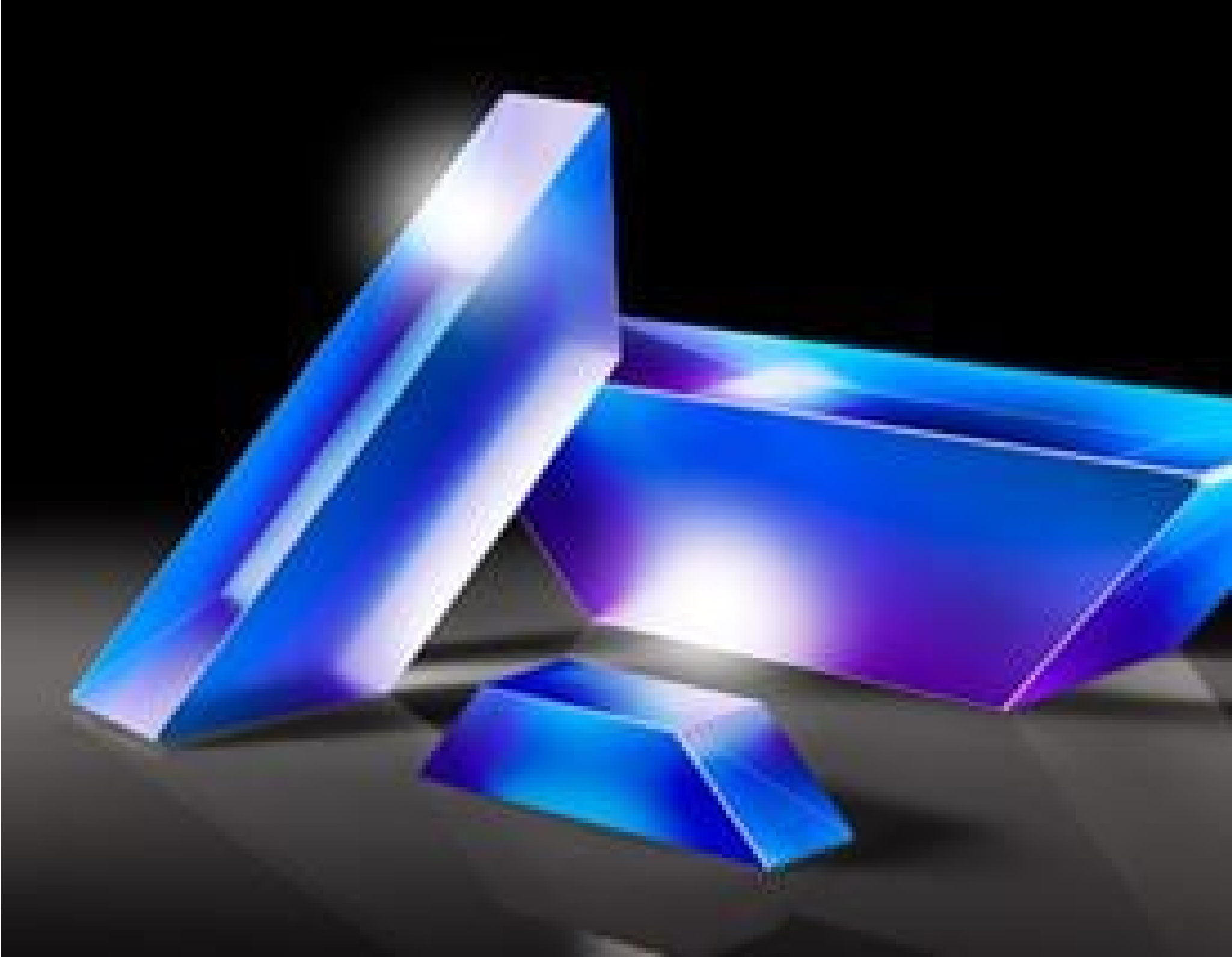

Stock **#32-999** ☐ In Stock

1 **C\$166.60**

ADD TO CART

Qty 1-5
C\$166.60
Qty 6+
C\$149.94
Volume Pricing
Request Quote

Get Product Downloads



Coating:

Uncoated

Substrate: ☐

[N-BK7](#)

Height (mm):

10.0

Length (mm):

43.56
Surface Quality: 60-40
Type: Dove Prism
Dimensional Tolerance (mm): ±0.13 Legs, ±0.25 Length
Angle Tolerance (arcmin): 2.00
Bevel: Protective bevel as needed
Image Orientation: Left-Handed
Ray Deviation (°): 0
Surface Flatness (P-V): λ/8 (Entrance and Exit Faces)

Regulatory Compliance

RoHS 2015: Compliant
Reach 219: Compliant
Certificate of Conformance: View
