

TECHSPEC<sup>®</sup> 10" Length, 1/4-20 Stud, Steel Post



Stock #59-755 CLEARANCE 17 In Stock

-

1

+

C\$22<sup>.79</sup>

ADD TO CART

| Volume Pricing |                               |
|----------------|-------------------------------|
| Qty 1+         | C\$22.79 each                 |
| Need More?     | <a href="#">Request Quote</a> |

Product Downloads

SPECIFICATIONS

General

Type:  
English

Physical & Mechanical Properties

Length (inches):  
10.0

|        |                    |
|--------|--------------------|
| 254.00 | Length (mm):       |
| 0.5    | Diameter (inches): |
| 12.70  | Diameter (mm):     |

Threading & Mounting

|        |              |
|--------|--------------|
| 1/4-20 | Male Thread: |
|--------|--------------|

Regulatory Compliance

|           |                             |
|-----------|-----------------------------|
| Compliant | RoHS 2015:                  |
| View      | Certificate of Conformance: |
| Compliant | REACH 241:                  |


PRODUCT DETAILS

Adapter [#58-983](#) is included. Additional [thread adapters](#) available separately.

- Male 8-32 or 1/4-20 Stud, Female 1/4-20 Base
- Posts Include Interchangeable Male Stud and Removable Base S.H.S.S.
- Available in Variety of Lengths
- [Metric Versions Also Available](#)

TECHSPEC® English Stainless Steel Mounting Posts include a 1/4" long male thread stud adapter that is easily interchangeable with other adapters to ensure compatibility between these posts and any optical mount. Removing the included adapter reveals female 8-32 threads on the post. Each optical post also has a thru-hole to allow an Allen wrench or other tool to rotate the post easily. Thread values are laser engraved on each post for quick identification and integration. TECHSPEC English Stainless Steel Mounting Posts are offered in a variety of lengths. [Metric Versions are also available for purchase.](#)

TECHNICAL INFORMATION

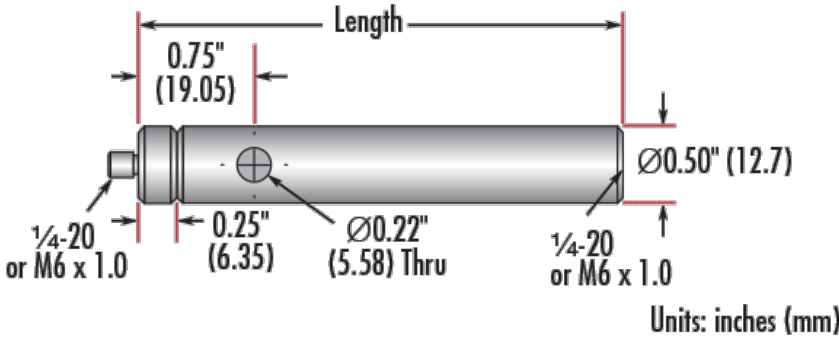

| #68-230                 |                         |     |  |
|-------------------------|-------------------------|-----|--|
| Stock No.               | Description             | Qty |  |
| <a href="#">#59-751</a> | Steel Post, 1" Length   | 1   |  |
| <a href="#">#59-752</a> | Steel Post, 1.5" Length | 1   |  |
| <a href="#">#58-999</a> | Steel Post, 2" Length   | 2   |  |
| <a href="#">#59-754</a> | Steel Post, 3" Length   | 2   |  |
| <a href="#">#59-000</a> | Steel Post, 4" Length   | 2   |  |
| <a href="#">#59-008</a> | Steel Post, 6" Length   | 1   |  |
| <a href="#">#59-009</a> | Steel Post, 8" Length   | 1   |  |

| #68-229                 |                         |     |  |
|-------------------------|-------------------------|-----|--|
| Stock No.               | Description             | Qty |  |
| <a href="#">#58-960</a> | Steel Post, 1" Length   | 1   |  |
| <a href="#">#58-961</a> | Steel Post, 1.5" Length | 1   |  |
| <a href="#">#58-962</a> | Steel Post, 2" Length   | 2   |  |
| <a href="#">#58-964</a> | Steel Post, 3" Length   | 2   |  |
| <a href="#">#58-965</a> | Steel Post, 4" Length   | 2   |  |
| <a href="#">#58-966</a> | Steel Post, 6" Length   | 1   |  |
| <a href="#">#58-967</a> | Steel Post, 8" Length   | 1   |  |