


1200 Grooves, 30mm Square, 1000nm NIR Ruled Grating

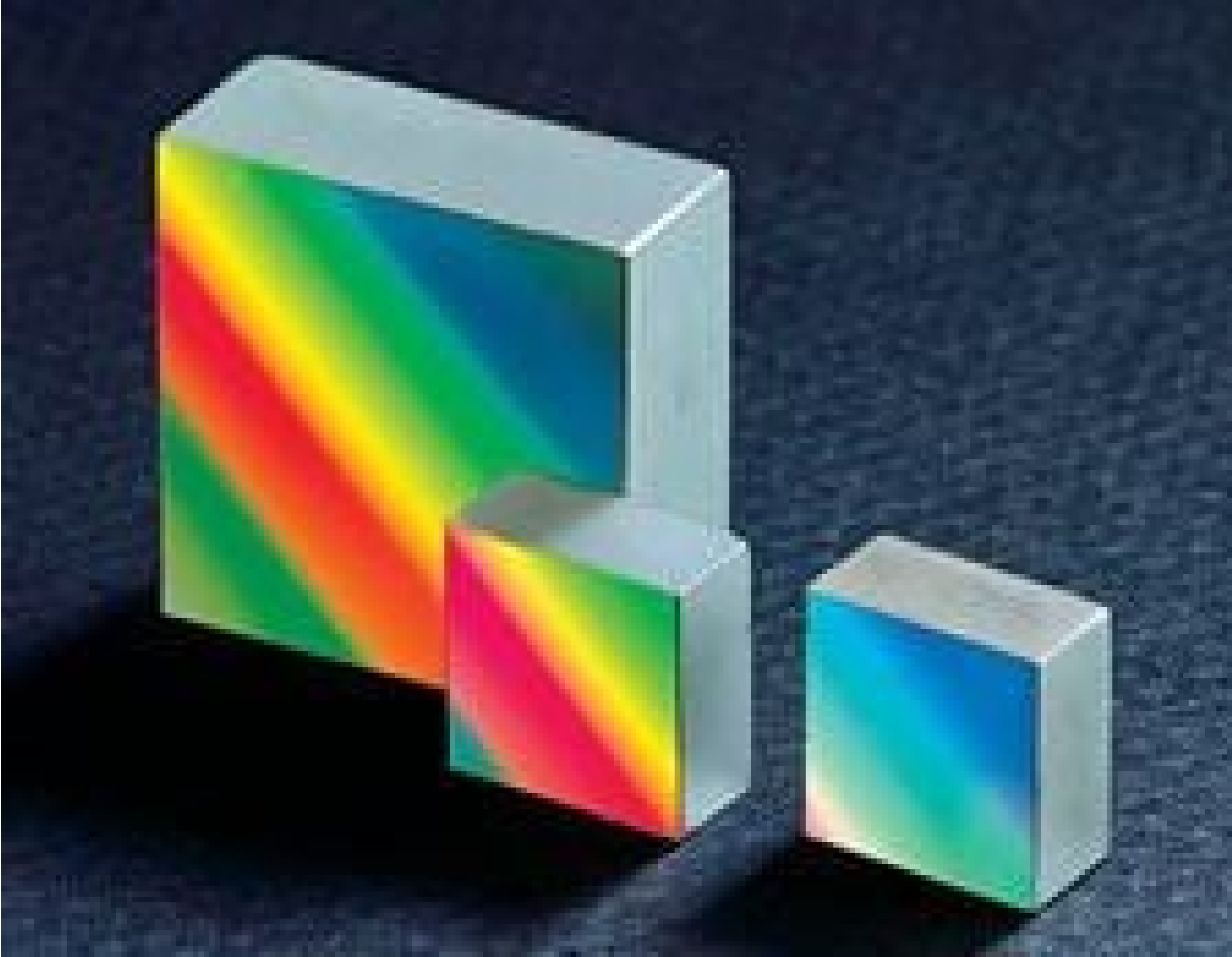

Stock #55-263 ☐ In Stock

-

1

+

C\$273.00

ADD TO CART

Qty 1+

C\$273.00

Volume Pricing

[Request Quote](#)

Get Product Downloads



Groove Density (grooves/mm):
1200

Wavelength Range (nm):
700 - 3000

Blaze Wavelength (nm):
1000

Blaze Angle (°):
36.87

Dimensions (mm):

30.0 x 30.0 ±0.5
Clear Aperture (%) : 90
Coating: Bare Gold
Construction: Ruled Grating
Direction of Grooves: Parallel to Short Dimension
Length (mm): 30.00
Substrate: ☐ Float Glass
Thickness (mm): 9.50 ±0.5
Type: Reflective Diffraction Grating
Width (mm): 30.00
Alignment of Grooves to Edge (°): ±0.5

Regulatory Compliance

RoHS 2015: Compliant
Reach 219: Compliant
Certificate of Conformance: View