

TECHSPEC[®] 125mm, Center Drive, Standard Top, English Extended Micrometer



TECHSPEC[®] Crossed-Roller Bearing Linear Translation Stages (Standard-Top Model)



Stock #66-452 3 In Stock

-

1

+

C\$1,190⁰⁰

ADD TO CART

Volume Pricing	
Qty 1-2	C\$1,190.00 each
Qty 3+	C\$1,041.74 each
Need More?	Request Quote

Product Downloads

General

Type:

English


Physical & Mechanical Properties

Type of Movement:


Linear (X)

Guide System:


30mm Standard-Top Stages - Center Drive

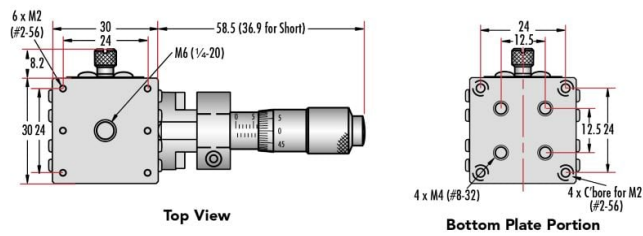


30mm Standard-Top Stages - Side Drive

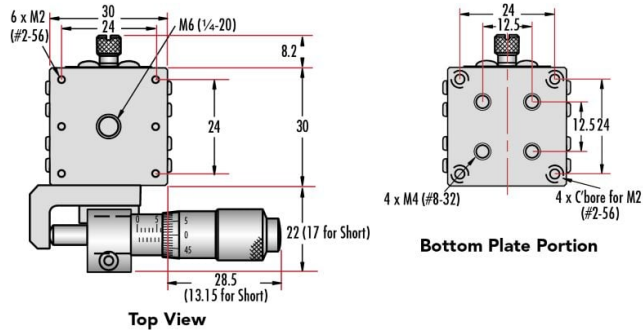


40mm Standard-Top Stages - Center Drive

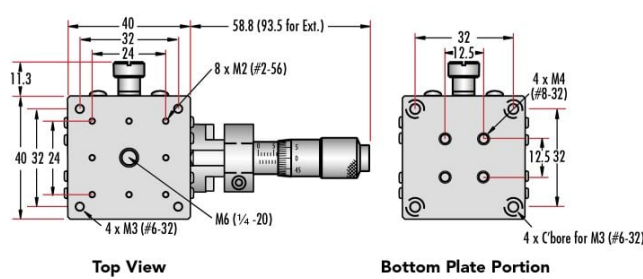


40mm Standard-Top Stages - Side Drive

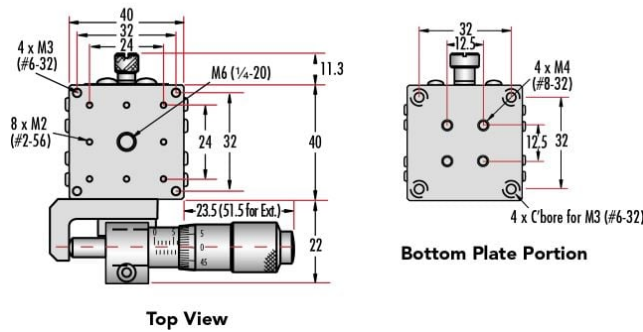


70mm Standard-Top Stages - Center Drive

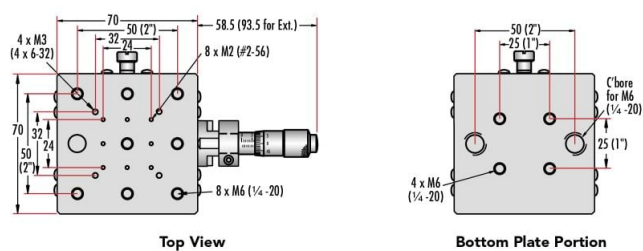

70mm Standard-Top Stages - Side Drive

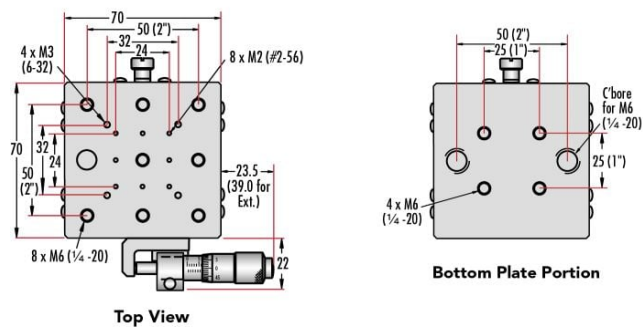

125mm Standard-Top Stages - Center Drive

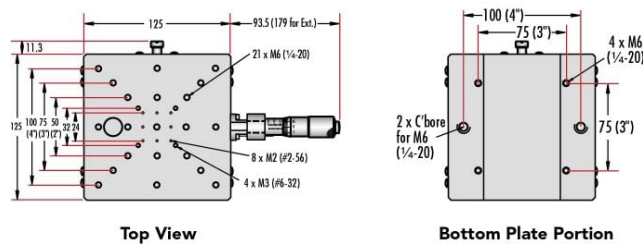

125mm Standard-Top Stages - Side Drive

