


TECHSPEC[®] 12.5mm Dia x 12.5mm FL Acylinder Lens, MgF₂ Coated

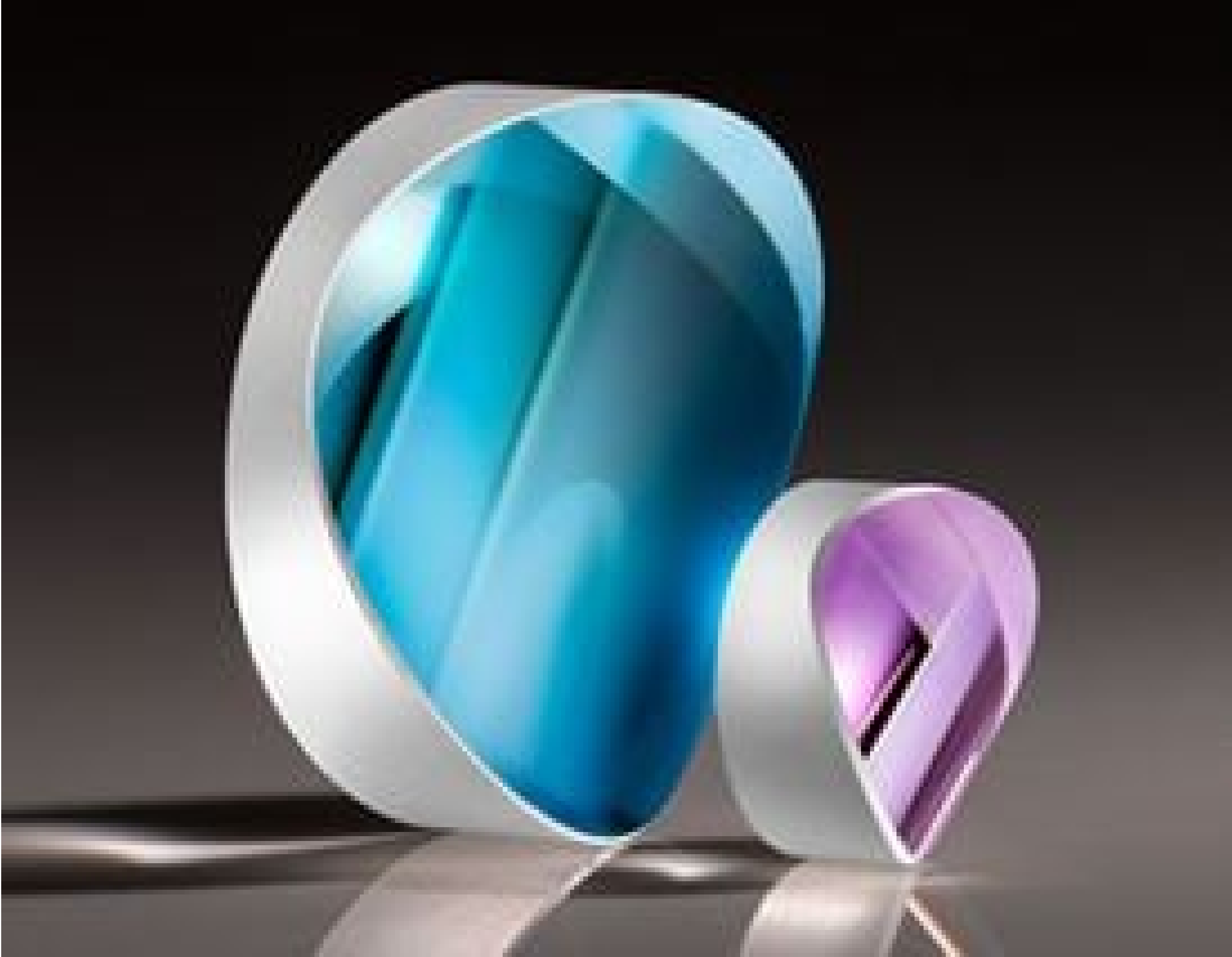

TECHSPEC Acylinder Lenses

Stock #86-035 ☐ In Stock

-

1

+

C\$875.00

ADD TO CART

Qty 1-5

C\$875.00

Qty 6+

C\$700.00

Volume Pricing

[Request Quote](#)

Get Product Downloads

Diameter (mm):
12.50 +0.0/-0.1

Effective Focal Length EFL (mm):
12.50

Substrate: ☐
[N-SF5](#)

f/#:

1.00
Numerical Aperture NA: 0.50
Coating: MgF ₂ (400-700nm)
Type: Acyliner Lens
Wavelength Range (nm): 400 - 700
Back Focal Length BFL (mm): 9.2
Center Thickness CT (mm): 5.50
Center Thickness Tolerance (mm): ±0.1
Clear Aperture (%): 90.00
Coating Specification: R _{avg} ≤1.75% @ 400 - 700nm
Edge Thickness ET (mm): 3.0
Focal Length Specification Wavelength (nm): 587.6
Surface Accuracy, RMS (µm): 1.0
Surface Quality: 60-40

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant