


12.5mm Dia. x 1mm High Efficiency Window

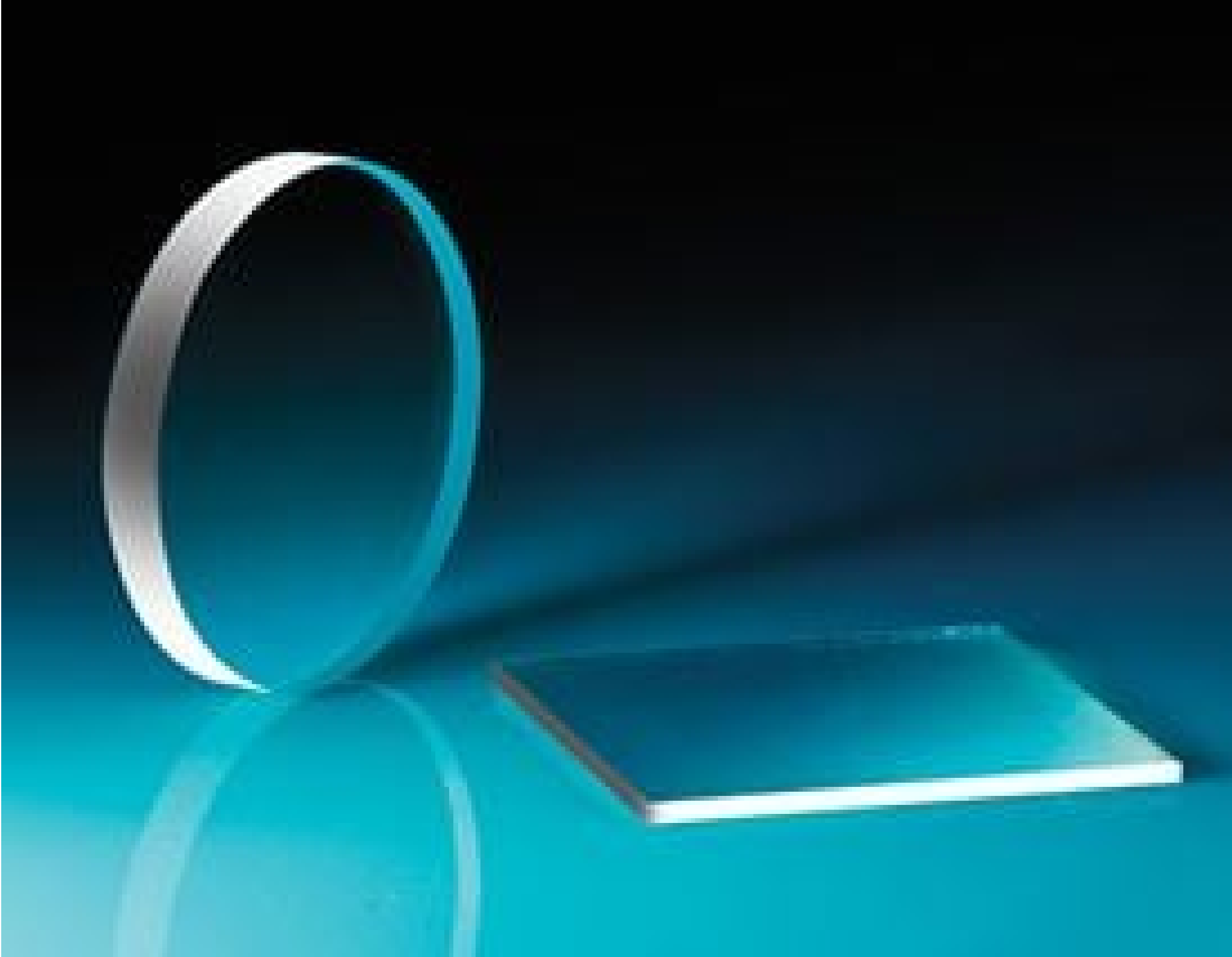

Stock **#21-324** ☐ In Stock

-

1

+

C\$30.10

ADD TO CART

Qty 1-5
C\$30.10
Qty 6+
C\$24.15
Volume Pricing
Request Quote

Get Product Downloads



Angle of Incidence (°):
0

Bevel:
Protective as needed

Clear Aperture (%):
≥90

Clear Aperture CA (mm):

11.25
Diameter (mm): 12.50 ±0.51
Thickness (mm): 1.00 ±0.25
Coating: BBAR (425-700nm)
Coating Specification: Ravg ≤0.5% @ 425 - 700nm
Edges: Ground
Substrate: Float Glass
Surface Quality: 80-50
Transmission (%): 95.6 Average (typical)
Type: Protective Window
Wavelength Range (nm): 425 - 700

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 233: Compliant