

TECHSPEC[®] 125mm, Side Drive, Standard Top, Metric Stage



TECHSPEC[®] Crossed-Roller Bearing Linear Translation Stages (Standard-Top Model)



+2

Stock #66-459 1 In Stock

⊖ 1 ⊕ C\$931⁰⁰

ADD TO CART

Volume Pricing	
Qty 1-2	C\$931.00 each
Qty 3+	C\$812.70 each
Need More?	Request Quote

Product Downloads

General

Type:

Metric


Physical & Mechanical Properties

Type of Movement:


Linear (X)

Guide System:


30mm Standard-Top Stages - Center Drive

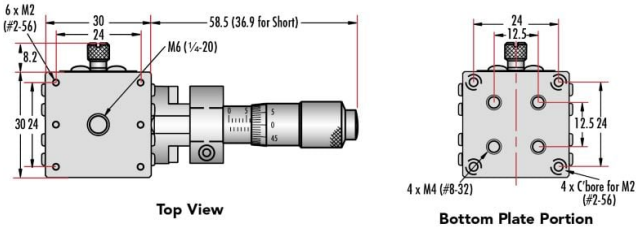


30mm Standard-Top Stages - Side Drive

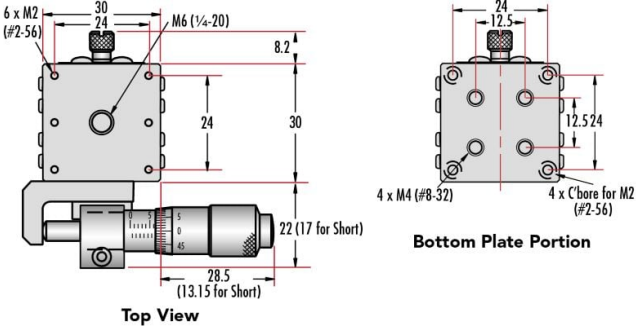


40mm Standard-Top Stages - Center Drive

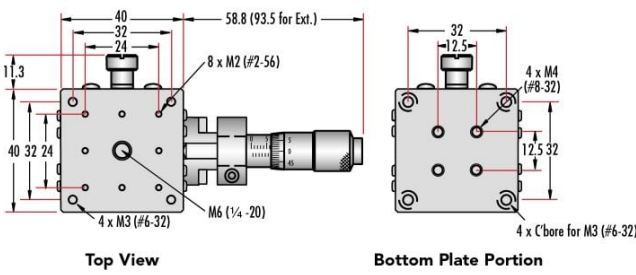


40mm Standard-Top Stages - Side Drive

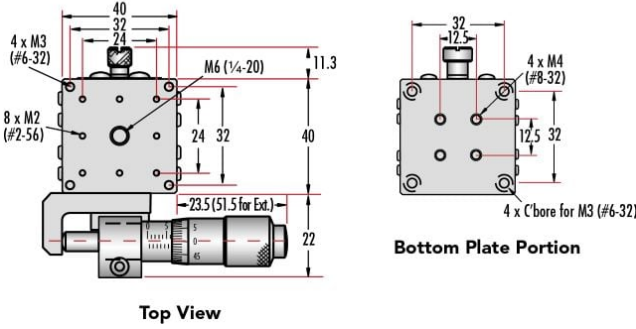


70mm Standard-Top Stages - Center Drive

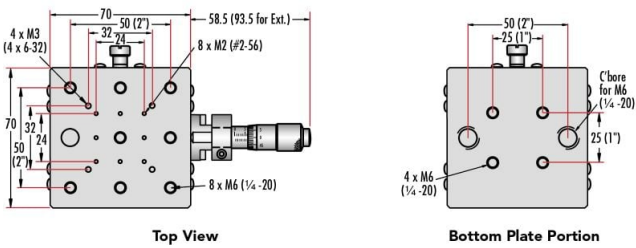

70mm Standard-Top Stages - Side Drive

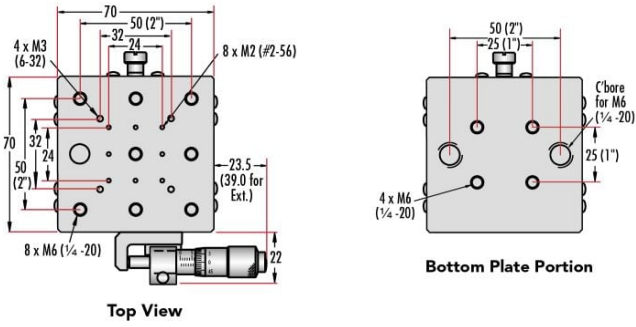

125mm Standard-Top Stages - Center Drive

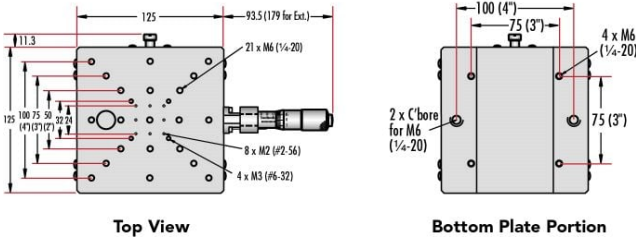

125mm Standard-Top Stages - Side Drive

