


127 x 177.8 x 3mm High Efficiency Window

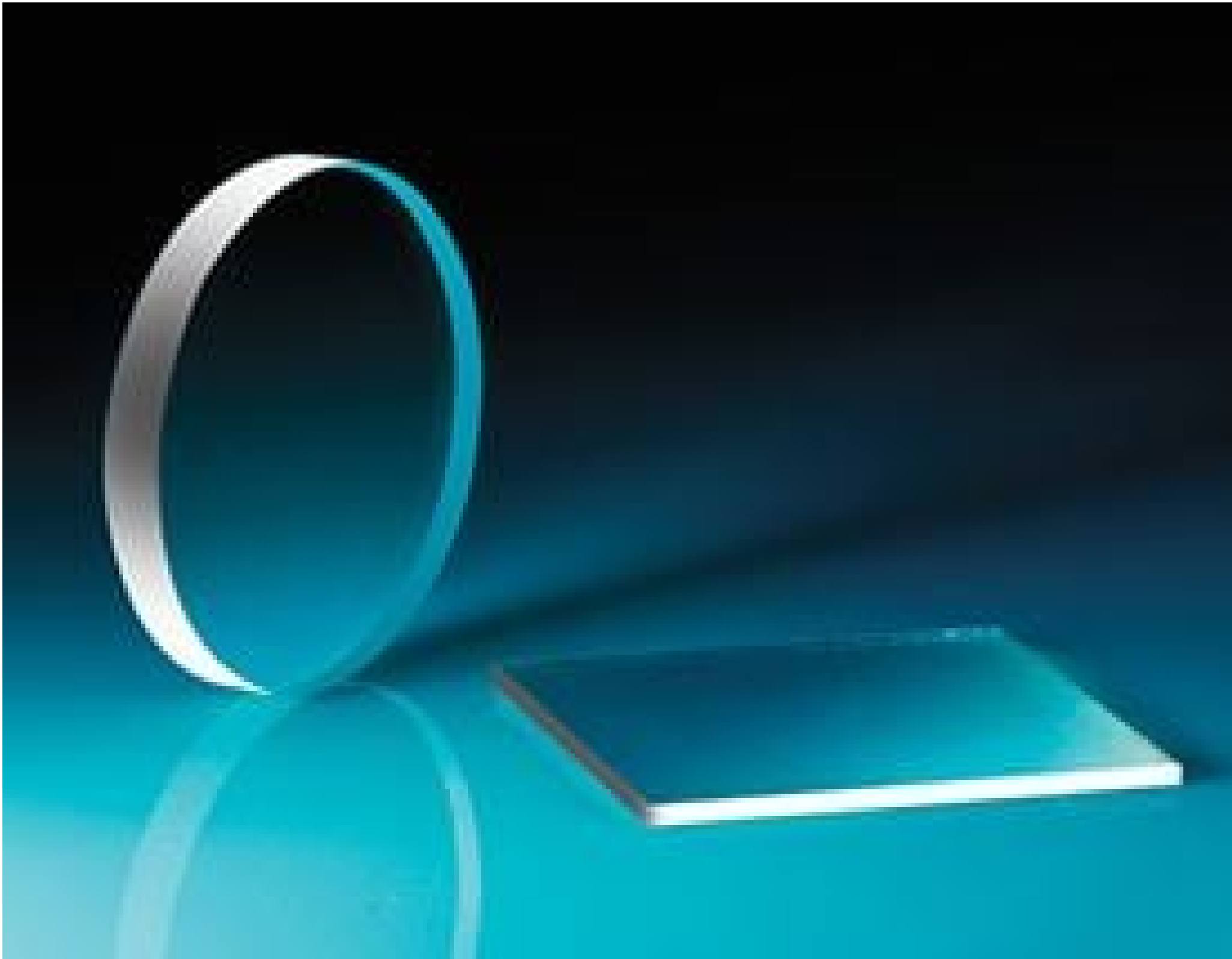

Stock **#43-973** ☐ In Stock

1

C\$68.60

ADD TO CART

Qty 1-5
C\$68.60
Qty 6+
C\$54.95
Volume Pricing
Request Quote

Get Product Downloads



Angle of Incidence (°):
0

Bevel:
Protective as needed

Clear Aperture (%):
≥90

Clear Aperture CA (mm):

114.30 x 160.02
Dimensions (mm): 127.00 x 177.80
Thickness (mm): 3.00 ±0.25
Coating: BBAR (425-700nm)
Coating Specification: R _{avg} ≤0.5% @ 425 - 700nm
Edges: Seamed
Substrate: Float Glass
Surface Quality: 80-50
Transmission (%): 95.6 Average (typical)
Type: Protective Window
Wavelength Range (nm): 425 - 700
Length (mm): 177.80
Width (mm): 127.00

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 240: Compliant