


SCHOTT AS87ECO, 12.7 x 38.1mm, 0.1mm Thick, Ultra-Thin Window

See More by [SCHOTT Optical Components](#)

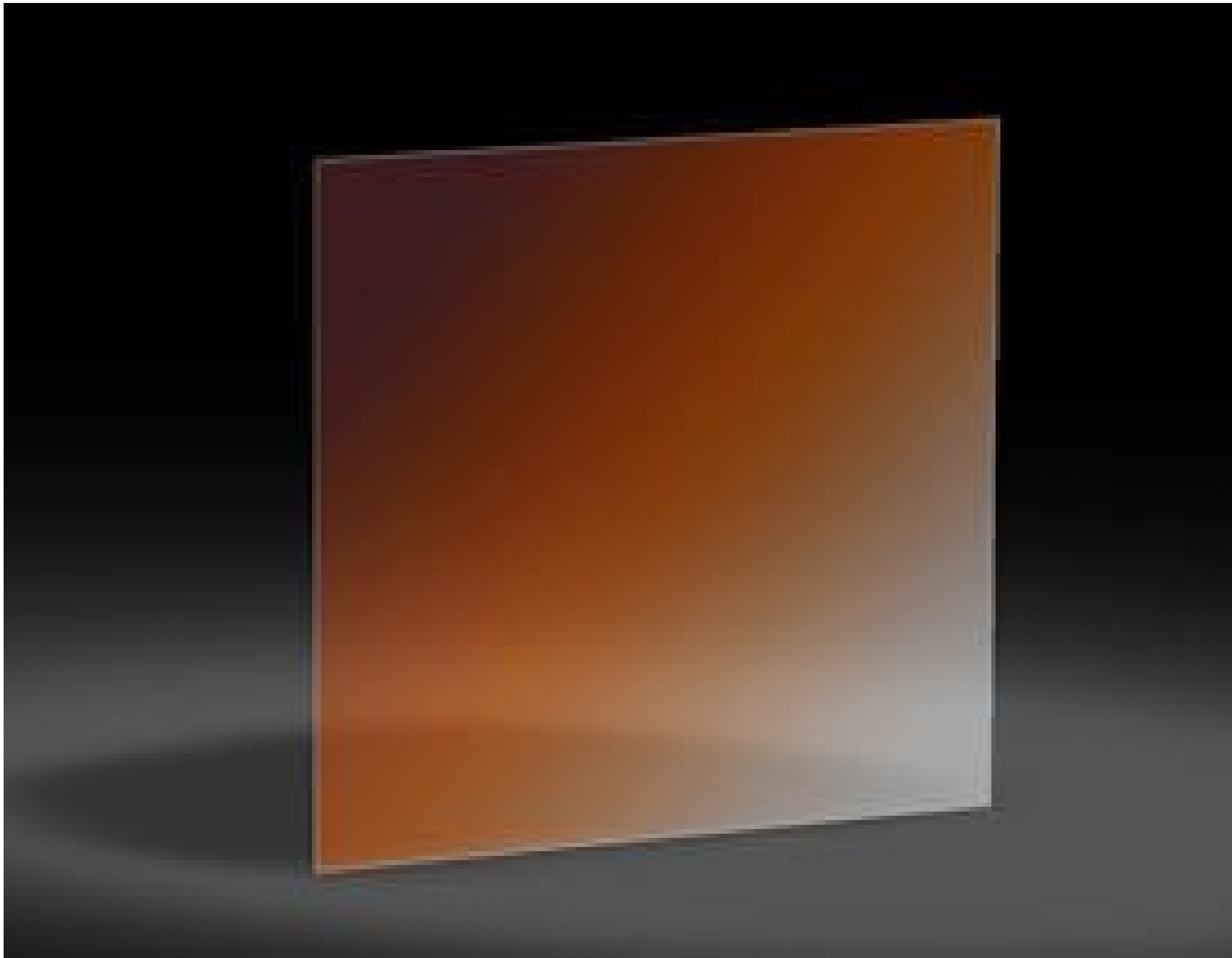

Stock **#12-299** CLEARANCE ☐ In Stock

-

1

+

C\$46.20

ADD TO CART

Qty 1-10
C\$46.20

Qty 11+
C\$37.10

Volume Pricing
Request Quote

Get Product Downloads

Abbe Number (v_d): 59.5
Bevel: Protective as needed
Clear Aperture (%): 90
Clear Aperture CA (mm):

11.43 x 34.29
Dimensions (mm): 12.70 x 38.10
Thickness (mm): 0.10 ±0.01
Coating: Uncoated
Coefficient of Thermal Expansion CTE (10⁻⁶/°C): 8.7
Density (g/cm³): 2.46
Index of Refraction n_d: 1.504
Knoop Hardness (kg/mm²): 500
Poisson's Ratio: 0.216
Substrate: AS 87 ECO
Surface Quality: 80-50
Type: Protective Window
Wavelength Range (nm): 200 - 3200
Young's Modulus (GPa): 73.3
Length (mm): 38.10
Width (mm): 12.70

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 233: Compliant