


134mm Dia. Uncoated Laser Debris Shield

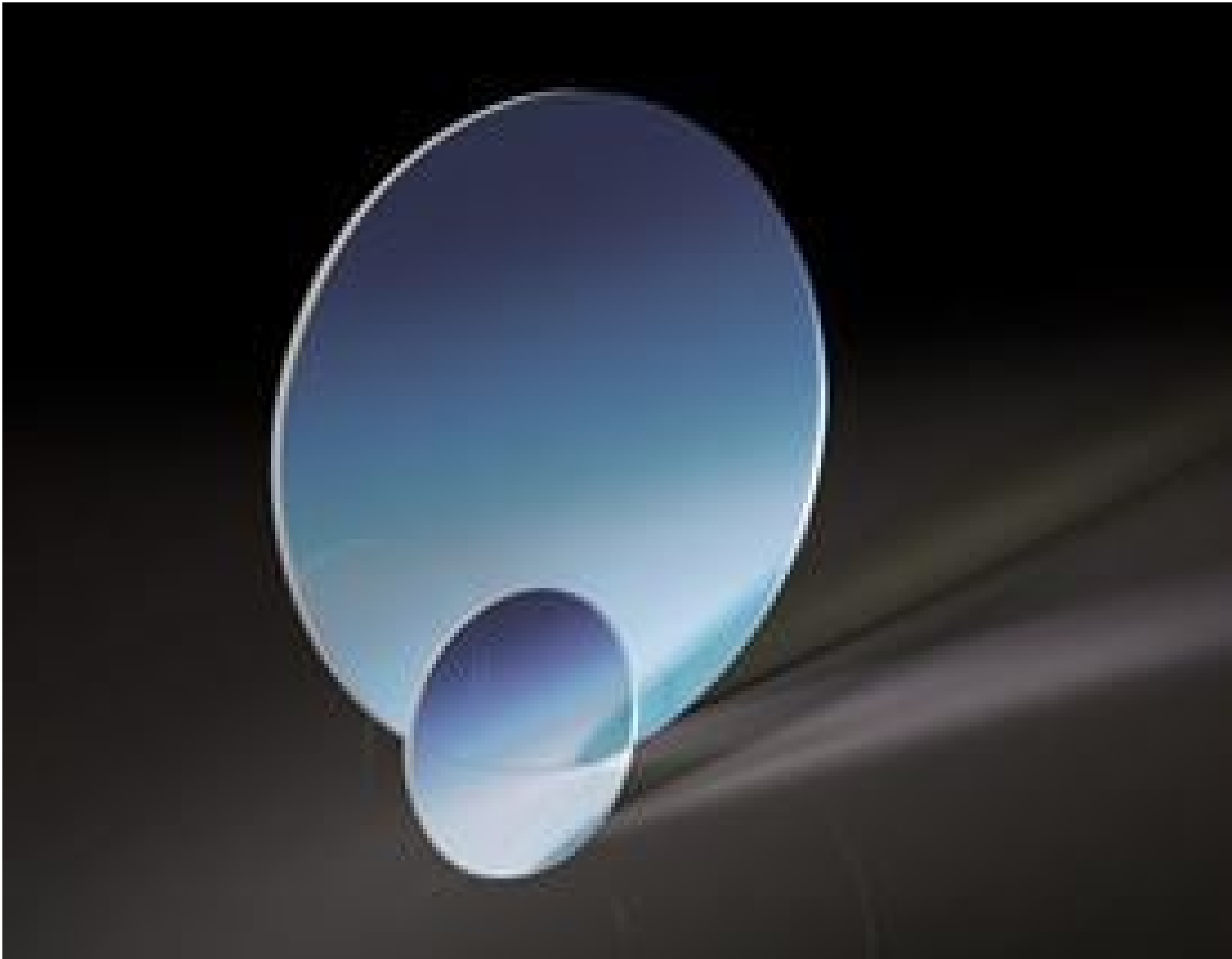

Laser Debris Shields

Stock **#37-668** ☐ In Stock

-

1

+

C\$262.50

ADD TO CART

Qty 1-5

C\$262.50

Qty 6+

C\$223.30

Volume Pricing

[Request Quote](#)

Get Product Downloads



Clear Aperture CA (mm):
113.9

Coating:
Uncoated

Diameter (mm):
134.00 ±0.1

Substrate: Fused Silica (Coming 7980)
Index of Refraction n_d: 1.458
Surface Quality: 20-10
Thickness (mm): 3.00 ±0.1
Type: Protective Window
Parallelism (arcmin): <30
Bevel: Break Edges
Clear Aperture (%): 85
Transmitted Wavefront, P-V: 2λ (70% of Dia.)
Abbe Number (v_d): 67.8
Wavelength Range (nm): 200 - 2200
Fused Silica Grade: 7980 0G
Edges: Fine Ground
Type of Window: Glass

Regulatory Compliance

RoHS 2015: Compliant
Reach 211: Compliant
Certificate of Conformance: View