


**TECHSPEC® 15mm Protected Silver Coated, N-BK7 Right Angle Mirror**

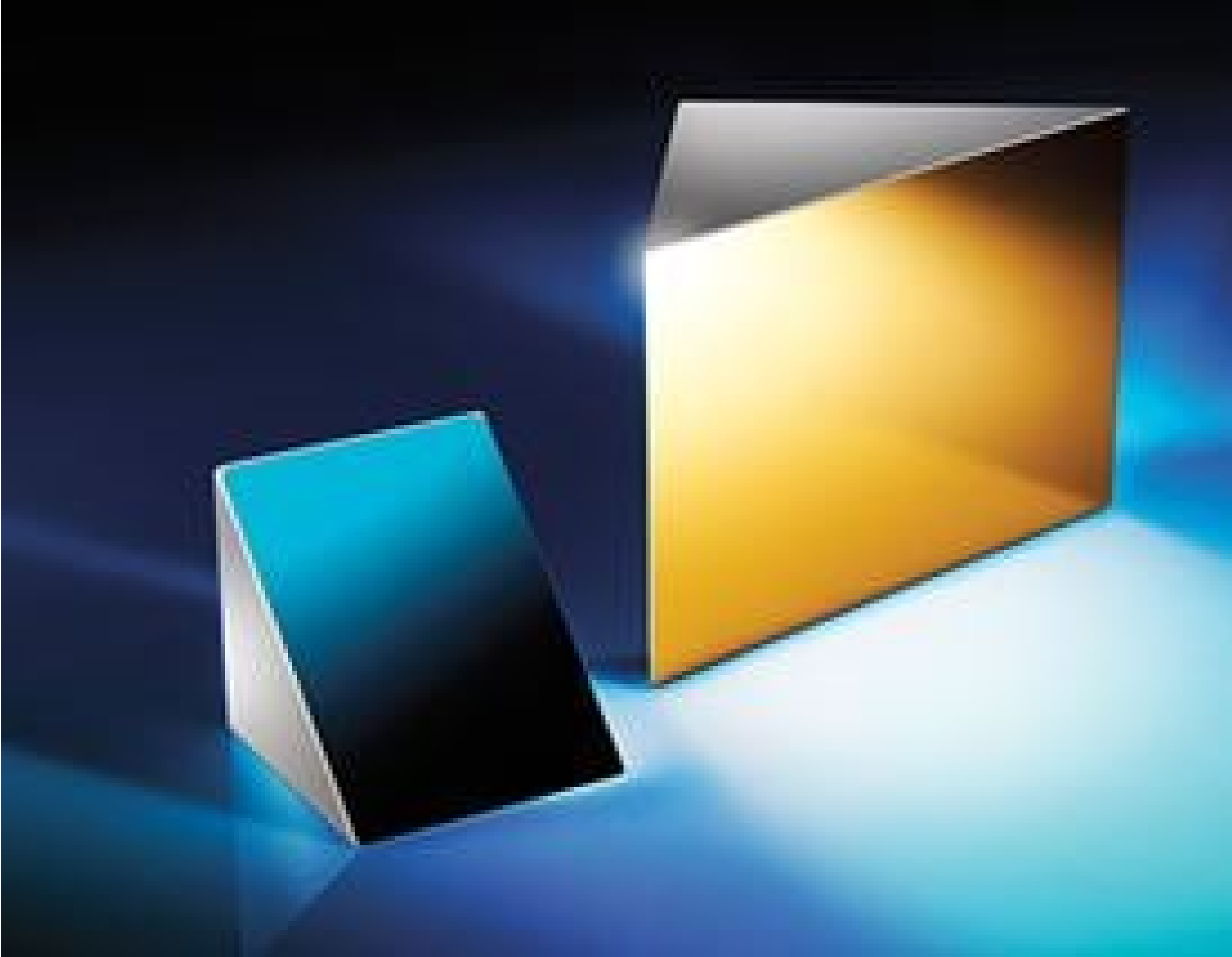

Stock **#89-628** ☐ In Stock

1  **C\$154.00**

ADD TO CART

|                               |
|-------------------------------|
| Qty 1-5                       |
| C\$154.00                     |
| Qty 6+                        |
| C\$123.20                     |
| Volume Pricing                |
| <a href="#">Request Quote</a> |

Get Product Downloads



Surface Flatness (P-V):  
λ/8

Substrate: ☐  
[N-BK7](#)

Surface Quality:  
40-20

Length of Legs (mm):

|                                                                                                                  |
|------------------------------------------------------------------------------------------------------------------|
| 15.00                                                                                                            |
| <b>Dimensional Tolerance (mm):</b><br>±0.1                                                                       |
| <b>Coating Specification:</b><br>R <sub>avg</sub> >98% @ 450 - 2000nm<br>R <sub>avg</sub> >98% @ 2000 - 10,000nm |
| <b>Coating:</b><br>Protected Silver (450-10000nm)                                                                |
| <b>Coating Type:</b><br>Metal                                                                                    |
| <b>Angle Tolerance (arcmin):</b><br>±2                                                                           |
| <b>Bevel:</b><br>Protective bevel as needed                                                                      |
| <b>Clear Aperture CA (mm):</b><br>19.09 x 13.50                                                                  |
| <b>Length of Hypotenuse (mm):</b><br>21.20                                                                       |
| <b>Type:</b><br>Right Angle Mirror                                                                               |
| <b>Wavelength Range (µm):</b><br>0.45 - 10                                                                       |
| <b>Wavelength Range (nm):</b><br>450 - 10000                                                                     |
| <b>Damage Threshold, Reference:</b> <input type="checkbox"/><br>0.5 J/cm² @ 532nm & 1064nm, 10ns                 |

Regulatory Compliance

|                                                            |
|------------------------------------------------------------|
| <b>RoHS 2015:</b><br><a href="#">Compliant</a>             |
| <b>Certificate of Conformance:</b><br><a href="#">View</a> |
| <b>Reach 233:</b><br><a href="#">Compliant</a>             |

---