


TECHSPEC® 15mm VIS 0° Coated, BBAR Coated Right Angle Prism

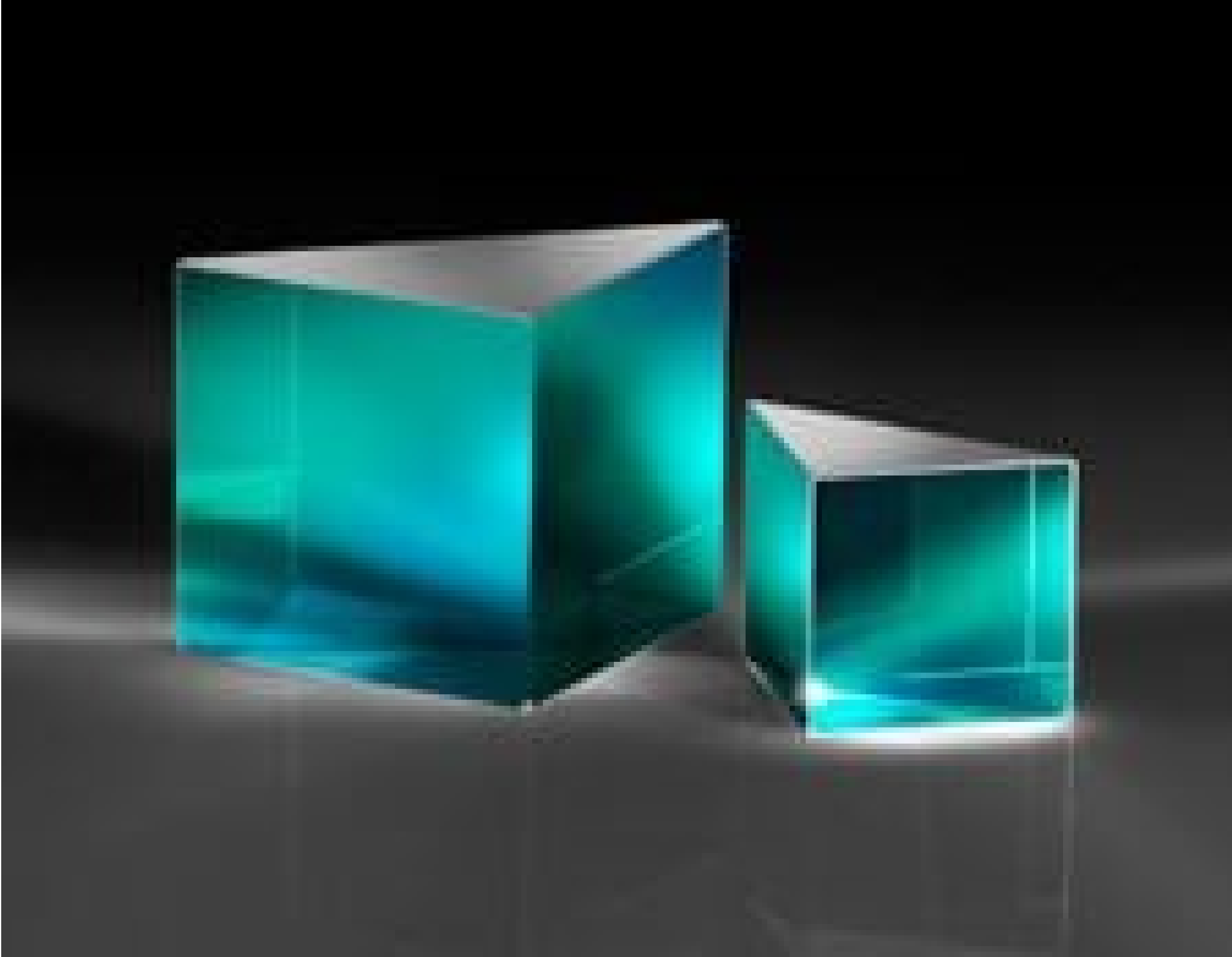

Stock **#84-508** ☐ In Stock

-

1

+

C\$155.40

ADD TO CART

Qty 1-5
C\$155.40
Qty 6+
C\$124.60
Volume Pricing
Request Quote

Get Product Downloads



Angle Tolerance (arcsec):
±15

Coating:
VIS 0° (425-675nm)

Substrate: ☐
[N-BK7](#)

Surface Quality:

40-20
Type: Right Angle Prism
Dimensional Tolerance (mm): +0.00/-0.10
Bevel: Protective bevel as needed
Clear Aperture (%): 90
Length of Hypotenuse (mm): 21.20
Length of Legs (mm): 15.00
Image Orientation: Left-Handed
Note: Coating on Entrance/Exit Faces
Coating Specification: R _{avg} ≤0.4% @ 425 - 675nm
Ray Deviation (°): 90
Wavelength Range (nm): 425 - 675
Surface Flatness (P-V): λ/8
Damage Threshold, Reference: ☐ Entrance/Exit Faces: 5 J/cm ² @ 532nm, 10ns

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View