


TECHSPEC® 18mm VIS 0° Coated Dove Prism

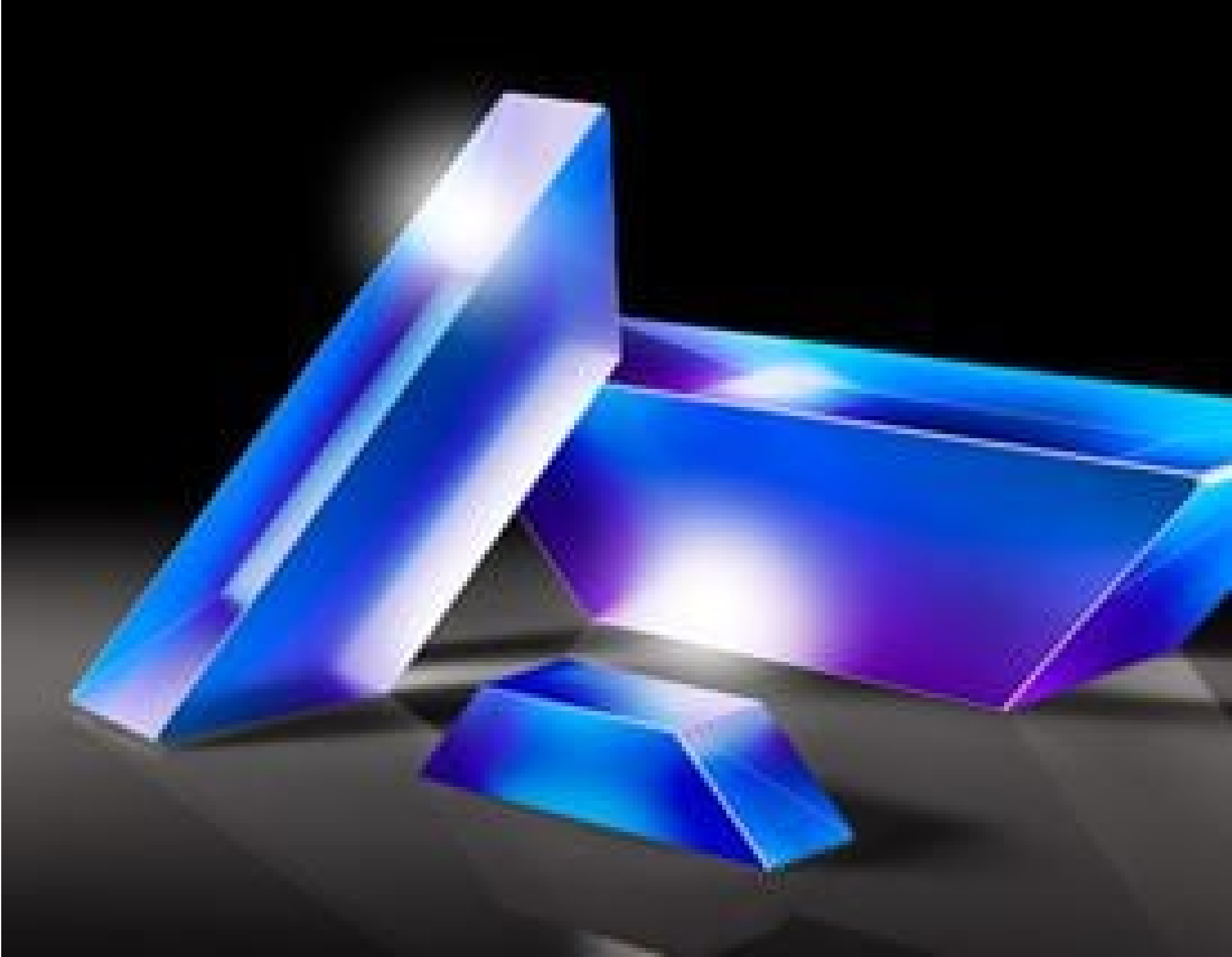

Stock **#49-427** ☐ In Stock

-

1

+

C\$217.00

ADD TO CART

Qty 1-5
C\$217.00
Qty 6+
C\$195.30
Volume Pricing
Request Quote

Get Product Downloads



Coating:
VIS 0° (425-675nm)

Substrate: ☐
[N-BK7](#)

Height (mm):
18.0

Length (mm):

74.60
Surface Quality: 60-40
Type: Dove Prism
Dimensional Tolerance (mm): ±0.13 Legs, ±0.25 Length
Angle Tolerance (arcmin): 2.00
Bevel: Protective bevel as needed
Image Orientation: Left-Handed
Coating Specification: R _{avg} ≤0.4% @ 425 - 675nm
Ray Deviation (°): 0
Wavelength Range (nm): 425 - 675
Surface Flatness (P-V): λ/8 (Entrance and Exit Faces)
Damage Threshold, Reference: ☐ 5 J/cm² @ 532nm, 10ns

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant