


TECHSPEC® 19.1mm Dia. Laser Mirror Substrate

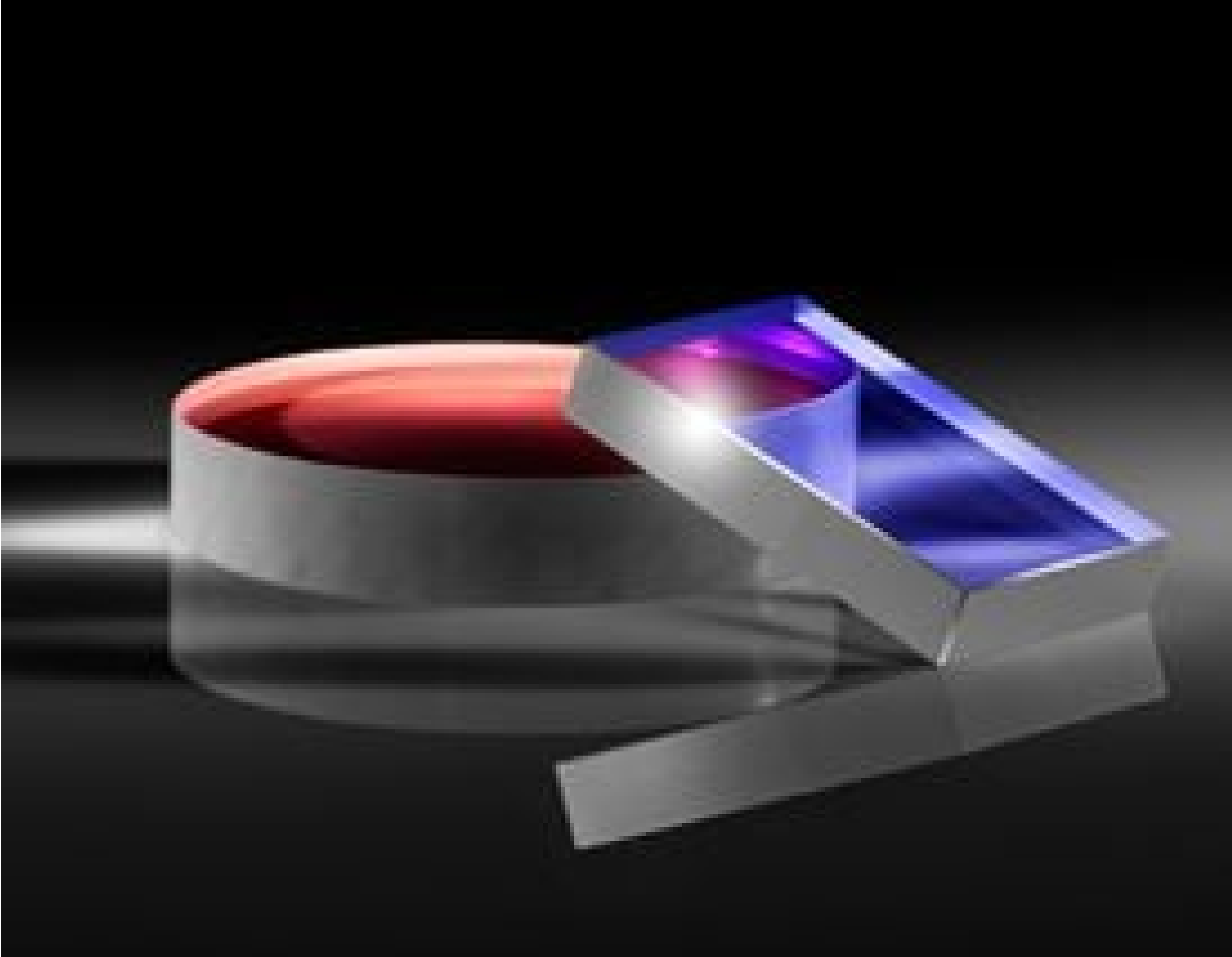

TECHSPEC® Laser Mirror Substrates

Stock **#38-000** ☐ In Stock

- 1 +

C\$124.60

ADD TO CART

Qty 1-10

C\$124.60

Qty 11+

C\$109.20

Volume Pricing

[Request Quote](#)

Get Product Downloads

Surface Quality:
10-5

Type:
Laser Mirror Substrate

Parallelism (arcmin):
<3

Clear Aperture (%):

Back Surface:
Commercial Polish

Surface Flatness (P-V):
λ/10

Coating:
Uncoated

Diameter (mm):
19.10 +0.00/-0.10

Thickness (mm):
6.35 ±0.20

Substrate:
[Fused Silica](#) (Corning 7980)

Regulatory Compliance

Reach 191:
[Compliant](#)

RoHS 2015:
[Compliant](#)

Certificate of Conformance:
[View](#)