


20mm Dia., 2mm Thick, Calcium Fluoride (CaF₂) Diffuser

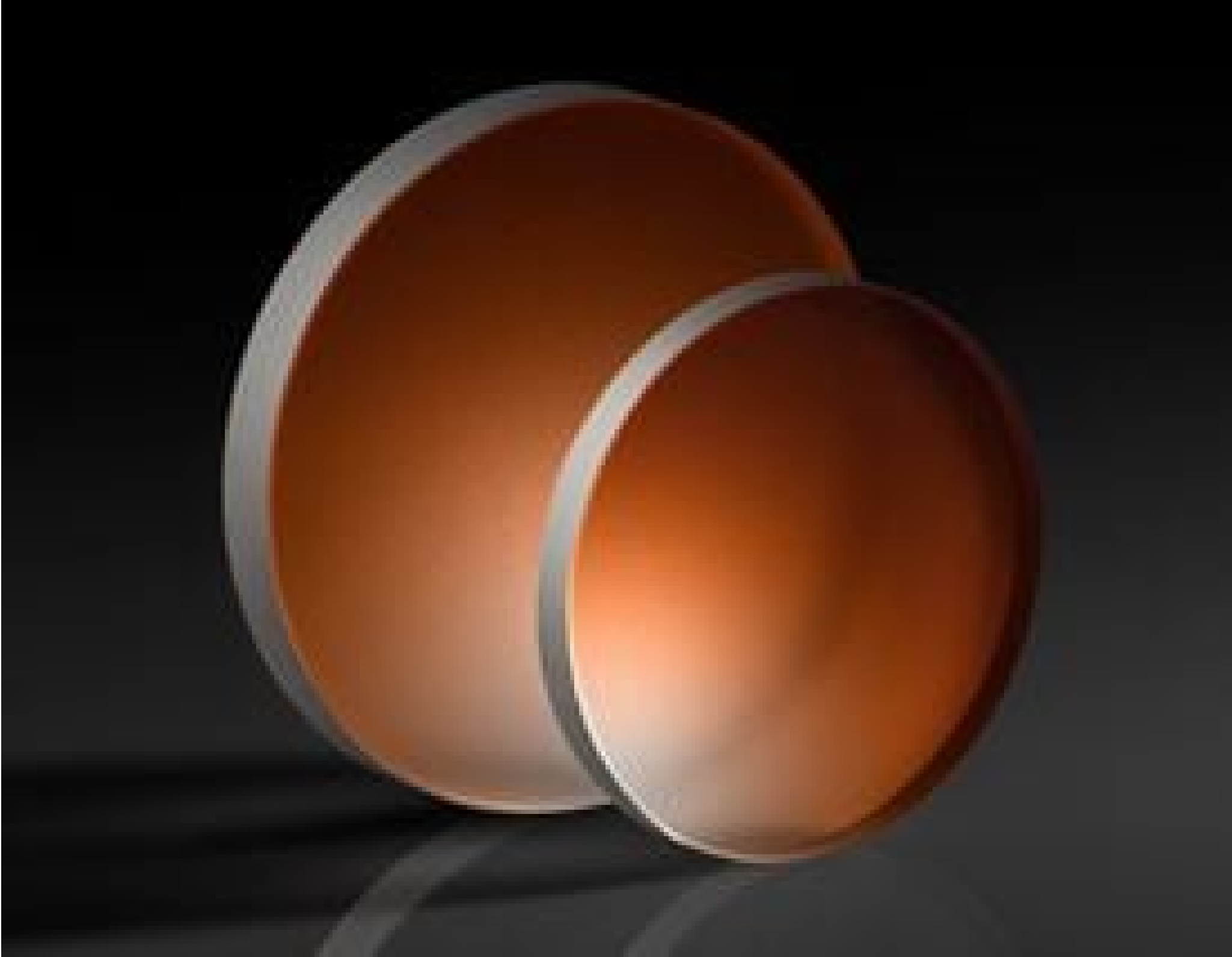

IR Calcium Fluoride (CaF₂) Diffusers

Stock **#19-733** ☐ In Stock

-

1

+

C\$210.00

ADD TO CART

Qty 1-10

C\$210.00

Qty 11+

C\$189.00

Volume Pricing

[Request Quote](#)

Get Product Downloads



Diameter (mm):
20.00 +0.00/-0.10

Coating:
Uncoated

Edges:
Fine Grind

Substrate: ☐ Calcium Fluoride (CaF ₂)
Thickness (mm): 2.00 ±0.10
Type: IR Diffuser
Wavelength Range (nm): 300 - 7000
Note: Fine Grind first surface with a roughness (Ra) of ☐ 0.75 microns

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View