


10-25nm, 50.8mm Dia, EUV/IR Dichroic Filter

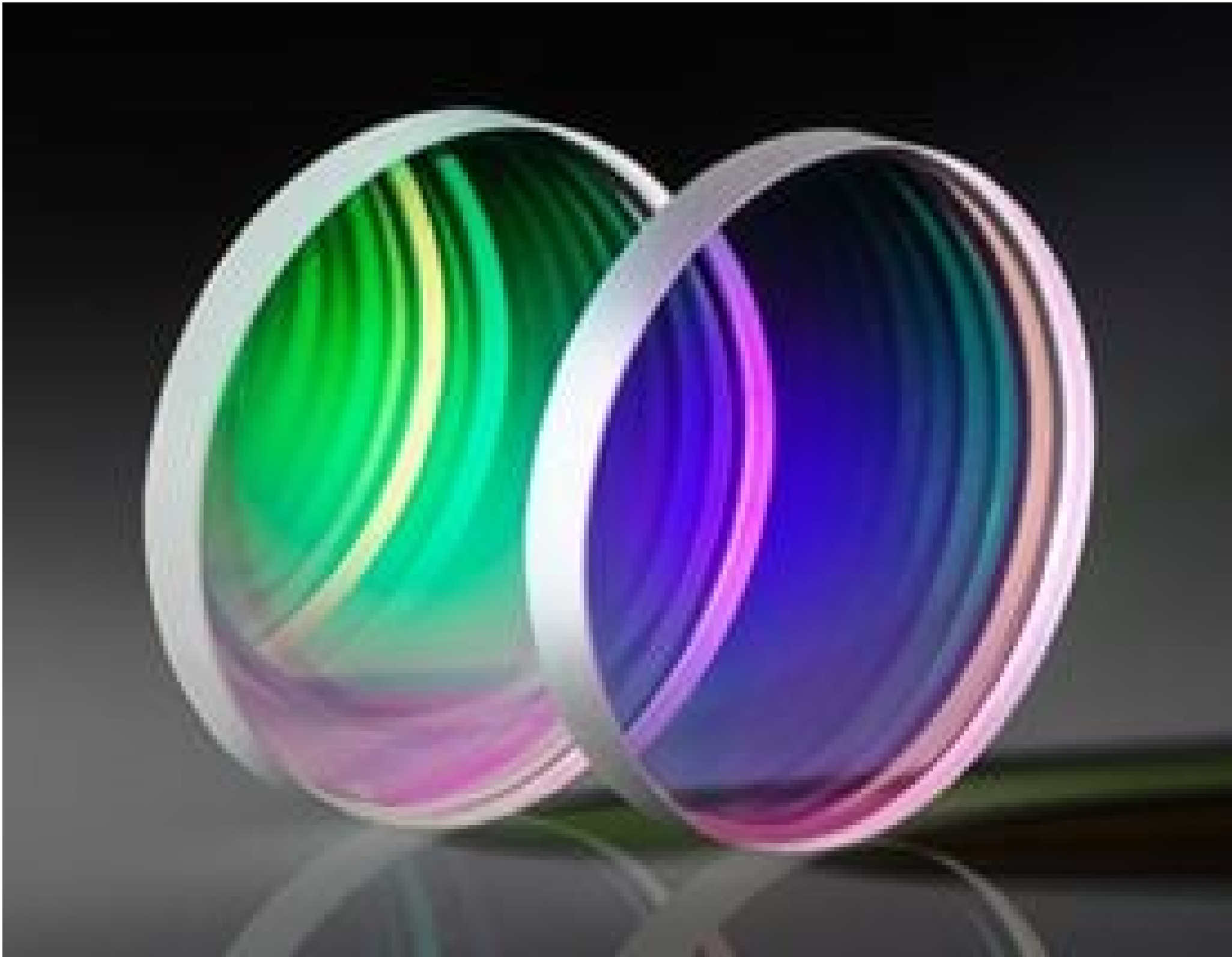

Extreme Ultraviolet (EUV) Dichroic Filters

Stock **#18-279** ☐ In Stock

1

C\$6,930.00

ADD TO CART

Qty 1+

C\$6,930.00

Volume Pricing

[Request Quote](#)

Get Product Downloads

Diameter (mm):
50.80

Angle of Incidence (°):
78

Substrate: ☐
[Fused Silica](#) (Corning 7980)

Coating:
Dielectric Multilayer AR

Reflection (%):
>35

Surface Quality:	20-10
Thickness (mm):	5.08 ±0.1
Type:	Dichroic Filter
Parallelism (arcmin):	<5
Dimensional Tolerance (mm):	+0.0/-0.2
Wavelength Range (nm):	10 - 25
Surface Figure, RMS:	<N10 @ 633nm

Regulatory Compliance

RoHS:	Compliant
Certificate of Conformance:	View