


TECHSPEC®

2.4mm Diameter x 3.0mm Length NIR I Coated, N-BK7 Drum Lens

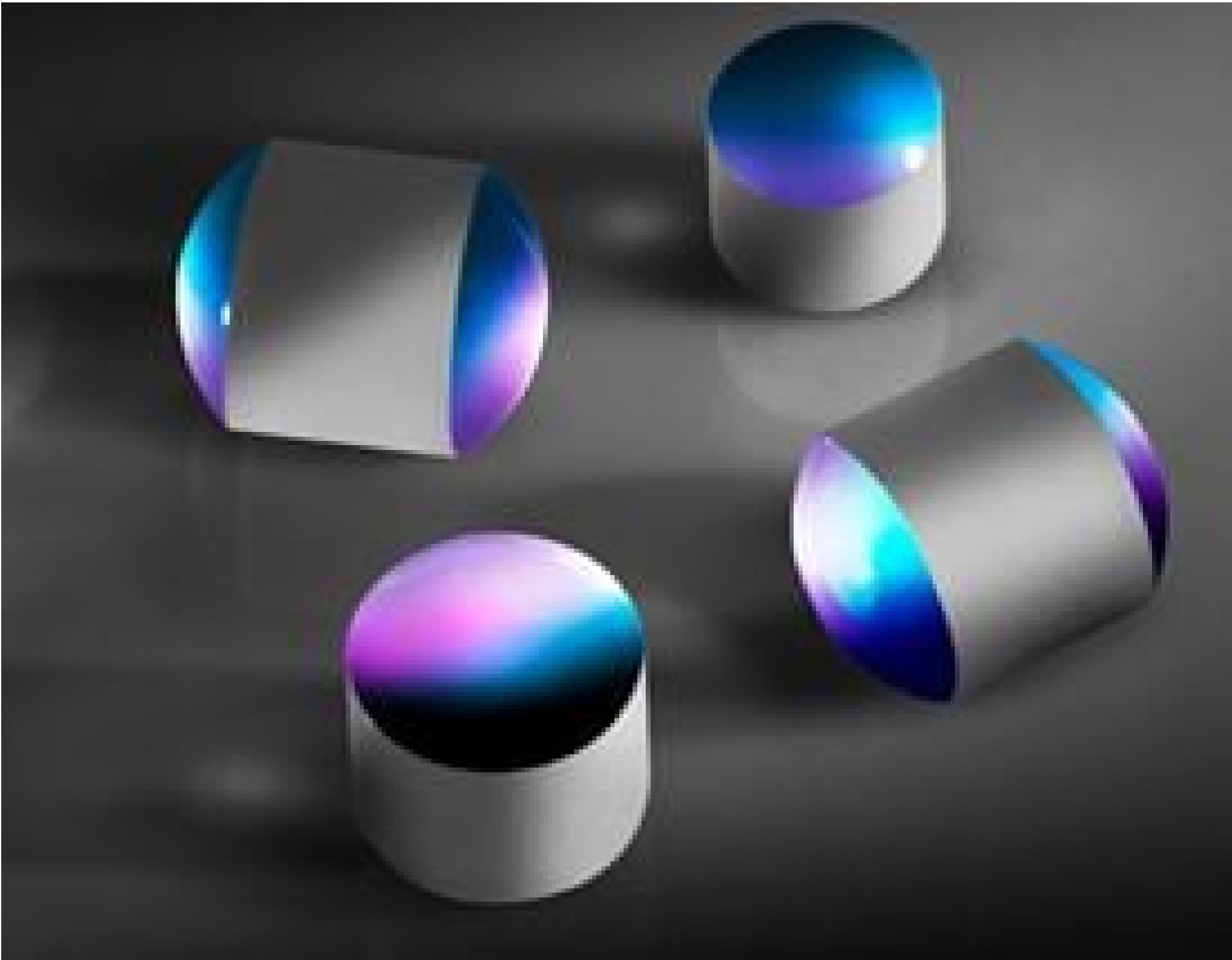

Stock **#45-837** [CONTACT US](#)

- 1 +

C\$91.70

ADD TO CART

Qty 1+

C\$91.70

Volume Pricing

[Request Quote](#)

Get Product Downloads



Diameter (mm):
2.40

Substrate: ☐
[N-BK7](#)

Coating:
NIR I (600-1050nm)

Type:
Drum Lens

Wavelength Range (nm):
600 - 1050

Coating Specification: R_{avg} ≤0.5% @ 600 - 1050nm
Index of Refraction n_d: 1.517
Length (mm): 3.00
Length Tolerance (μm): ±3
Radius R (mm): 1.50
Radius Tolerance (μm): +0/-1.5
Surface Quality: 40-20
Diameter Tolerance (μm): +0/-50

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant