


250μm, Optical Grade Plastic Optical Fiber Unjacketed

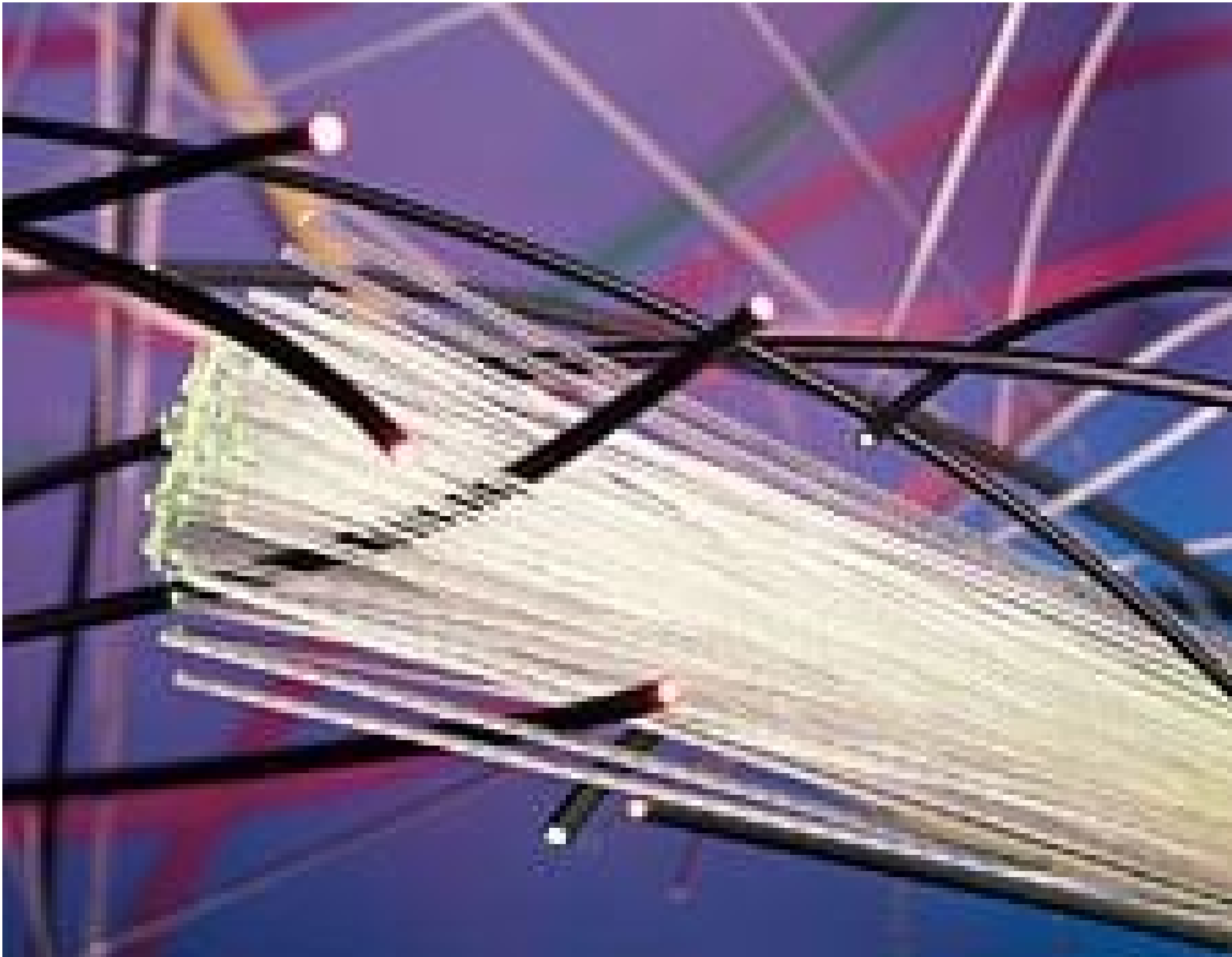

Stock **#02-531** ☐ In Stock

1

C\$1.26

ADD TO CART

Qty 1+

C\$1.26

Volume Pricing

[Request Quote](#)

Get Product Downloads

Acceptance Angle (°):
61.00

Minimum Bend Radius (mm):
6.25

Substrate: ☐
Acrylic

Attenuation (dB/m):
0.30

Numerical Aperture NA:
0.51

Number of Fibers: 1.00
Operating Temperature (°C): -55 to +70
Outer Diameter (mm): 0.25
Core Diameter (µm): 240.00
Fiber Diameter (µm): 250.00
Length (ft): Cut to Order, Minimum 10
Construction: Unjacketed
Index of Refraction n_d - Core: 1.492
Index of Refraction n_d - Cladding: 1.402
Attenuation (dB/km): 150 - 300 (@ 650nm)
Numerical Aperture (NA) Tolerance: ±0.03
Diameter Tolerance (%): ±6

Regulatory Compliance

RoHS 2015: Compliant
Reach 197: Compliant
Certificate of Conformance: View