


## 25.4mm Dia. 1064nm 45°, Low Cost Laser Line Mirror

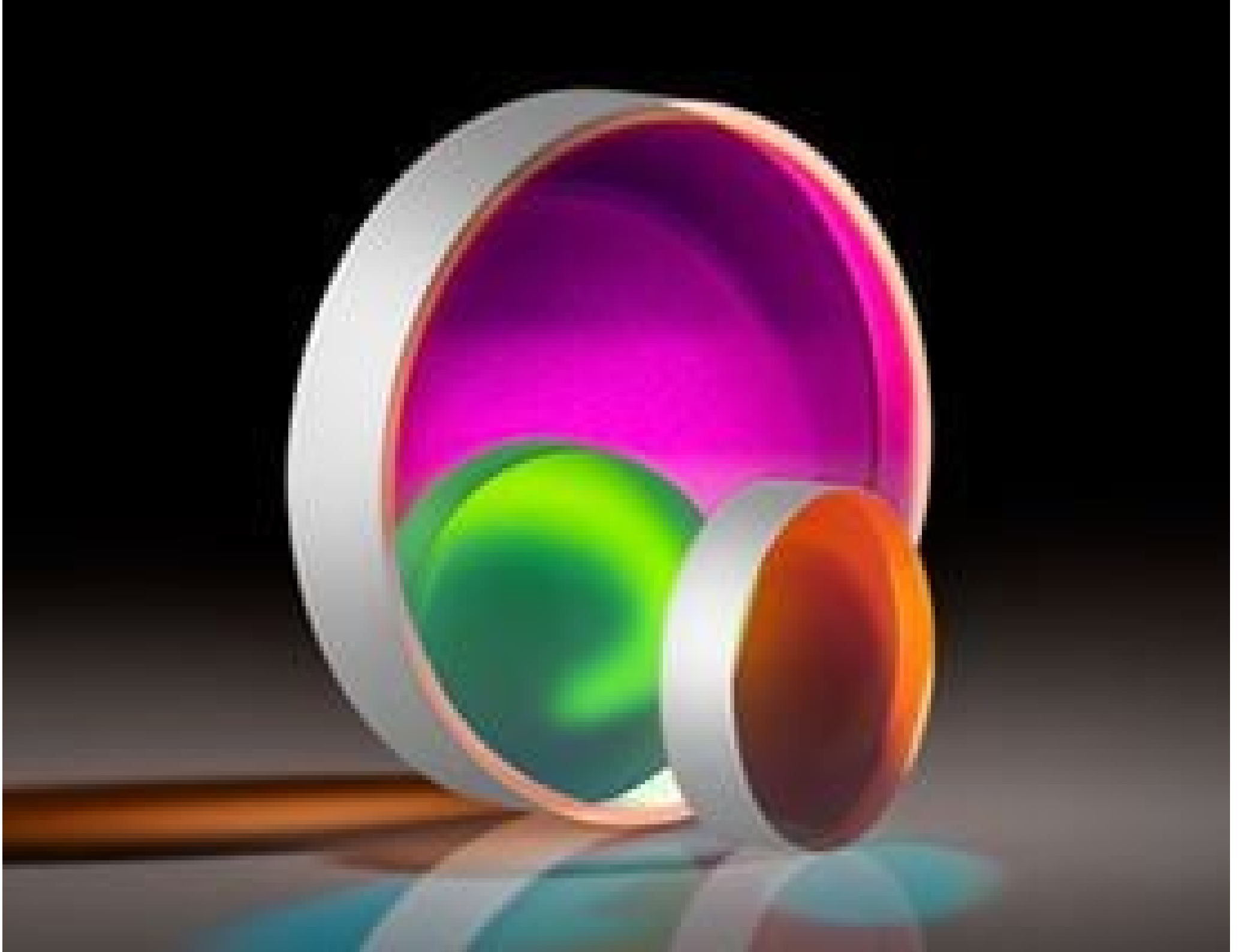

Stock #11-075  In Stock

1  **C\$165.20**

**ADD TO CART**

Qty 1-10

**C\$165.20**

Qty 11+

**C\$147.00**

Volume Pricing

[Request Quote](#)

Get Product Downloads



**Surface Quality:**  
20-10

**Type:**  
Laser Mirror

**Parallelism (arcmin):**  
<3

**Clear Aperture (%):**  
90

**Durability:**  
ML-C-675C

**Back Surface:**  
Commercial Polish

**Reflection at DWL (%):**  
99

**Coating Specification:**  
R<sub>abs</sub> >99% @ 1064nm

**Surface Flatness (P-V):**  
λ/10

**Coating Type:**  
Dielectric

**Coating:**  
Laser Mirror (1064nm)

**Design Wavelength DWL (nm):**  
1064

**Diameter (mm):**  
25.40 +0.0/-0.1

**Thickness (mm):**  
6.35 ±0.2

**Angle of Incidence (°):**  
45

**Substrate:**   
[N-BK7](#)

**Damage Threshold, By Design:**   
5 J/cm<sup>2</sup> @ 1064nm, 20ns, 20Hz

## Regulatory Compliance

**RoHS 2015:**  
[Compliant](#)

**Reach 223:**  
[Compliant](#)

**Certificate of Conformance:**  
[View](#)