


TECHSPEC®

25.4mm Dia. Silver, Precision Broadband Laser Mirror

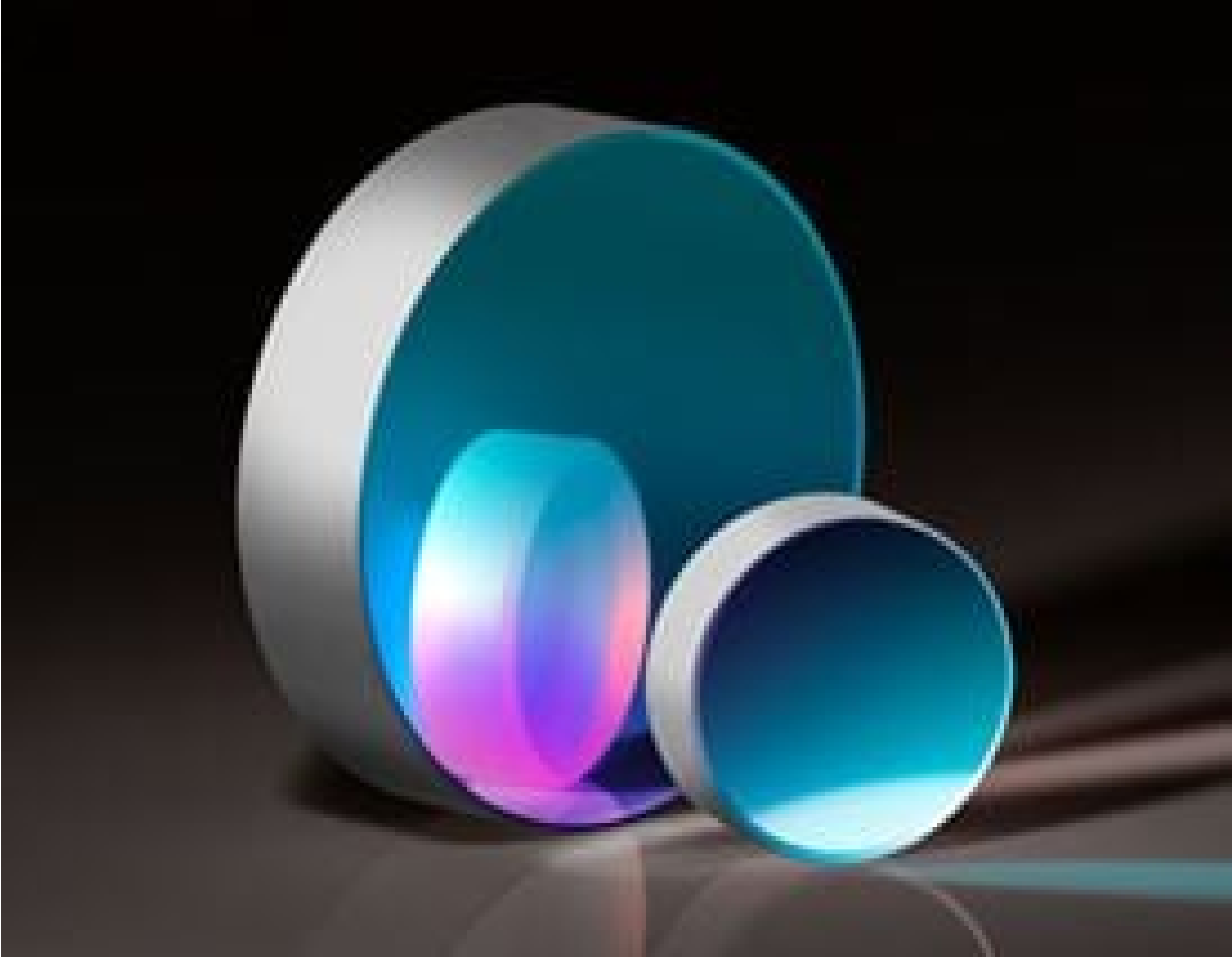

Stock **#45-758** ☐ In Stock

-

1

+

C\$218.40

ADD TO CART

Qty 1-5

C\$218.40

Qty 6+

C\$191.80

Volume Pricing

[Request Quote](#)

Get Product Downloads



Surface Quality:
20-10

Type:
Laser Mirror

Clear Aperture (%):
>80

Durability:

ML-M-13508-C
Back Surface: Ground
Coating Specification: R _{avg} >99% @ 0.45 - 12.0μm
Wavelength Range (nm): 450 - 12000
Surface Flatness (P-V): λ/10
Irregularity (P-V) @ 632.8nm: λ/20
Coating Type: Metal
Coating: Protected Silver (450-12000nm)
Diameter (mm): 25.40 +0.0/-0.2
Thickness (mm): 8.00 ±0.3
Angle of Incidence (°): 0-45
Substrate: ☐ BOROFLOAT®
Note: Optical Power: λ/10
Damage Threshold, By Design: ☐ 0.5 J/cm ² @ 10ns

Regulatory Compliance

RoHS 2015: Compliant
REACH 201: Compliant
Certificate of Conformance: View