


TECHSPEC®

25mm Aluminized, Schmidt Prism

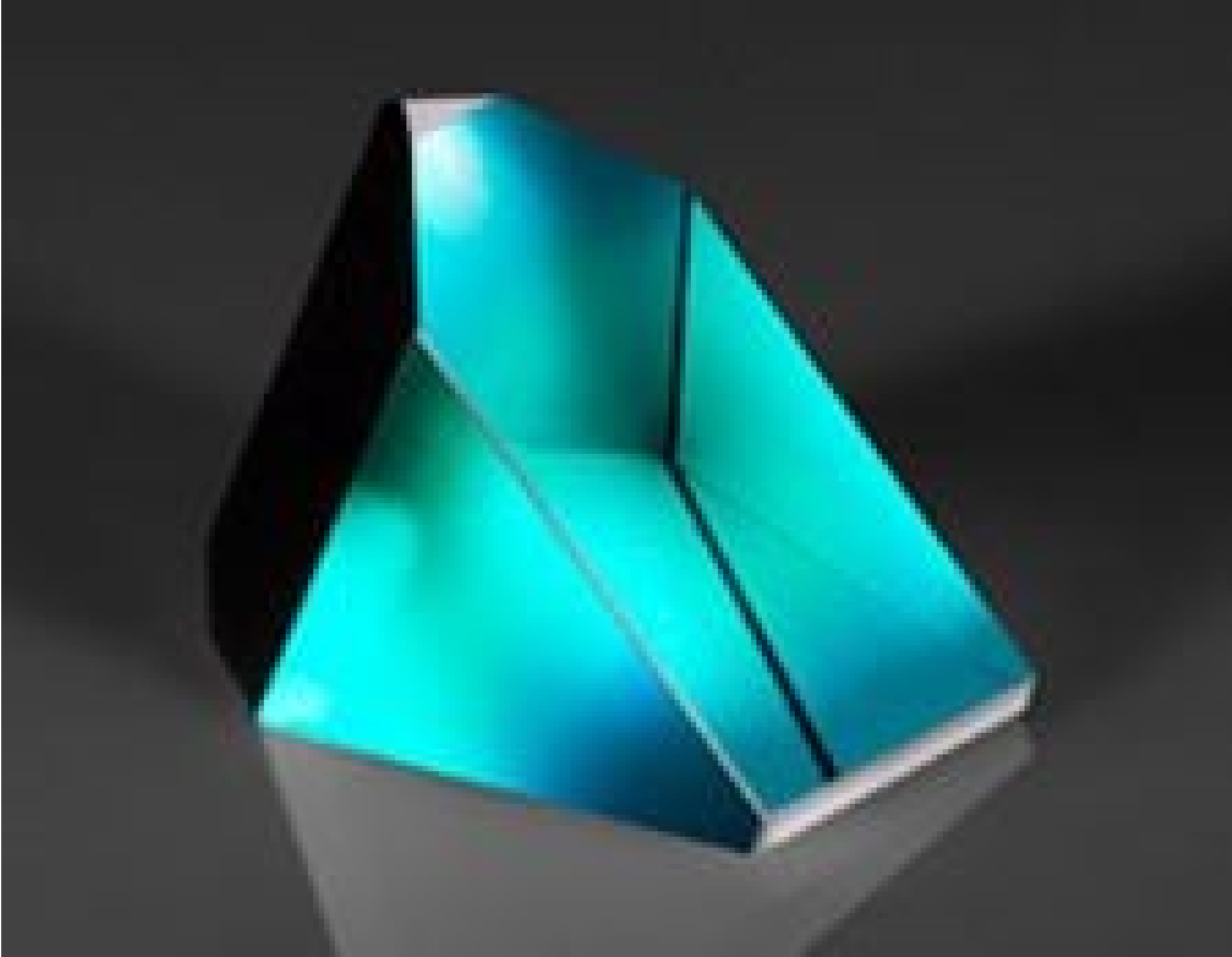

Stock #47-260 ☐ In Stock

-

1

+

C\$297.50

ADD TO CART

Qty 1-5
C\$297.50
Qty 6+
C\$238.00
Volume Pricing
Request Quote

Get Product Downloads



Angle Tolerance (arcsec):
5.00

Coating:
VIS 0° & Aluminized

Substrate: ☐
[N-BK7](#)

Height (mm):

41.3
Length (mm): 36.70
Surface Quality: 40-20
Type: Schmidt Prism
Dimensional Tolerance (mm): ±0.1
Bevel: Protective bevel as needed
Image Orientation: Right-Handed
Coating Specification: Entrance/Exit Faces: R _{avg} ≤0.4% @425 - 675nm Roof: R _{avg} >85% @400 - 700nm w/Black Overpaint
Ray Deviation (°): 45
Wavelength Range (nm): 400 - 700
Surface Flatness (P-V): λ/8
Width (mm): 25.00

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View