


25mm Dia. High Contrast UV Polarizer

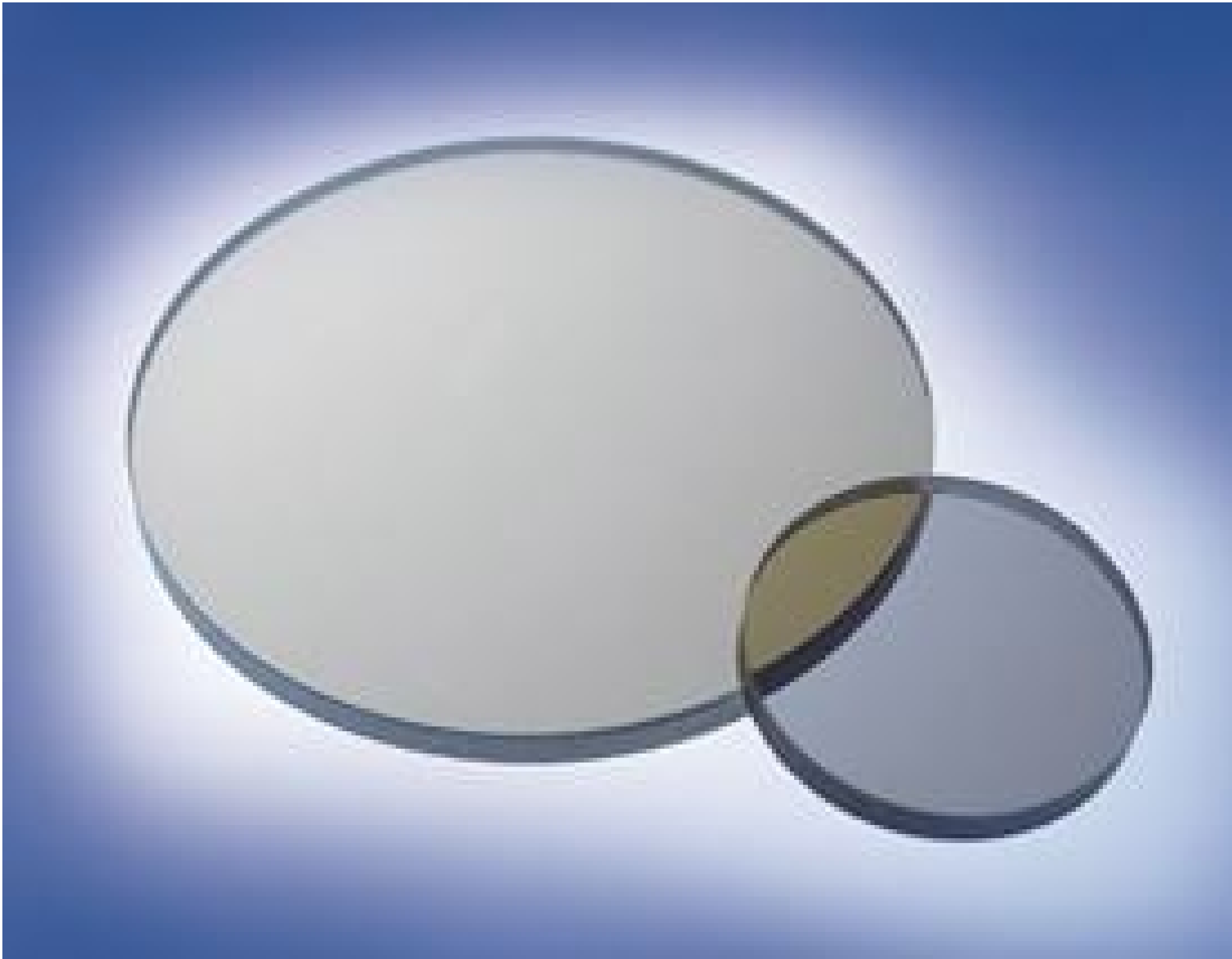

Stock **#36-651** ☐ In Stock

- 1 +

C\$1,254.40

ADD TO CART

Qty 1-9
C\$1,254.40
Qty 10+
C\$1,139.60
Volume Pricing
Request Quote

Get Product Downloads

Angle of Incidence (°):
±20

Clear Aperture CA (mm):
22.50

Diameter (mm):
25.00

Extinction Ratio:
100,000:1

Substrate: Soda Lime Float Glass
Operating Temperature (°C): -20 to +80
Thickness (mm): 2.00
Thickness Tolerance (mm): ±0.2
Transmission (%): >51
Type: Linear Polarizer
Dimensional Tolerance (mm): +0.0/-0.2
Construction: Nanoparticle
Clear Aperture (%): 90
Transmitted Wavefront, P-V: < λ/4
Beam Deviation (arcmin): <1
Polarization Axis Mark (%): ±2
Wavelength Range (nm): 365 - 395

Regulatory Compliance

RoHS 2015: Compliant
Reach 197: Compliant
Certificate of Conformance: View