


SCHOTT KG1, 25mm Dia., 3mm Thick, Colored Glass Heat Absorbing Shortpass Filter

See More by [SCHOTT Optical Components](#)

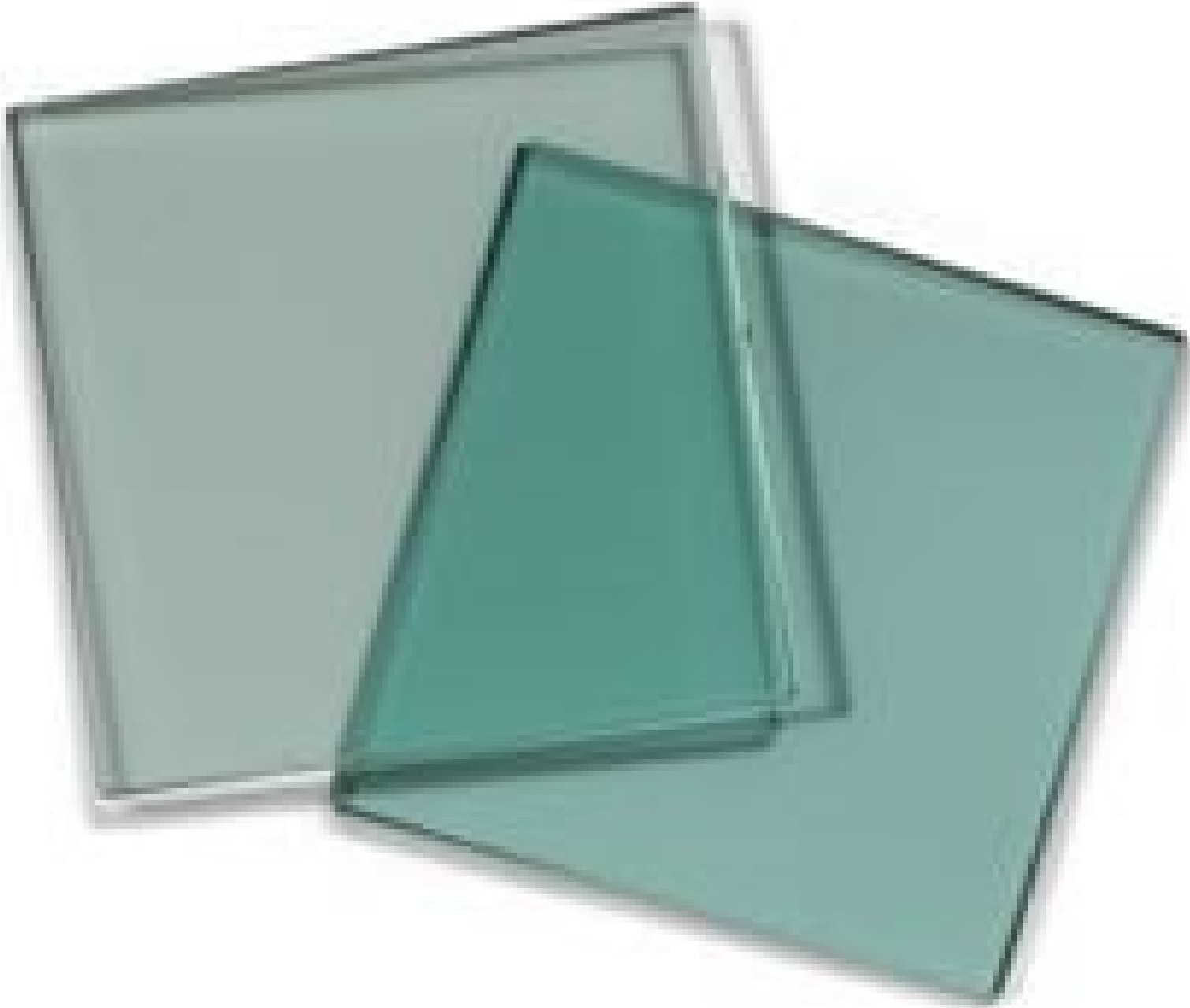

Stock **#45-646** ☐ In Stock

-

1

+

C\$49.00

ADD TO CART

Qty 1-10
C\$49.00
Qty 11+
C\$43.40
Volume Pricing
Request Quote

Get Product Downloads



Diameter (mm):
25.00

Density (g/cm³):
2.53

Glass/Filter Number:
[SCHOTT KG1](#)

Substrate: Heat Absorbing Glass
Operating Temperature (°C): 300 Maximum
Coating: Uncoated
Index of Refraction n_d: 1.51
Surface Quality: 60-40
Transformation Temperature (°C): 599
Thickness (mm): 3.00 ±0.38
Type: IR Cut-Off Filter
Dimensional Tolerance (mm): ±0.25
Reflection Factor P_d: 0.92
Wavelength Range (nm): 300 - 2700
Bevel: Protective as needed

Regulatory Compliance

Reach 191: Compliant
RoHS 2015: Compliant
Certificate of Conformance: View