


TECHSPEC® 25mm Dia., Uncoated, λ /10 Stemmed Mirror

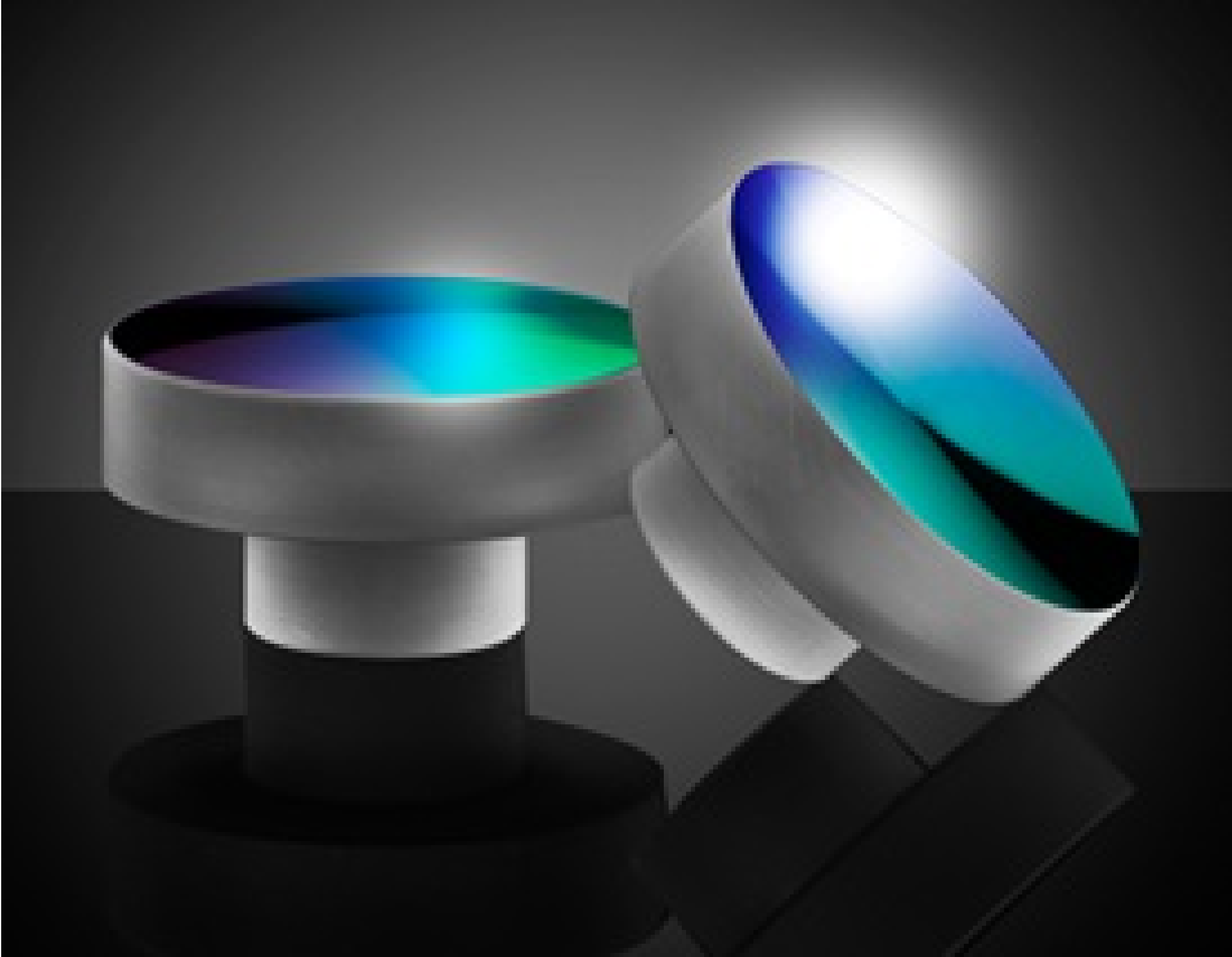

Stock #14-577 ☐ In Stock

1 **C\$166.60**

ADD TO CART

Qty 1-5

C\$166.60

Qty 6+

C\$133.00

Volume Pricing

[Request Quote](#)

Get Product Downloads



Coating:

Uncoated

Diameter (mm):

25.00 +0.00/-0.10

Substrate: Fused Silica (Coming 7980)
Surface Quality: 10-5
Thickness (mm): 13.00 ±0.20
Type: Stemmed Mirror
Clear Aperture (%): 90.00
Back Surface: Commercial Polish
Surface Flatness (P-V): λ/10
Coating Type: Uncoated
Edges: Ground, protective bevel as needed
Stem Diameter (mm): 12.50 +0.00/-0.10
Compatible Kinematic Mount: #58-853
Stem Length (mm): 6.50 ±0.20

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View