


25mm Diameter, Optical Cast Plastic Window

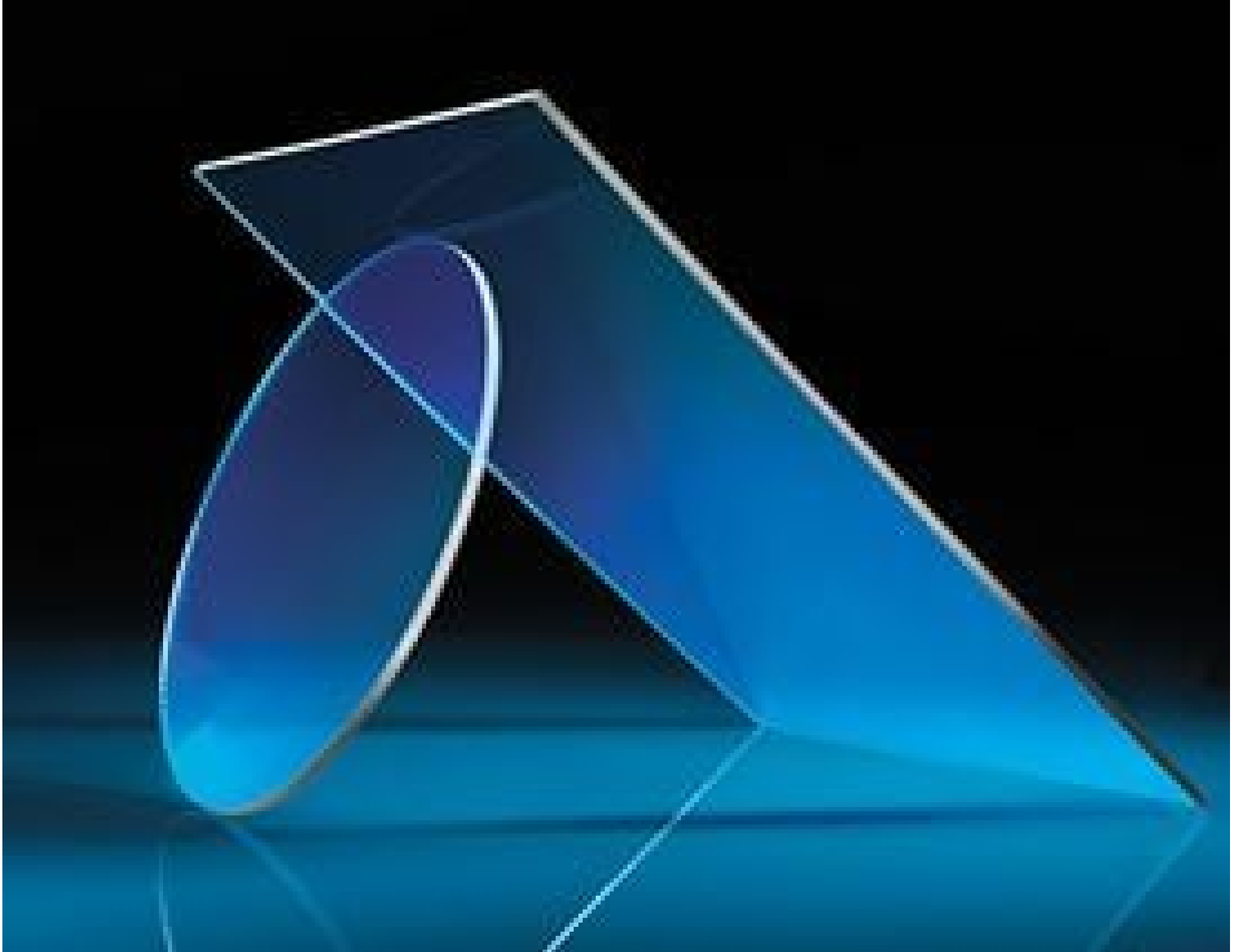

Stock #19-826 In Stock

⊖ 1 ⊕ **C\$30.80**

ADD TO CART

Qty 1-49

C\$30.80

Qty 50+

C\$24.50

Volume Pricing

[Request Quote](#)

Get Product Downloads



Abbe Number (v_d):
59.2

Diameter (mm):
25.00 ±0.3

Diameter (inches):
0.98

Thickness (mm):
1.50 ±0.15

Coating:
Uncoated

Density (g/cm³):
1.320

Index of Refraction n_d:
1.501

Operating Temperature (°C):
100 Continuous, 130 for 1 hour

Substrate:
Thermoset ADC (CR-39®)

Transmission (%):
>90 (typical)

Type:
Protective Window

Wavelength Range (nm):
400 - 1500

Regulatory Compliance

RoHS 2015:
[Compliant](#)

Certificate of Conformance:
[View](#)

Reach 240:
[Compliant](#)
