


TECHSPEC®

25mm Uncoated Dove Prism

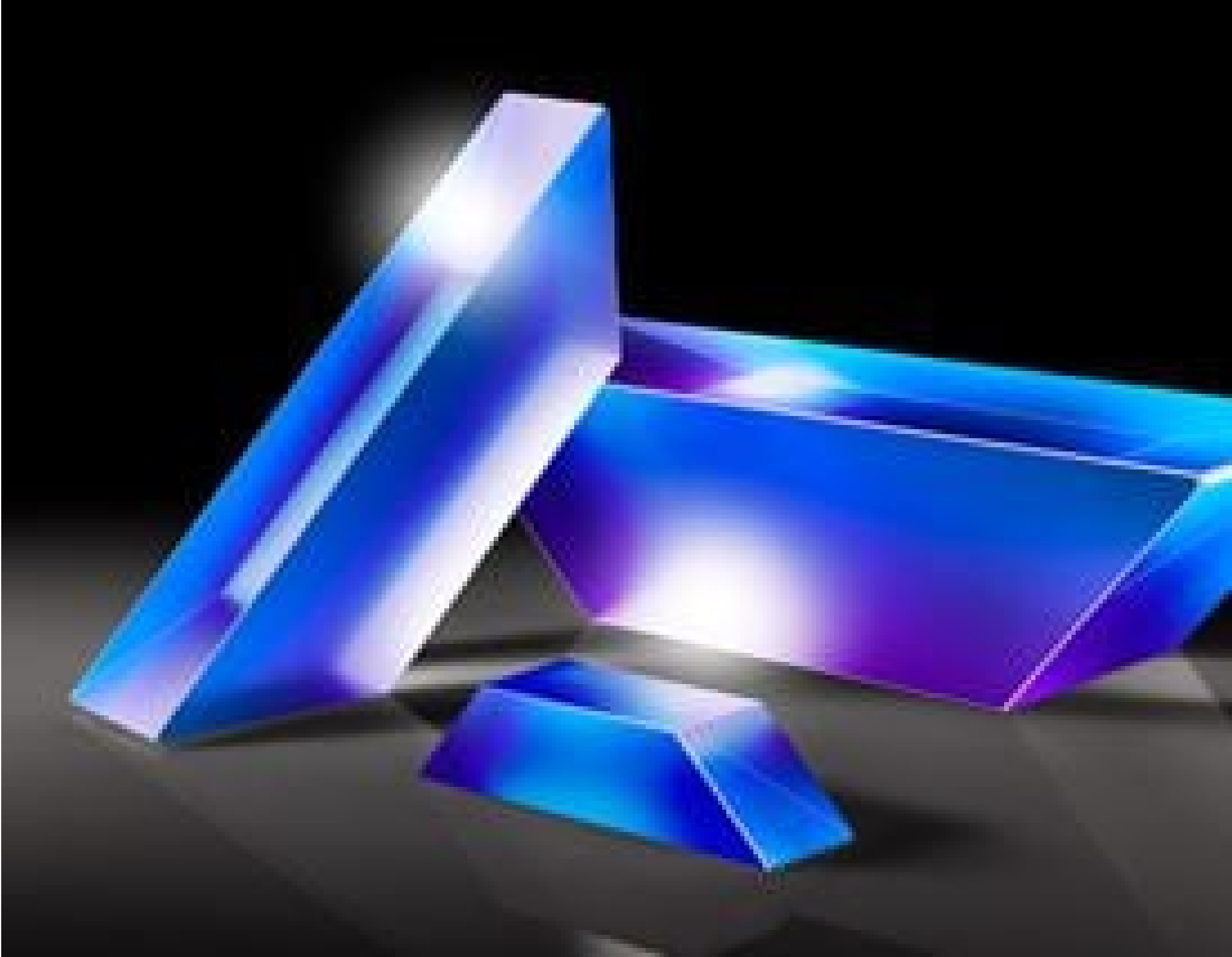

Stock **#45-403** ☐ In Stock

-

1

+

C\$267.40

ADD TO CART

Qty 1-5
C\$267.40
Qty 6+
C\$240.66
Volume Pricing
Request Quote

Get Product Downloads



Coating:

Uncoated

Substrate: ☐

[N-BK7](#)

Height (mm):

25.0

Length (mm):

103.18
Surface Quality: 60-40
Type: Dove Prism
Dimensional Tolerance (mm): ±0.13 Legs, ±0.25 Length
Angle Tolerance (arcmin): 2.00
Bevel: Protective bevel as needed
Image Orientation: Left-Handed
Ray Deviation (°): 0
Surface Flatness (P-V): λ/8 (Entrance and Exit Faces)

Regulatory Compliance

RoHS 2015: Compliant
Reach 219: Compliant
Certificate of Conformance: View