


26mm Diameter, English Hole Gauge, Contact Reticle

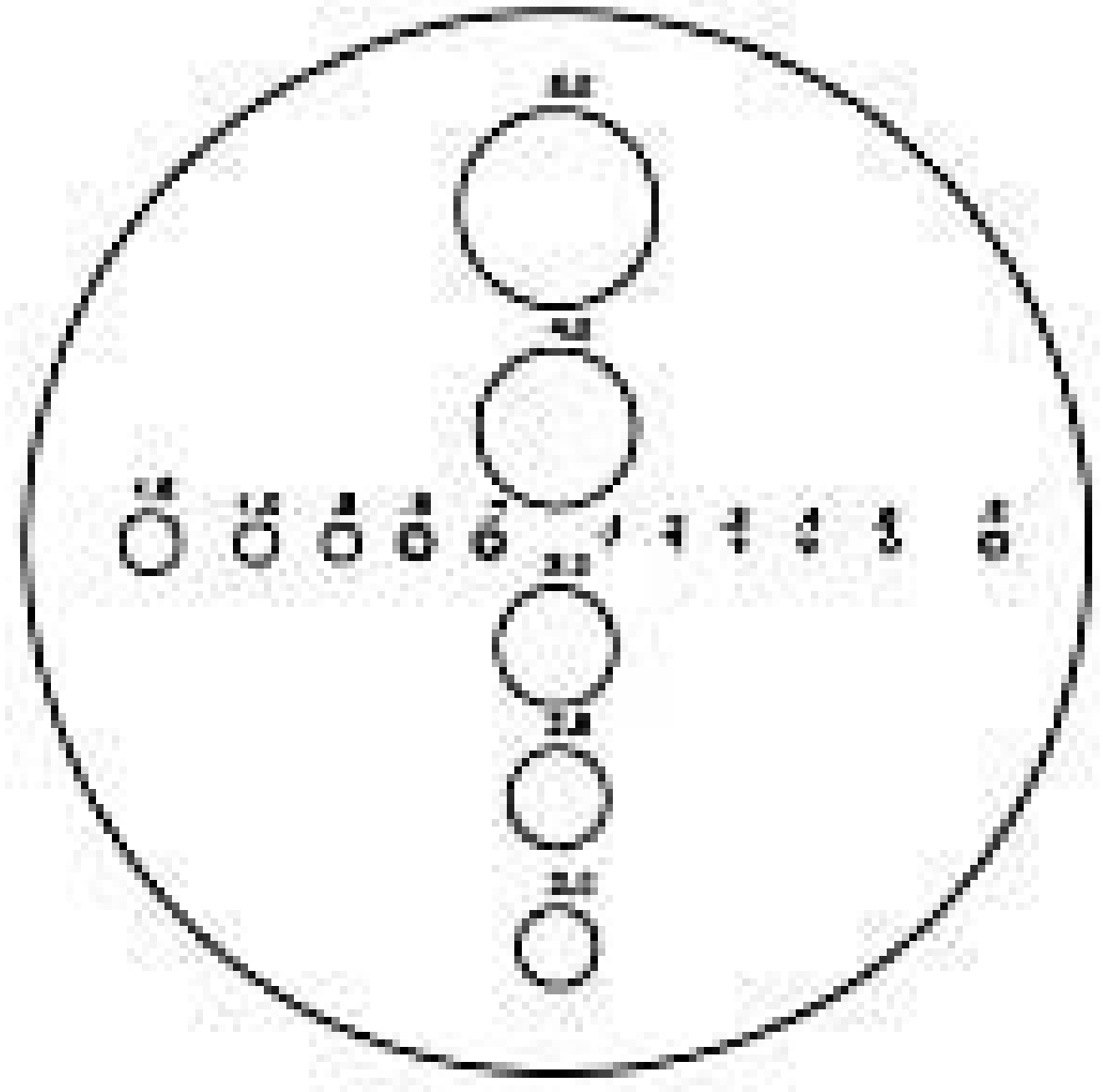

Hole Guage

Stock #64-853 ▢ In Stock



1



C\$93.80

ADD TO CART

Qty 1-4

C\$93.80

Qty 5+

C\$88.06

Volume Pricing

[Request Quote](#)

Get Product Downloads

Diameter (mm):

26.00 ±0.125

Angle Tolerance (arcsec):

±1

Line Thickness (µm):

25.00

Surface Quality:

60-40
Thickness (mm): 1.50
Thickness Tolerance (mm): ±0.10
Type: English Hole Gauge
Line to Line Accuracy (µm): ±2
Bevel: Protective bevel as needed
Parallelism (arcsec): <30
Centering (mm): 0.25
Line Thickness Tolerance (µm): ±13
Surface Flatness (P-V): 3 - 4λ

Regulatory Compliance

RoHS 2015: Compliant
Reach 209: Compliant
Certificate of Conformance: View