


27mm Diameter, English/Metric Line, Contact Reticle

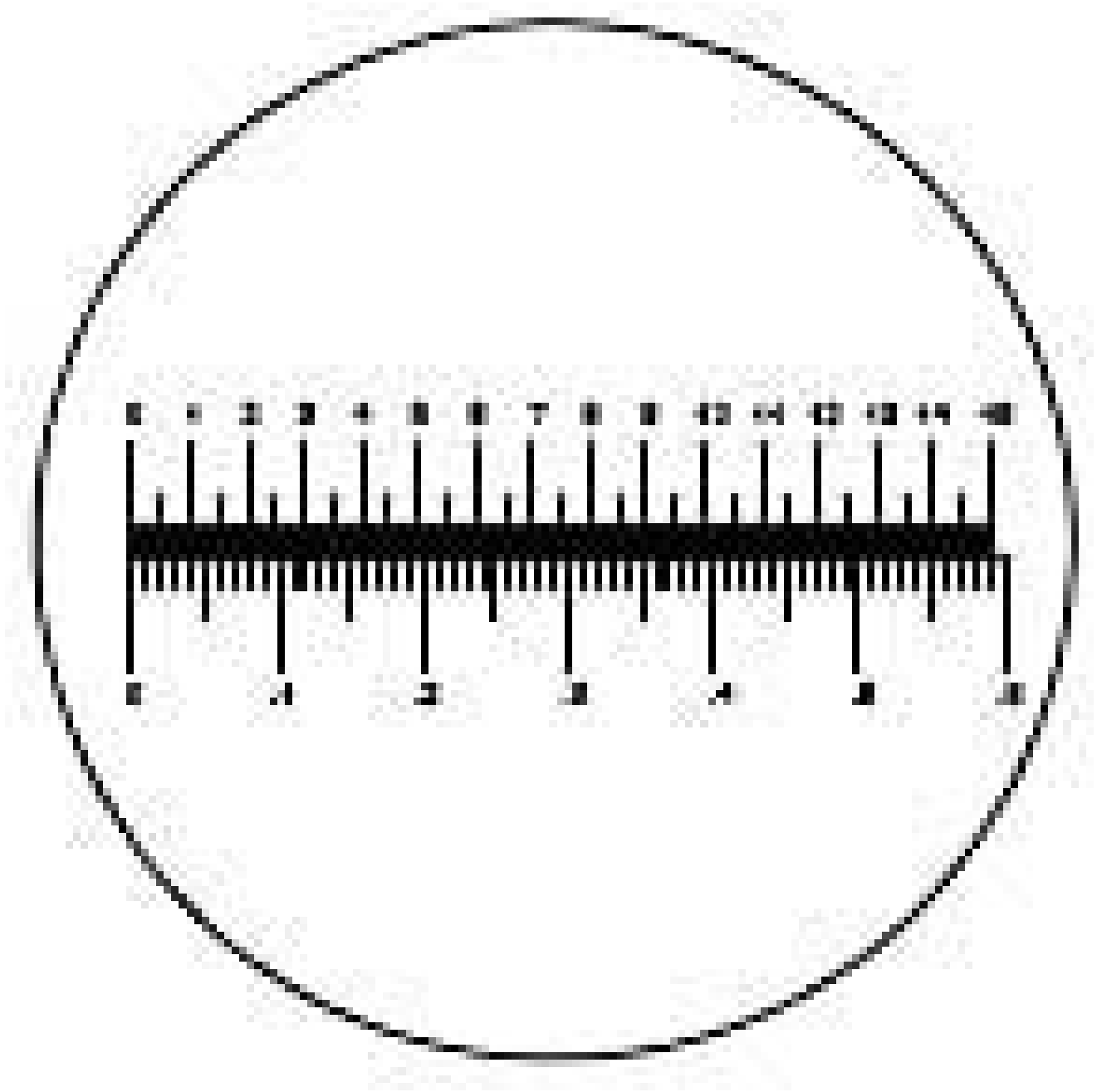

Inch-Metric Comparision

Stock **#39-458** □ **In Stock**



1



C\$93.80

ADD TO CART

Qty 1-4

C\$93.80

Qty 5+

C\$88.06

Volume Pricing

[Request Quote](#)

Get Product Downloads

Diameter (mm):

27.00 ±0.05

Angle Tolerance (arcsec):

±1

Line Thickness (µm):

25.00

Surface Quality:

60-40
Thickness (mm): 2.28
Thickness Tolerance (mm): ±0.127
Type: Inch-Metric Comparison
Line to Line Accuracy (µm): ±2
Parallelism (arcsec): <30
Centering (mm): 0.25
Line Thickness Tolerance (µm): ±13
Surface Flatness (P-V): 3 - 4λ

Regulatory Compliance

RoHS 2015: Compliant
Reach 211: Compliant
Certificate of Conformance: View