


TECHSPEC® 30 x 30mm Enhanced Aluminum, λ/20 Mirror

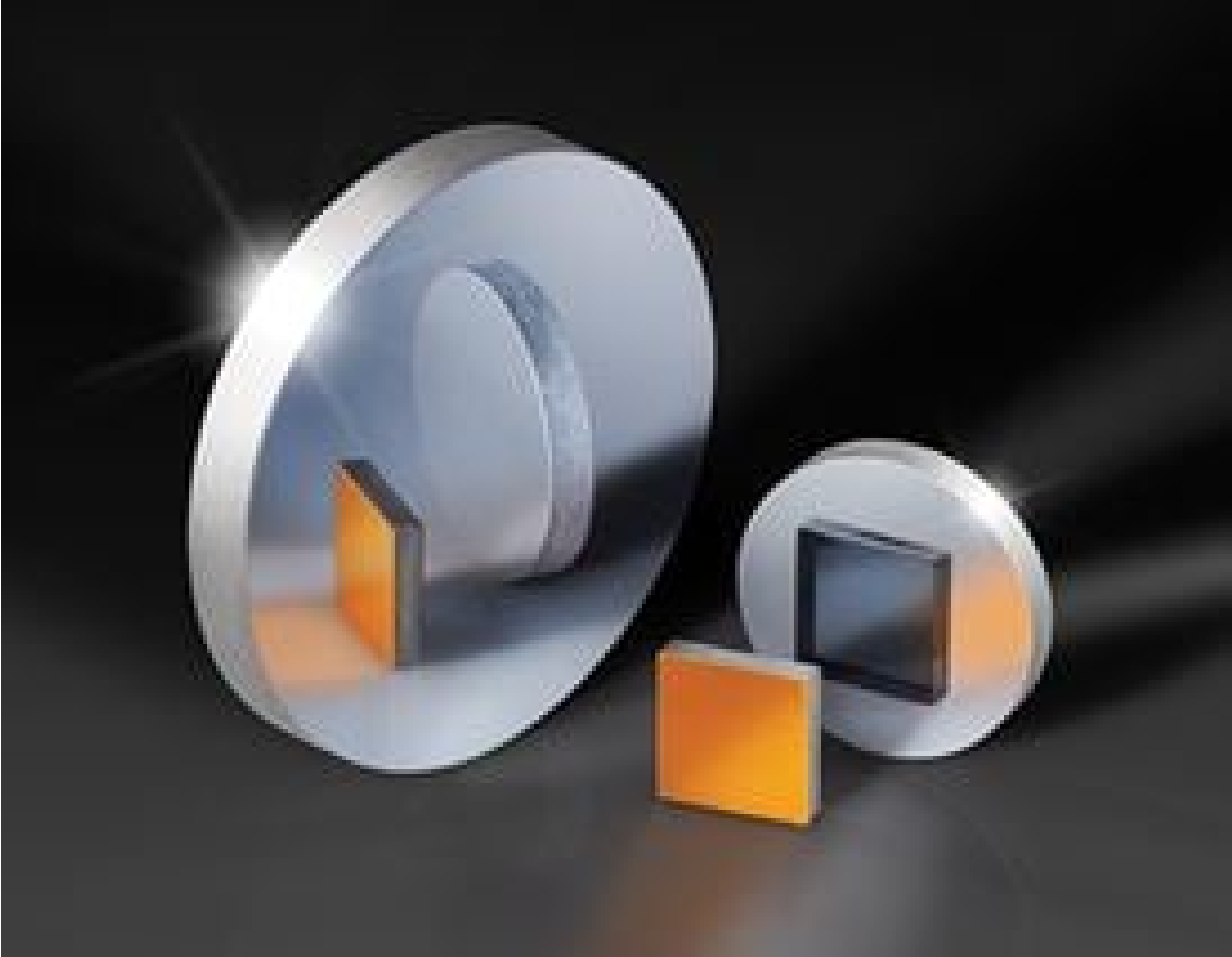

Stock **#34-363** ☐ In Stock

1 **C\$261.80**

ADD TO CART

Qty 1-5
C\$261.80
Qty 6+
C\$209.30
Volume Pricing
Request Quote

Get Product Downloads



Surface Flatness (P-V):
λ/20 (flatness pre-coating)

Substrate: ☐
[Fused Silica](#) (Corning 7980)

Back Surface:
Commercial Polish

Surface Quality:

20-10
Dimensions (mm): 30.0 x 30.0 +0.00/-0.20
Coating Specification: R _{avg} >95% @ 450 - 650nm
Coating: Enhanced Aluminum (450-650nm)
Coating Type: Metal
Clear Aperture (%): 90.00
Edges: Ground, protective bevel as needed
Parallelism (arcsec): 30.00
Thickness (mm): 5.00
Type: Flat Mirror
Wavelength Range (nm): 450 - 650
Length (mm): 30.00
Width (mm): 30.00

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant