
 


300 x 300mm, 1λ Retarder Film (WP560)

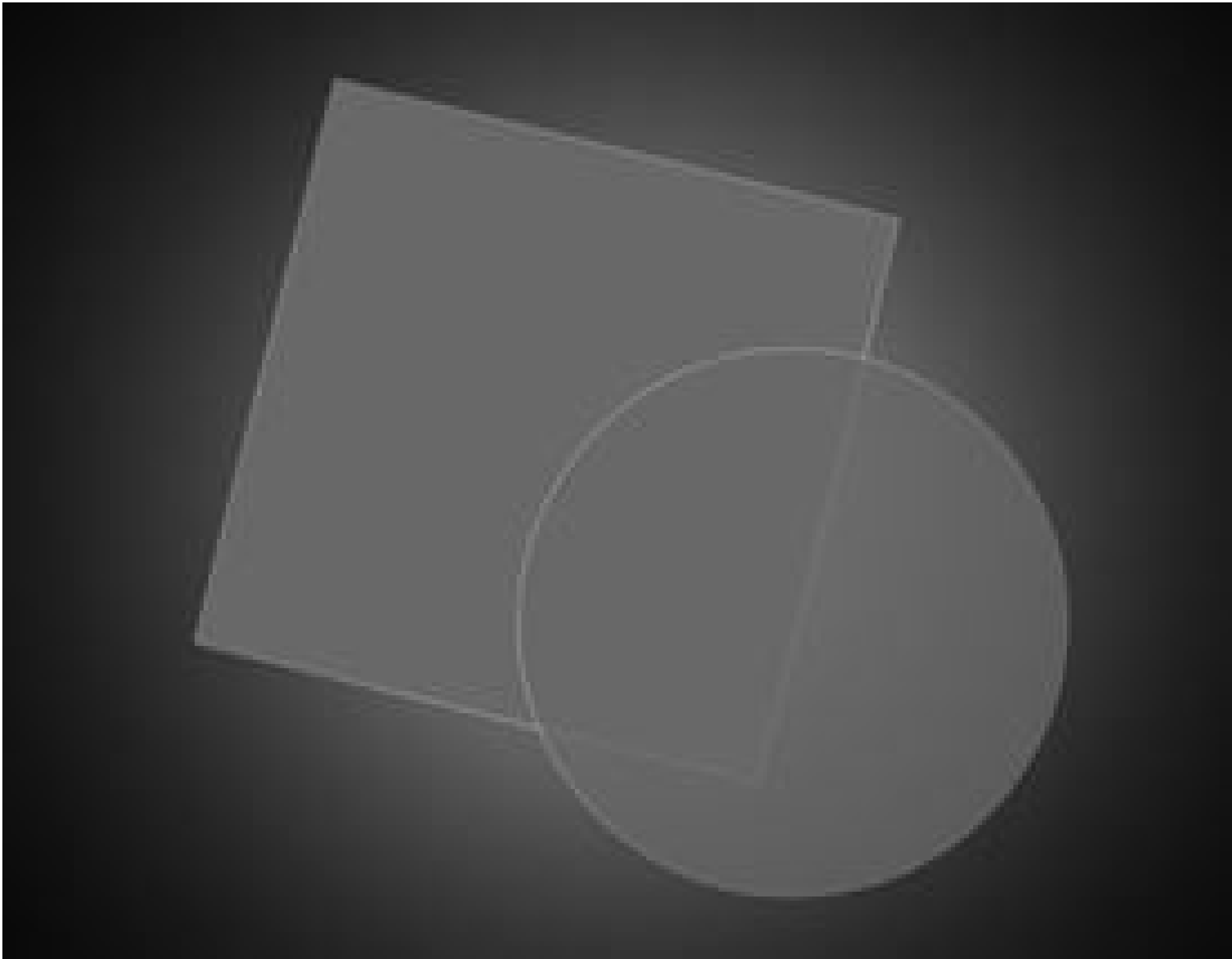

Retarder Film with protective film removed



Stock **#88-259** ☐ In Stock

-

1

+

C\$359.80

ADD TO CART

Qty 1-10
C\$359.80
Qty 11+
C\$333.20
Volume Pricing
Request Quote

Get Product Downloads

Design Wavelength DWL (nm):
560

Substrate: ☐
[Polymer Film WP560](#)

Length (mm):

300.00
Operating Temperature (°C): -20 to +50
Retardance: 1λ
Dimensions (mm): 300.0 x 300.0
Thickness (mm): 0.15 ±0.015
Transmission (%): >89
Type: Retarder Film
Dimensional Tolerance (mm): +0.0/-2.0
Construction: Polarizing Film
Phase Shift (°): 360.00
Haze (%): <1
Note: Fast axis is indicated by a black stripe on the protective film. This film should be removed before use.
Wavelength Range (nm): 400 - 700
Heat Resistance (°C x Hours): 80 x 1000
Width (mm): 300.00
Retardation (nm): 560 ±10

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant