


300mm, 2mm steps, Machine Vision Micrometer

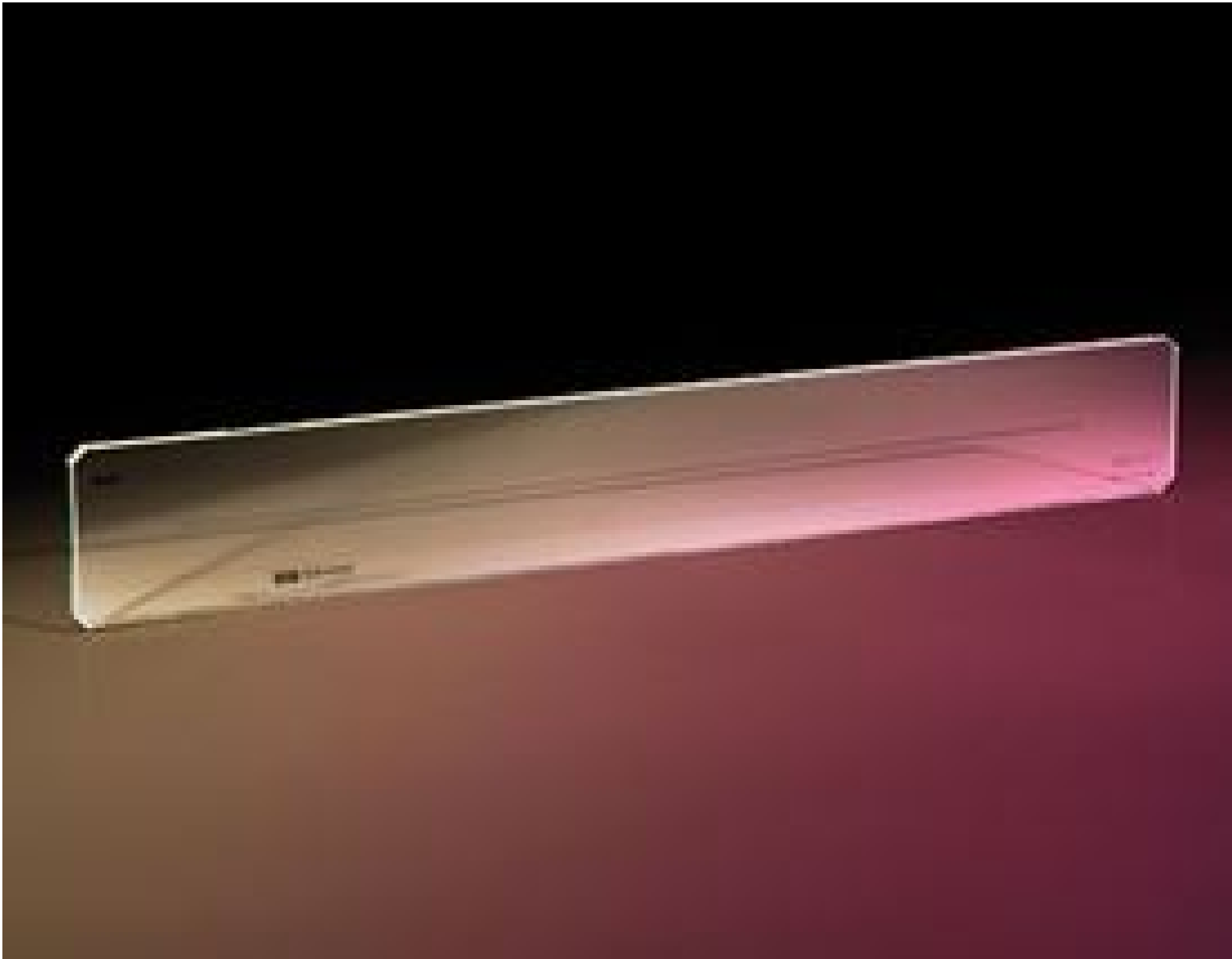

EO Machine Vision Stage Micrometer

Stock **#58-293** ☐ In Stock

- 1 +

C\$1,596.00

ADD TO CART

Qty 1-4
C\$1,596.00
Qty 5+
C\$1,517.46
Volume Pricing
Request Quote

Get Product Downloads

Coating:
First Surface Reflective Chromium, OD > 3.0
Reflectivity = 50% ±5% @ 550nm

Number of Divisions:
150.00

Substrate:
Float Glass

Line Width (mm): 0.125
Increments: 2mm
Scale Length (mm): 300.00
Dimensions (mm): 50.8 W x 338.1 L x 6.35 T
Surface Quality: 40-20 Over Pattern Area
Dimensional Tolerance (mm): ±1.27
Line Width Tolerance (mm): ±0.003
Accuracy (mm): ±0.003 up to 125mm; ±0.005 up to 300mm

Regulatory Compliance

RoHS 2015: Compliant
Reach 209: Compliant
Certificate of Conformance: View
