

TECHSPEC® 30mm, 40mm Radius, English Goniometer



30mm, 40mm Radius, English Goniometer

Stock **#66-520** **1 In Stock**

⊖ 1 ⊕ C\$574⁰⁰

ADD TO CART

Volume Pricing	
Qty 1-2	C\$574.00 each
Qty 3+	C\$500.78 each
Need More?	Request Quote

Product Downloads

General

Type:
English




Resolution (arcmin):
5

Physical & Mechanical Properties

Type of Movement:
Goniometer

Stage Size (mm):

30mm Goniometers

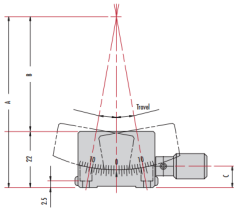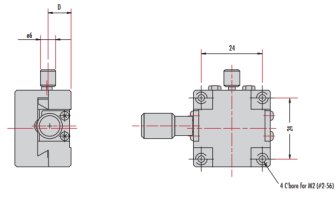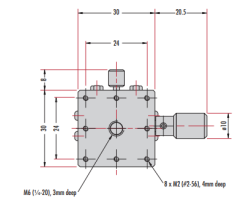

Ø (mm)	English Stage	Metric Stage	A (mm)	B (mm)	C (mm)	D (mm)
40	M6-520	M6-523	45	23	7.4	7
50	M6-521	M6-524	47	45	8.4	9
62	M6-522	M6-525	49	47	8.4	9