

**TECHSPEC® 30mm, Center Drive, Standard Top, 0.25" Travel, English Micrometer**



Stock #83-503 **20+ In Stock**

⊖ 1 ⊕ C\$613<sup>20</sup>

ADD TO CART

Volume Pricing	
Qty 1-2	C\$613.20 each
Qty 3+	C\$534.80 each
Need More?	<a href="#">Request Quote</a>

Product Downloads

**General**

English Type:

**Physical & Mechanical Properties**

Linear (X) Type of Movement:

Crossed Roller Bearing Guide System:

Center Drive Drive Orientation:



**30mm Standard-Top Stages - Center Drive**



**30mm Standard-Top Stages - Side Drive**



**40mm Standard-Top Stages - Center Drive**



**40mm Standard-Top Stages - Side Drive**




**70mm Standard-Top Stages - Center Drive**



**70mm Standard-Top Stages - Side Drive**



**125mm Standard-Top Stages - Center Drive**

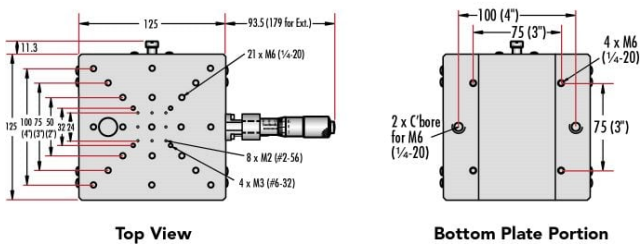

**125mm Standard-Top Stages - Side Drive**

