


TECHSPEC® 3.2mm Diameter x 4.0mm Length, N-LASFN9 Drum Lens

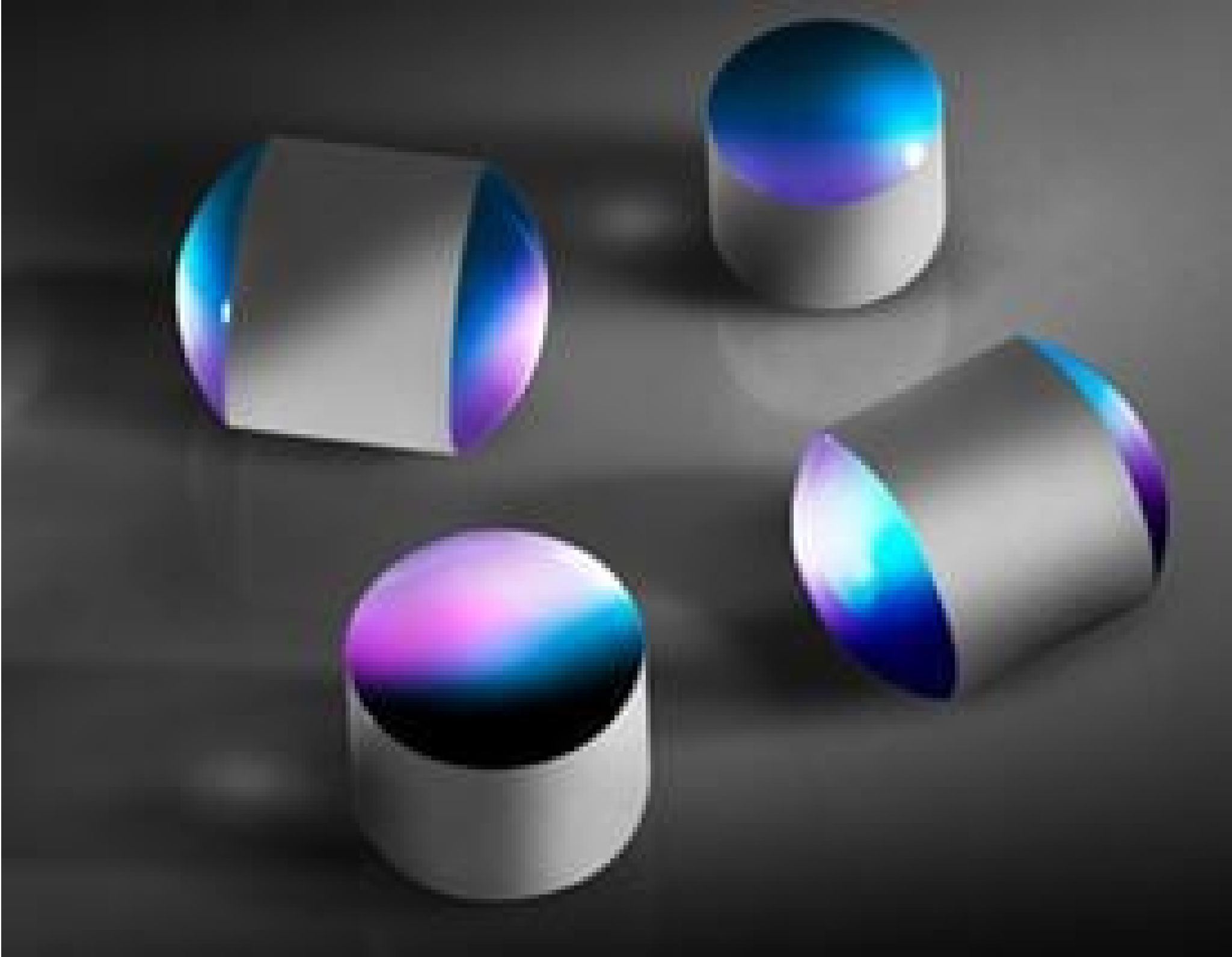

Stock **#45-665** CLEARANCE ☐ In Stock

-

1

+

C\$27.93

ADD TO CART

Qty 1+

C\$27.93

Volume Pricing

[Request Quote](#)

Get Product Downloads



Diameter (mm):
3.20

Substrate: ☐
[N-LASFN9](#)

Coating:
Uncoated

Type:
Drum Lens

Wavelength Range (nm):
380 - 2500

Index of Refraction n_d: 1.850
Length (mm): 4.00
Length Tolerance (μm): ± 3
Radius R (mm): 2.00
Radius Tolerance (μm): $+0/-1.5$
Surface Quality: 40-20
Diameter Tolerance (μm): $+0/-50$

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View