


355 & 532nm, 4-6mm Dia. Input Beam, Focal Flat Top Beam Shaper | Focal π Shaper_NUV_Q-5

See More by [AdlOptica](#)

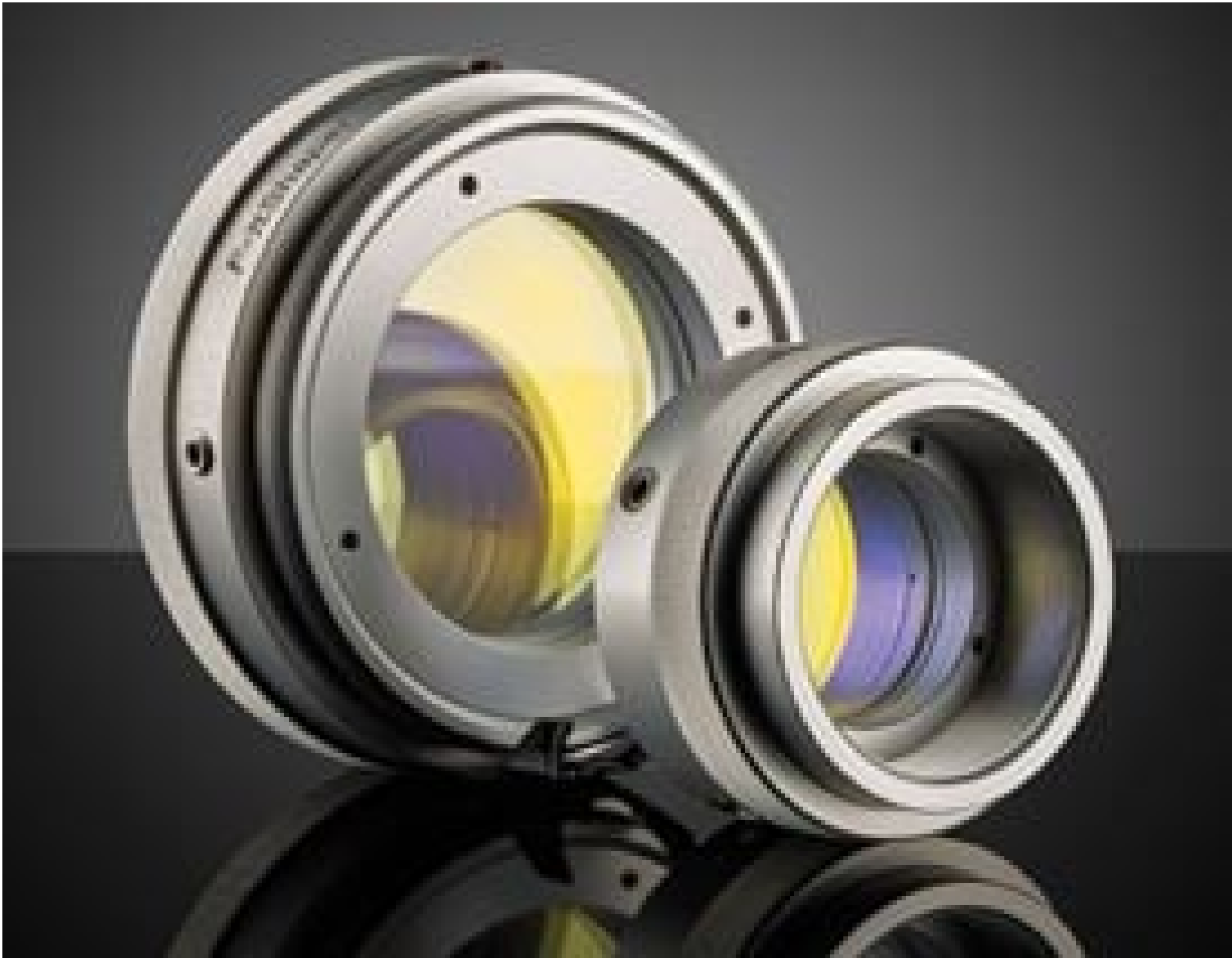

Stock **#12-238** ☐ In Stock

1

C\$4,698.40

ADD TO CART

Qty 1-4
C\$4,698.40
Qty 5+
C\$4,226.60
Volume Pricing
Request Quote

Get Product Downloads

Clear Aperture CA (mm):
20

Design Wavelength DWL (nm):

355, 532
Diameter (mm): 42.00
Model Number: πShaper_NUV_Q-5
Length (mm): 29.00
Transmission (%): >99
Type: Beam Shaper
Weight (g): 50
Wavelength Range (nm): 335 - 560
Input Beam Diameter, 1/e² (mm): 4 - 6
Maximum Input Power, CW (kW): 0.2
Inner Thread: M30 x0.75
Outer Thread: M30 x0.75
Compatible Adapter: #12-322
Input Beam Mode: TEM ₀₀
Typical Input Beam Mode Quality, M²: <1.5
Input Beam Divergence (mrad): ±20

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 240: Compliant