


TECHSPEC® 35mm Square 45°, Cyan Dichroic Filter

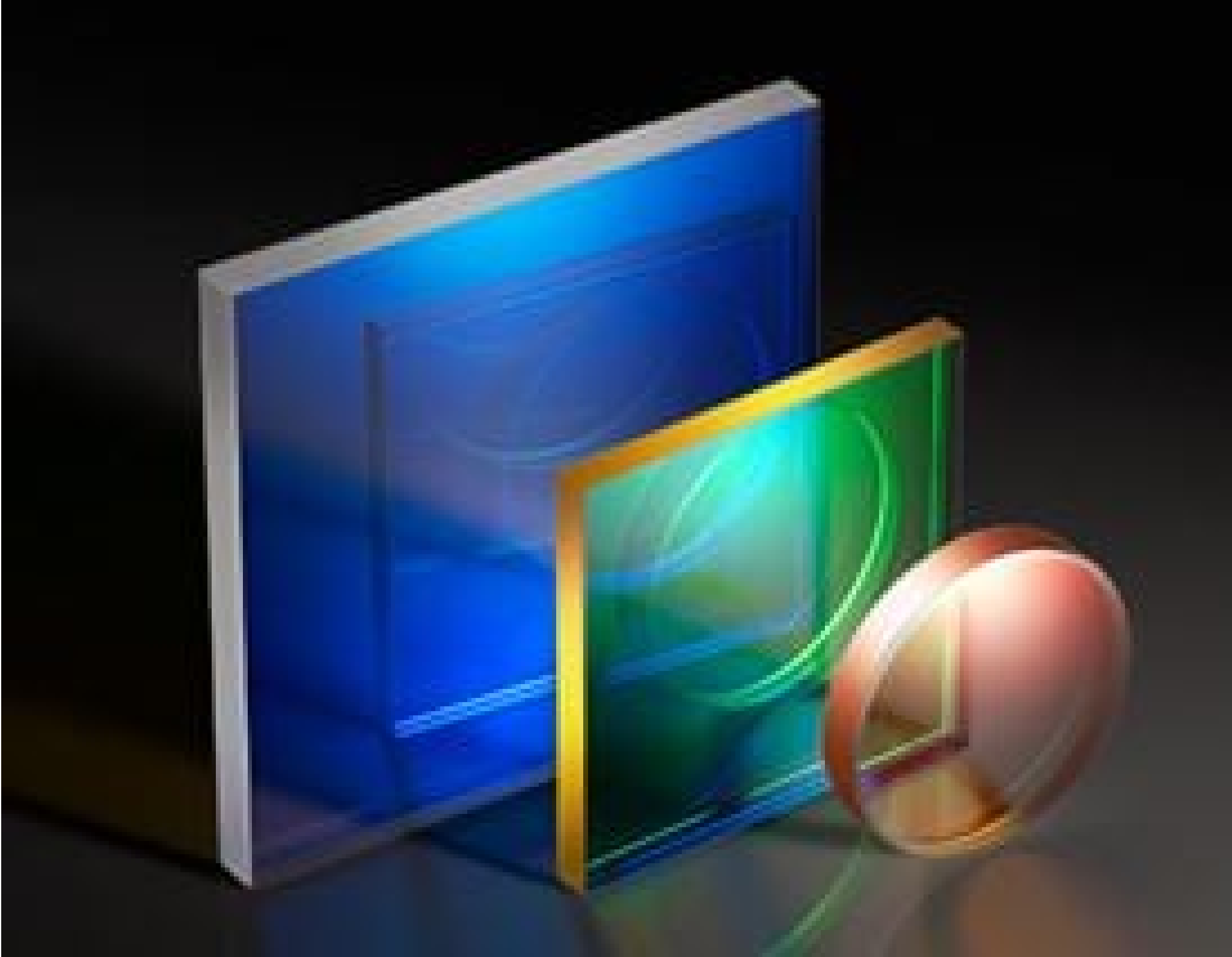

Stock **#66-248** ☐ In Stock

1 **C\$154.00**

ADD TO CART

Qty 1-10
C\$154.00
Qty 11+
C\$130.90
Volume Pricing
Request Quote

Get Product Downloads



Dimensions (mm):
35.0 x 35.0

Angle of Incidence (°):
45.00

Cut-Off Wavelength (nm):
590.00

Substrate: ☐

N-BK7
Length (mm): 35.00
Coating: Traditional Coated
Color: Cyan
Reflection (%): R _{abs} = 50% @ 590nm R _{avg} > 98% @ 400 - 565nm
Reflection Wavelength (nm): 400 - 565
Surface Quality: 60-40
Thickness (mm): 3.00
Thickness Tolerance (mm): ±0.20
Transmission (%): 90.00
Transmission Wavelength (nm): 625 - 725
Type: Dichroic Filter
Width (mm): 35.00
Wavelength Tolerance (nm): ±15
Parallelism (arcmin): <1
Dimensional Tolerance (mm): ±0.25
Clear Aperture (%): 90.00
Coating Specification: Surface 1: Multi-Layer Dichroic Surface 2: Single Layer MgF ₂
Wavelength Range (nm): 400 - 725
Surface Flatness (P-V): λ/4

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant