


TECHSPEC[®] 40mm, Center Drive, Thru-Hole, English Micrometer Stage

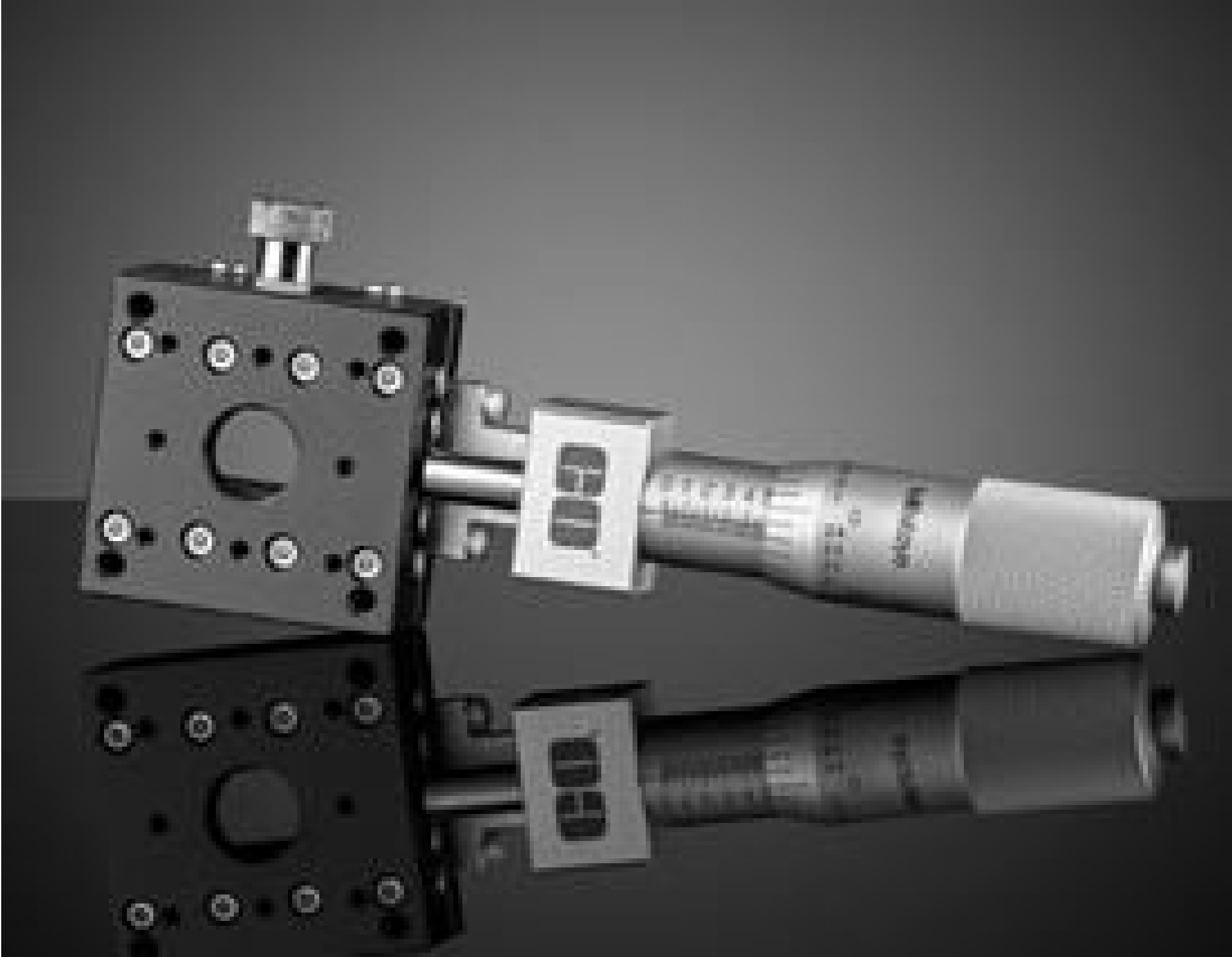

40mm, S-Mount (M12 x 0.5) Thread Centered, Micrometer Drive Stage (Center Drive)

Stock #66-415 ☐ In Stock

-

1

+

C\$548.80

ADD TO CART

Qty 1-2

C\$548.80

Qty 3+

C\$479.22

Volume Pricing

[Request Quote](#)

Get Product Downloads

Type of Movement:

Linear (X)

Guide System:

Crossed Roller Bearing

Type of Drive:

English Micrometer

Drive Orientation:

Center Drive
Type: English
Stage Size (mm): 40 x 40
Travel (inches): 0.5
Center Hole: M12 x 0.5
Construction: Aluminium Stage
Leadscrew Pitch (mm): 0.635
Load Capacity (kg): 4
Mounting Threads: (1) M12 x 0.5, (4) 6-32, (8) 2-56
Stage Size (inches): 1.57 x 1.57
Straight Line Accuracy (µm): 2
Pitch (arcsec): 30
Yaw (arcsec): 25

Regulatory Compliance

RoHS 2015: Exempt
Certificate of Conformance: View
Reach 233: Contains SVHC(s)
