


[All Products](#) / [Clearance Products](#) / [Clearance Optics](#) / [Drum Lenses](#)

[See all 9 Products in Family](#)

TECHSPEC® 4.0mm Diameter x 5.0mm Length, N-BK7 Drum Lens

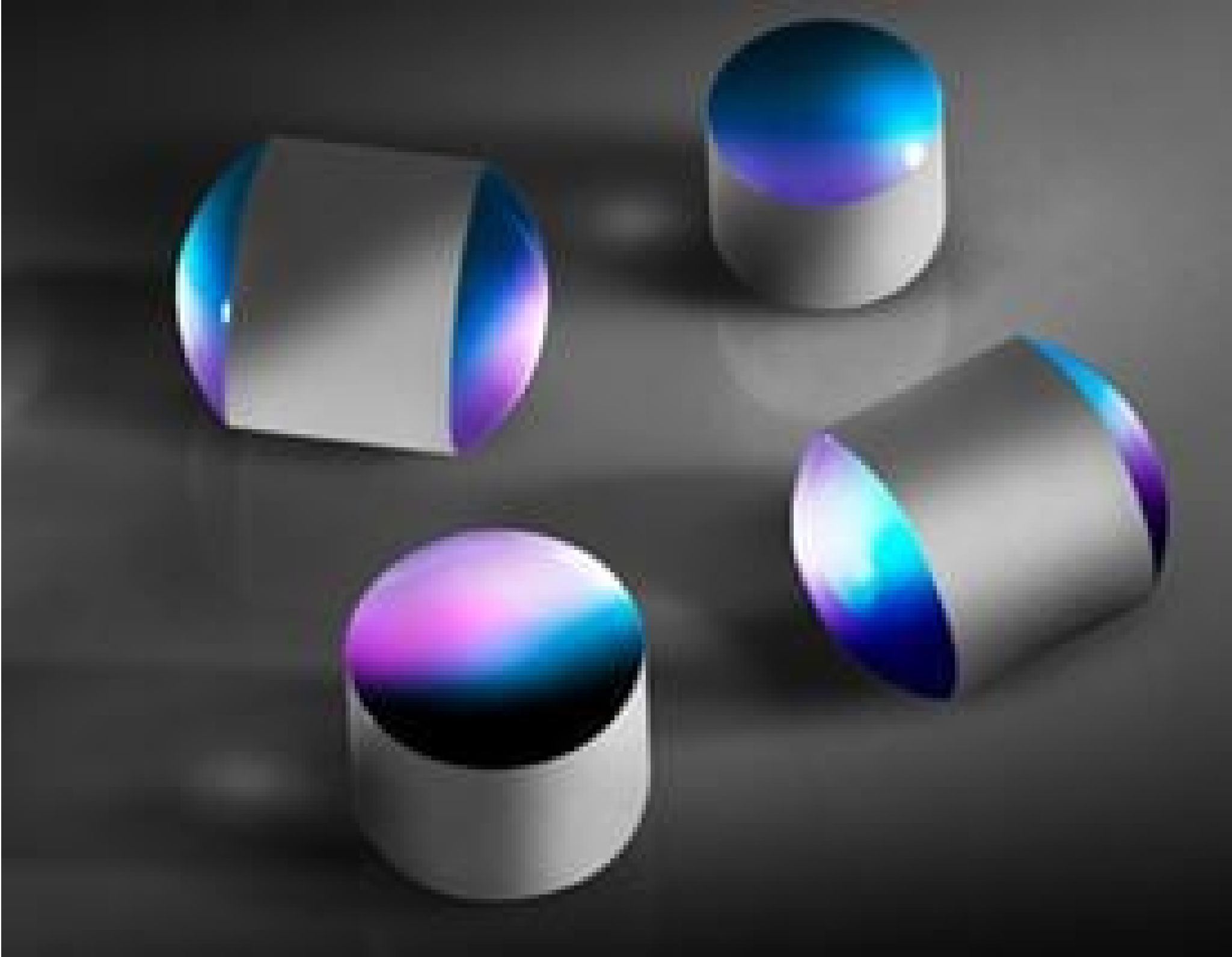

Stock **#45-551** CLEARANCE ☐ In Stock

1

C\$27.93

ADD TO CART

Qty 1+

C\$27.93

Volume Pricing

[Request Quote](#)

Get Product Downloads



Diameter (mm):
4.00

Substrate: ☐
[N-BK7](#)

Coating:
Uncoated

Type:
Drum Lens

Wavelength Range (nm):
350 - 2200

Index of Refraction n_d: 1.517
Length (mm): 5.00
Length Tolerance (μm): ± 3
Radius R (mm): 2.50
Radius Tolerance (μm): +0/-1.5
Surface Quality: 40-20
Diameter Tolerance (μm): +0/-50

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View