

TECHSPEC[®] 40mm, Side Drive, Standard Top, English, Micrometer Stage



40mm, Side Drive, Standard Top

Stock **#66-406** 4 In Stock

-

1

+

C\$613²⁰

ADD TO CART

Volume Pricing	
Qty 1-2	C\$613.20 each
Qty 3+	C\$534.80 each
Need More?	Request Quote

Product Downloads

General

Type:

English

Physical & Mechanical Properties

Type of Movement:

Linear (X)

Guide System:

Crossed Roller Bearing

Drive Orientation:

Hardware & Interface Connectivity


Threading & Mounting

[illegible]


Contains SVHC(s)	REACH 241:
------------------	------------

[illegible]


30mm Standard-Top Stages - Center Drive

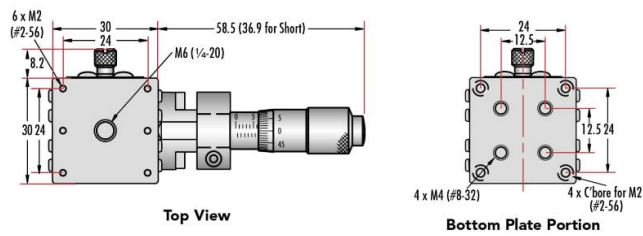


30mm Standard-Top Stages - Side Drive

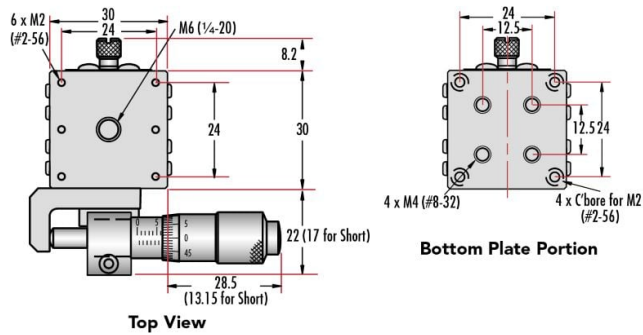


40mm Standard-Top Stages - Center Drive

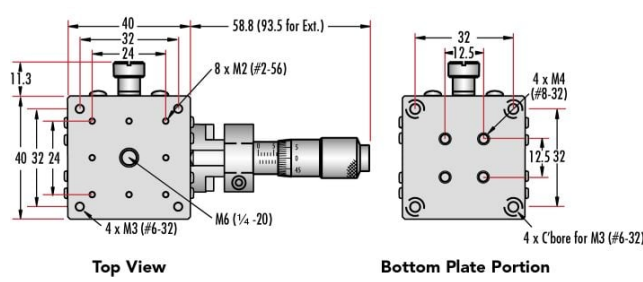


40mm Standard-Top Stages - Side Drive

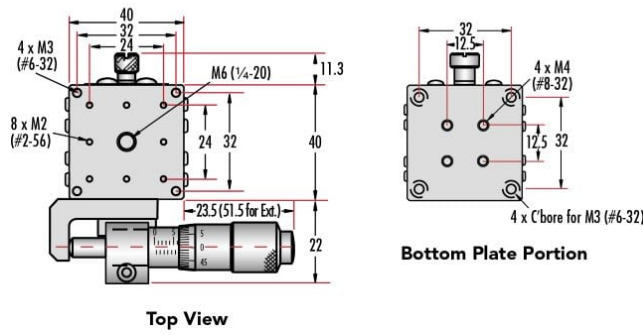


70mm Standard-Top Stages - Center Drive

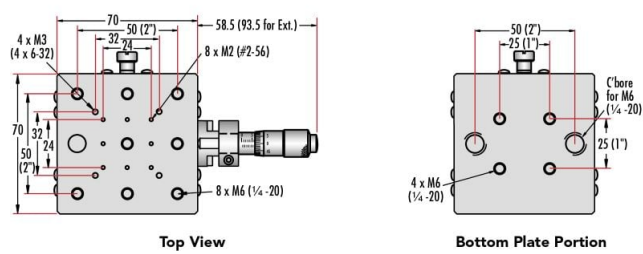

70mm Standard-Top Stages - Side Drive

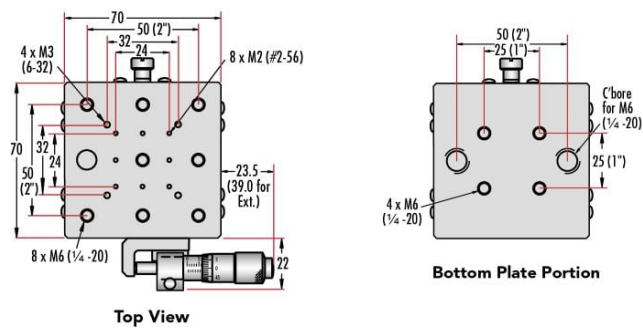

125mm Standard-Top Stages - Center Drive

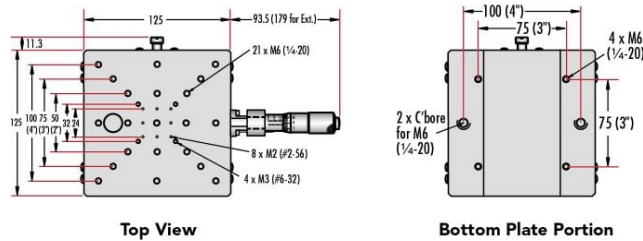

125mm Standard-Top Stages - Side Drive

