


48 x 84mm AR Coated Float Glass Window

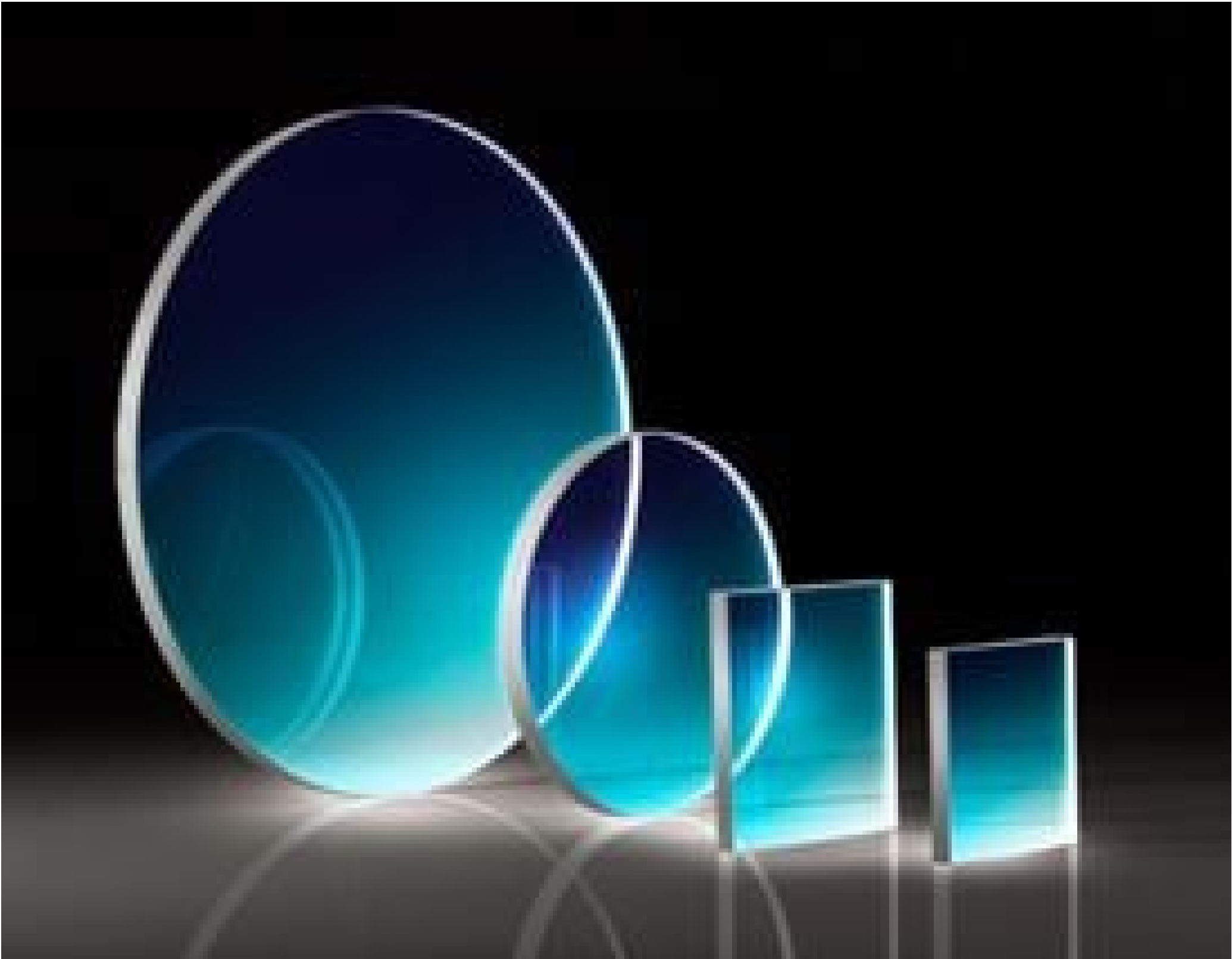

Stock **#32-741** 20+ In Stock

-

1

+

C\$41^{.65}

ADD TO CART

Volume Pricing	
Qty 1-5	C\$41.65 each
Qty 6-49	C\$37.80 each
Qty 50-99	C\$35.00 each
Need More?	Request Quote

Product Downloads

SPECIFICATIONS

General

Protective Window

Type:

Physical & Mechanical Properties

48.00 x 84.00	Dimensions (mm):
3.00 (nominal)	Thickness (mm):
Fine Ground	Edges:
84.00	Length (mm):
48.00	Width (mm):
Optical Properties	
BBAR (400-700nm)	Coating:
Float Glass	Substrate:
4 - 6λ	Surface Flatness (P-V):
80-50	Surface Quality:
400 - 700	Wavelength Range (nm):
Regulatory Compliance	
Compliant	RoHS 2015:
View	Certificate of Conformance:
Compliant	Reach 247:

PRODUCT DETAILS

- Transmits Visible and Near Infrared Wavelengths
- Available Uncoated or with an Anti-Reflection Coating
- Variety of Sizes Available

Float Glass Optical Windows are optical glass with polished faces that are relatively parallel and are typically used as a protective element between two environments. Float glass readily transmits visible and near-infrared wavelengths and can be used in a wide variety of applications. Float Glass Optical Windows are versatile products offered in circular and rectangular options. They are available uncoated or with BBAR (Broadband Anti-Reflective) 400-700nm coating.

COMPATIBLE MOUNTS